

## Clamping levers, die-cast zinc with external thread, threaded insert stainless steel

Item description/product images



### Description

**Material:**

Handle die-cast zinc DIN EN 12844.

Steel parts stainless steel 1.4305.

**Version:**

Handle, powder-coated.

Steel parts bright.

**Note:**

Standard colours are:

orange RAL 2004, ruby red RAL 3003, silver metallic.

Where  $L \geq 60$  mm the thread length is 60 mm.

**On request:**

Other threads, screw lengths, colours and special versions.

Dimension "H1" available in other lengths at extra charge.

**Drawing reference:**


1) flat point DIN EN ISO 4753

**Clamping levers, die-cast zinc with external thread, threaded insert stainless steel**

Item description/product images




lift to  
disengage

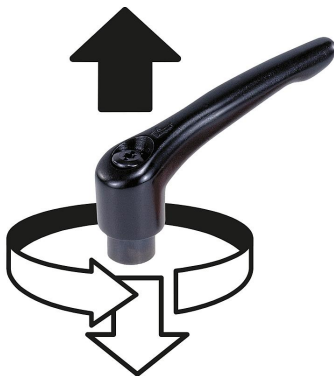

# Clamping levers, die-cast zinc with external thread, threaded insert stainless steel

Drawings

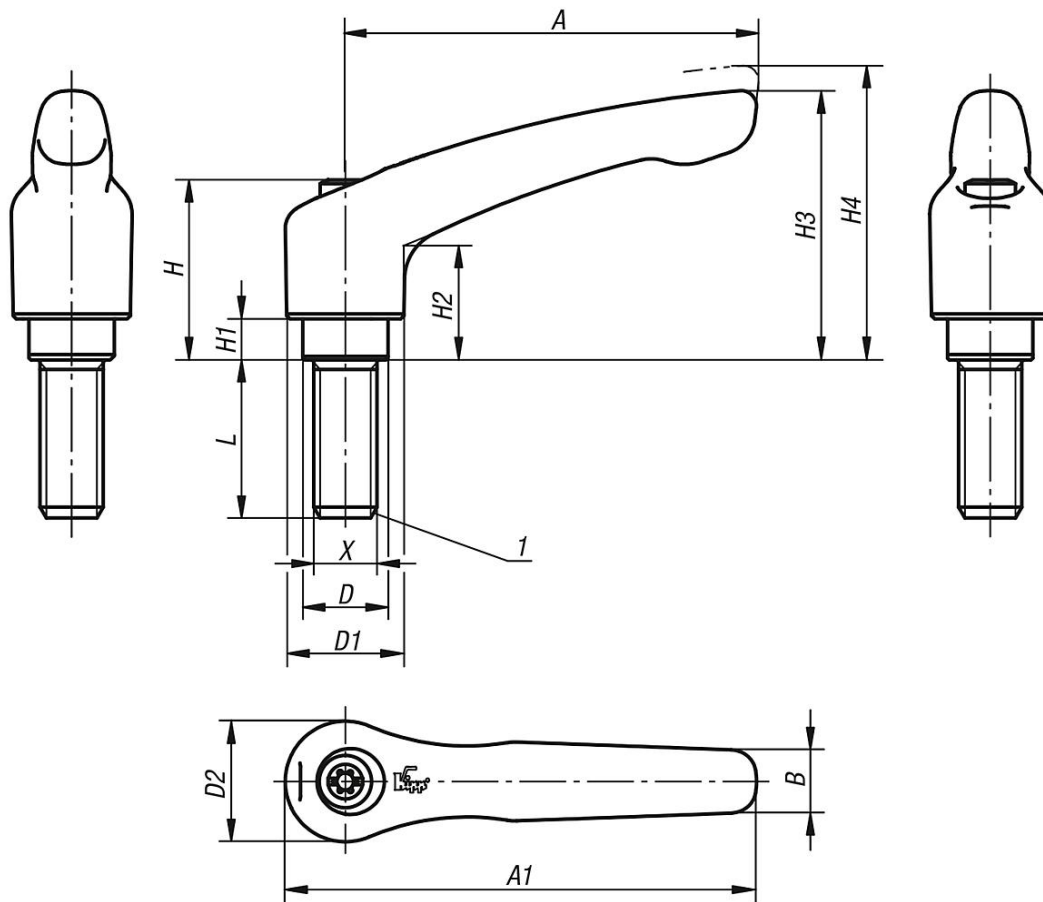

## Overview of items

### Clamping levers with male thread, steel parts stainless steel

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0123.00427X10	ruby red RAL3003	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.0042X10	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.0043X10	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.00427X15	ruby red RAL3003	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.0042X15	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.0043X15	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.00427X20	ruby red RAL3003	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.0042X20	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.0043X20	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.00427X25	ruby red RAL3003	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
K0123.0042X25	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
K0123.0043X25	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
K0123.00527X10	ruby red RAL3003	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.0052X10	orange RAL 2004	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.0053X10	silver metallic	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
K0123.00527X15	ruby red RAL3003	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.0052X15	orange RAL 2004	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.0053X15	silver metallic	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
K0123.00527X20	ruby red RAL3003	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.0052X20	orange RAL 2004	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.0053X20	silver metallic	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
K0123.00527X25	ruby red RAL3003	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25

# Clamping levers, die-cast zinc with external thread, threaded insert stainless steel

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0123.0052X25	orange RAL 2004	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
K0123.0053X25	silver metallic	plastic-coated	0	M5	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
K0123.10527X10	ruby red RAL3003	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.1052X10	orange RAL 2004	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.1053X10	silver metallic	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.10527X15	ruby red RAL3003	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.1052X15	orange RAL 2004	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.1053X15	silver metallic	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.10527X20	ruby red RAL3003	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.1052X20	orange RAL 2004	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.1053X20	silver metallic	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.10527X25	ruby red RAL3003	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.1052X25	orange RAL 2004	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.1053X25	silver metallic	plastic-coated	1	M5	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.10627X10	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.1062X10	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.1063X10	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	10
K0123.10627X15	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.1062X15	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.1063X15	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	15
K0123.10627X20	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.1062X20	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.1063X20	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	20
K0123.10627X25	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.1062X25	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.1063X25	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	25
K0123.10627X30	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	30
K0123.1062X30	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	30
K0123.1063X30	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	30
K0123.10627X40	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	40
K0123.1062X40	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	40
K0123.1063X40	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	40
K0123.10627X50	ruby red RAL3003	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	50
K0123.1062X50	orange RAL 2004	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	50
K0123.1063X50	silver metallic	plastic-coated	1	M6	10	13	14	24,5	4	14,5	31	34	40	47	7	16	50
K0123.20627X15	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.2062X15	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.2063X15	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.20627X20	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2062X20	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2063X20	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.20627X25	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2062X25	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2063X25	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.20627X30	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2062X30	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2063X30	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.20627X40	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2062X40	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2063X40	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.20627X50	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2062X50	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2063X50	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.20627X60	ruby red RAL3003	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2062X60	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2063X60	silver metallic	plastic-coated	2	M6	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.20827X15	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.2082X15	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.2083X15	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	15
K0123.20827X20	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2082X20	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2083X20	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20

# Clamping levers, die-cast zinc with external thread, threaded insert stainless steel

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0123.20827X25	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2082X25	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2083X25	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.20827X30	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2082X30	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2083X30	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.20827X40	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2082X40	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2083X40	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.20827X50	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2082X50	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2083X50	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.20827X60	ruby red RAL3003	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2082X60	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2083X60	silver metallic	plastic-coated	2	M8	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.21027X20	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2102X20	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.2103X20	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	20
K0123.21027X25	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2102X25	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.2103X25	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	25
K0123.21027X30	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2102X30	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.2103X30	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	30
K0123.21027X40	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2102X40	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.2103X40	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	40
K0123.21027X50	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2102X50	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.2103X50	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	50
K0123.21027X60	ruby red RAL3003	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2103X60	silver metallic	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.2102X60	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20	60
K0123.30827X20	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.3082X20	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.3083X20	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.30827X25	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.3082X25	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.3083X25	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.30827X30	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.3082X30	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.3083X30	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.30827X40	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40
K0123.3082X40	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40
K0123.3083X40	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40
K0123.30827X50	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.3082X50	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.3083X50	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.30827X60	ruby red RAL3003	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.3082X60	orange RAL 2004	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.3083X60	silver metallic	plastic-coated	3	M8	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.31027X20	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.3102X20	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.3103X20	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	20
K0123.31027X25	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.3102X25	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.3103X25	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	25
K0123.31027X30	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.3102X30	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.3103X30	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	30
K0123.31027X40	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40
K0123.3102X40	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40



# Clamping levers, die-cast zinc with external thread, threaded insert stainless steel

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0123.3103X40	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	40
K0123.31027X50	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.3102X50	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.3103X50	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	50
K0123.31027X60	ruby red RAL3003	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.3102X60	orange RAL 2004	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.3103X60	silver metallic	plastic-coated	3	M10	16	21	22	37	10	24	54,5	58,5	80	91	11	22	60
K0123.41227X25	ruby red RAL3003	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	25
K0123.4122X25	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	25
K0123.4123X25	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	25
K0123.41227X30	ruby red RAL3003	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	30
K0123.4122X30	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	30
K0123.4123X30	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	30
K0123.41227X40	ruby red RAL3003	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	40
K0123.4122X40	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	40
K0123.4123X40	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	40
K0123.41227X50	ruby red RAL3003	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	50
K0123.4122X50	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	50
K0123.4123X50	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	50
K0123.41227X60	ruby red RAL3003	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	60
K0123.4122X60	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	60
K0123.4123X60	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	60
K0123.51627X30	ruby red RAL3003	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
K0123.5162X30	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
K0123.5163X30	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
K0123.51627X40	ruby red RAL3003	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
K0123.5162X40	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
K0123.5163X40	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
K0123.51627X50	ruby red RAL3003	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
K0123.5162X50	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
K0123.5163X50	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
K0123.51627X60	ruby red RAL3003	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
K0123.5162X60	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
K0123.5163X60	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60