


Clamping technology | Standard elements | Operating parts

HEINRICH KIPP WERK

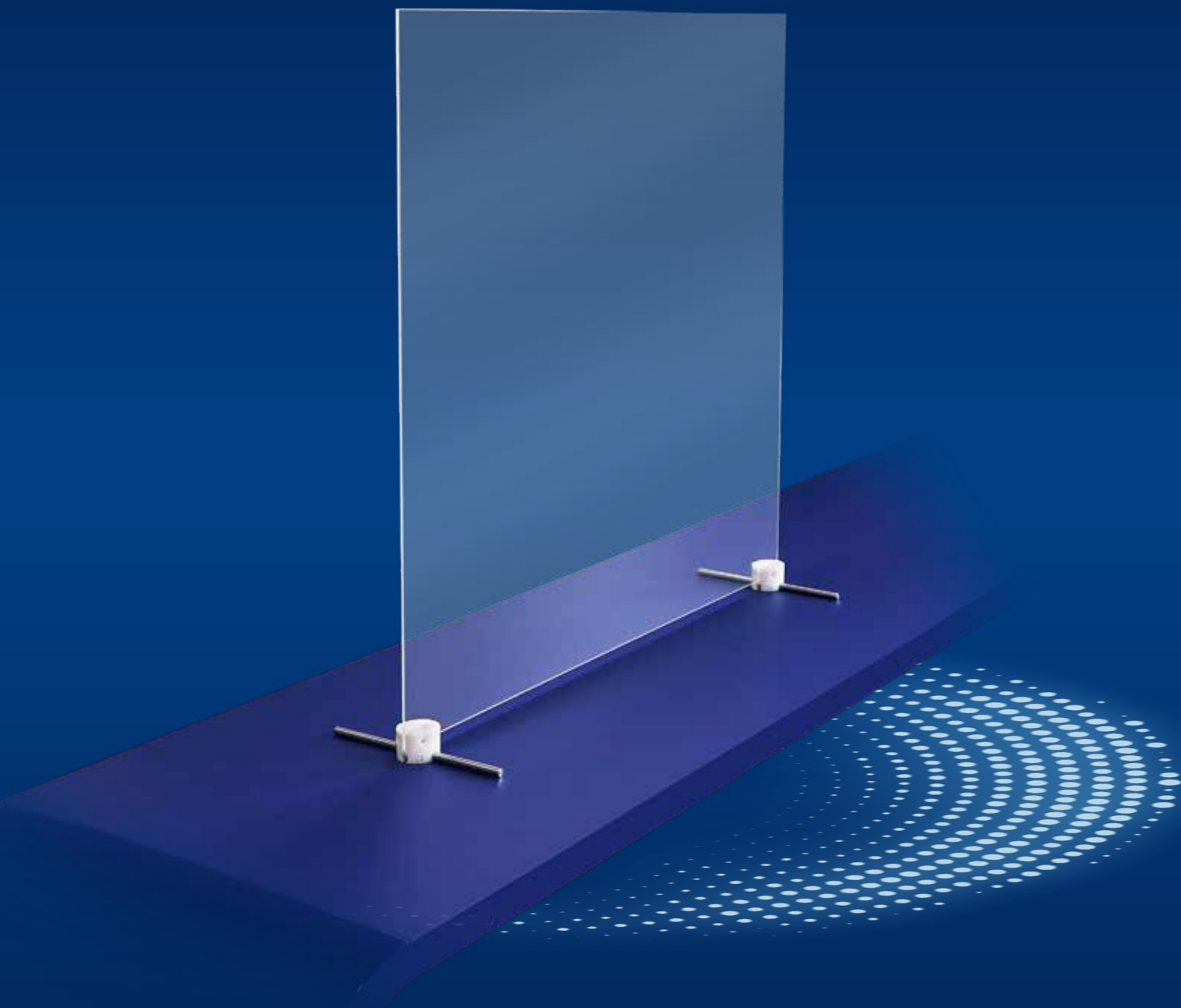

**HYGIENIC**shield

# TRUST IN KIPP

## Manufacturing expertise with family tradition

HEINRICH KIPP WERK has been a quality partner to industry for 100 years. We offer a comprehensive product spectrum with more than 42,000 elements in the core sectors of clamping technology, standard elements and operating parts.

During the Corona crises we have expanded our range to include special stands made from acrylic glass, plastic and aluminium.



The KIPP HYGIENICshield offers your employees and your customers sure protection from the coughing, sneezing and saliva of others. In our assortment you will find 3 products in various designs, some of which are modularly configurable. Special sizes can be supplied any time on request.

## **HYGIENICshield Standard**



## **HYGIENICshield System**



## **HYGIENICshield Premium**



Table and floor standing versions consisting of an aluminium frame and acrylic glass panels. Stable construction and universally applicable:

- Retail stores / Chemists
- Food markets / Checkout desks
- Doctors surgeries / Waiting rooms
- Reception desks / Entrance lobbies



## Free-standing floor version

Total height	1903 mm
Frame width	900 mm
Foot length	530 mm

- Square profile, frame top open
- Acrylic glass 850x850 mm, 4 mm thick
- Total clearance height 1000 mm
- Pass-through gap 140 mm by a table height of 860 mm

**K1081.21**



## Floor version on rollers

Total height	1960 mm
Frame width	900 mm
Foot length	530 mm

- Square profile, frame top open
- Acrylic glass 850x850 mm, 4 mm thick
- Total clearance height 1060 mm
- 2 swivel castors with roller brake for a secure stand

**K1081.26**



### Free-standing counter version

Total height	1025 mm
Pass-through gap	145 mm
Frame width	900 mm
Foot length	530 mm

- Square profile, frame top open
- Acrylic glass 850x850 mm, 4 mm thick

**K1081.11**



### Screwed-down counter version

Total height	1025 mm
Pass-through gap	145 mm
Frame width	900 mm
Foot area each	72x60 mm

- Square profile, frame top open
- Acrylic glass 850x850 mm, 4 mm thick

**K1081.12**



### Front mounted counter version

Total height	1275 mm
Pass-through gap	variable
Frame width	900 mm
Foot area each	72x60 mm

- Square profile, frame top open
- Acrylic glass 850x850 mm, 4 mm thick

**K1081.13**



### Special versions


On request, we can also supply all types in special sizes (dimensions can be configured individually).

Other version also possible on request:

- Screwed-on ceiling panel
- Screwed-on wall panel



# HYGIENICshield System

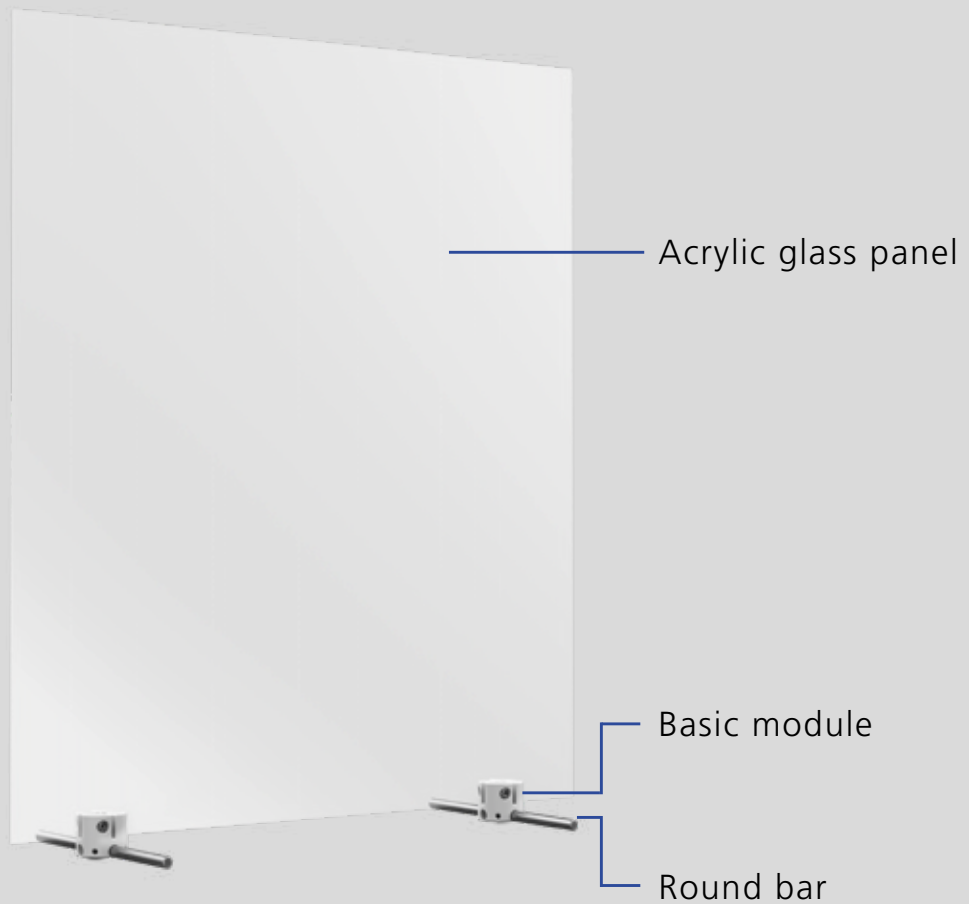

### Acrylic glass panel

Height 850 mm  
 Width 850 mm  
 Material 4 mm thick acrylic glass

**K1636.0850085004**



### Basic module 36 mm

Height 36 mm  
 Diameter 50 mm  
 Colour white  
 Colour black  
 Material Polyoxymethylene (POM)

**K1637.150036**

**K1637.250036**



### Basic module 145 mm

Height 145 mm  
 Diameter 50 mm  
 Colour white  
 Colour black  
 Material Polyoxymethylene (POM)

**K1637.150145**

**K1637.250145**




### Round bar

Length 250 mm  
 Length 125 mm  
 Diameter 10 mm  
 Material stainless steel 1.4404

**K1638.10X250**

**K1638.10X125**

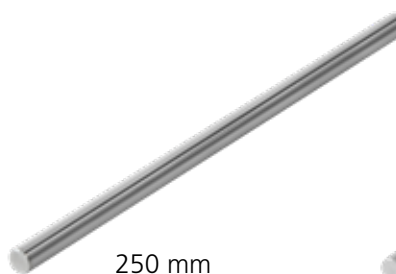




# HYGIENICshield System





Well thought-out modular system made of acrylic glass, plastic elements and stainless steel.  
Modular, light and flexible - perfectly suitable for:

- Catering / Hotels / Restaurants
- Office desks / Meeting rooms
- Counters / Communication areas
- Schools / Libraries

Various configurations can be created from the elements. Some possibilities are shown here.

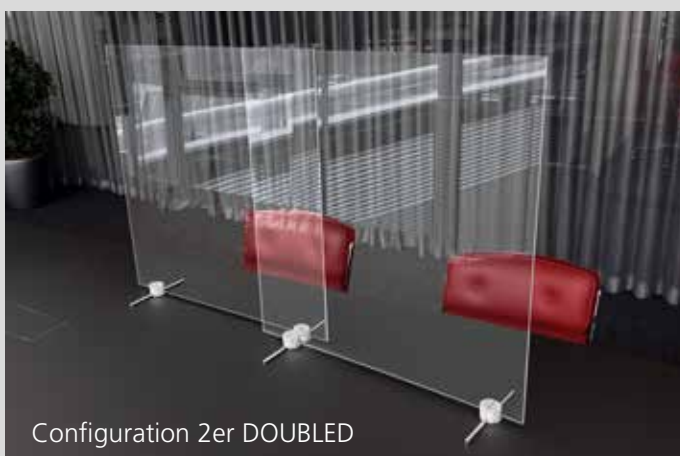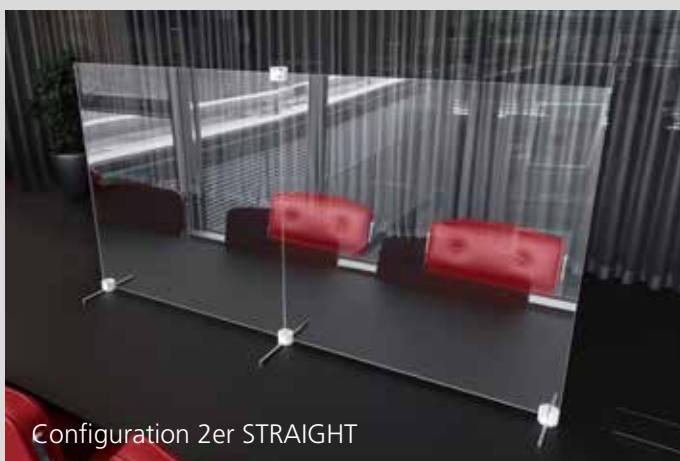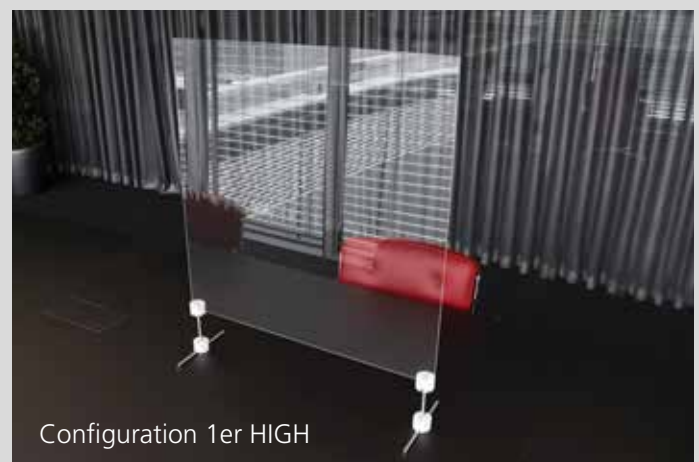




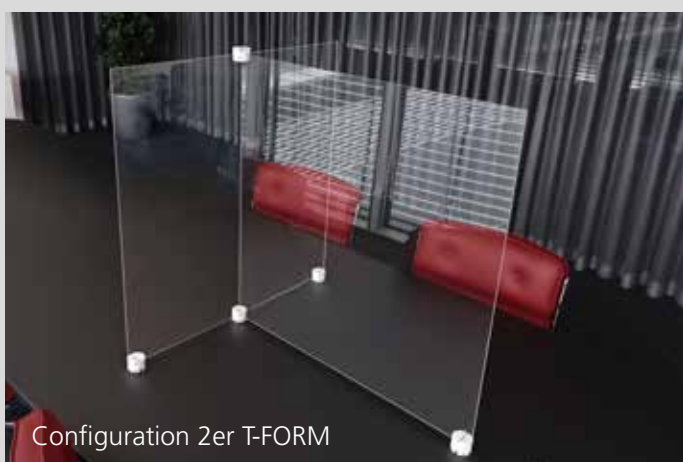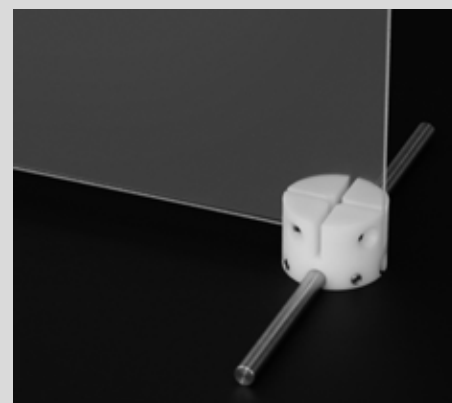


Configuration 2er T-FORM



Configuration 3er H-FORM

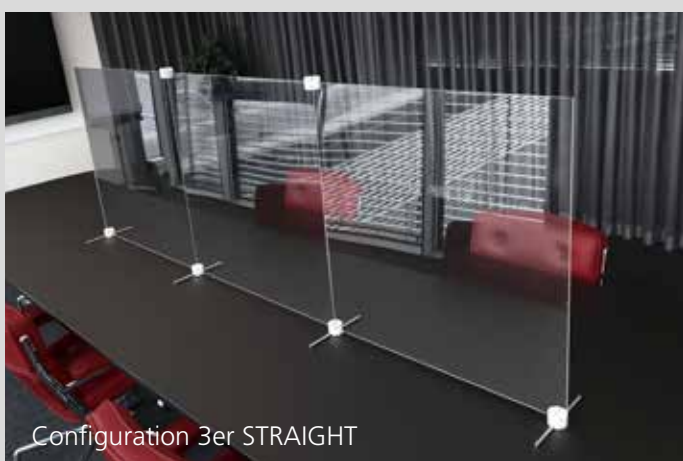


Configuration 3er STRAIGHT

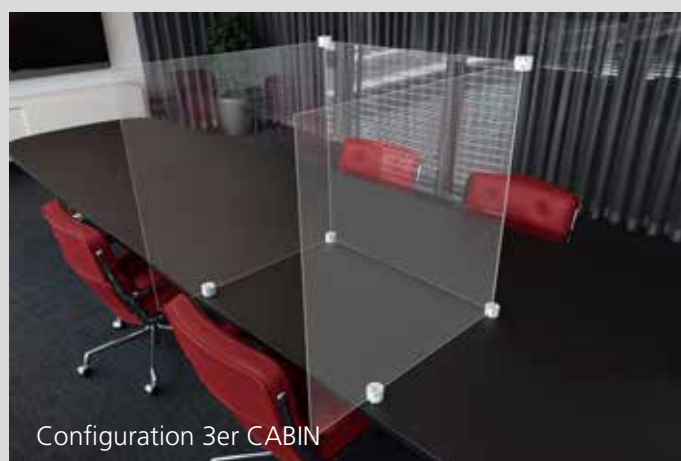

Configuration 3er CABIN



Configuration 4er CROSS

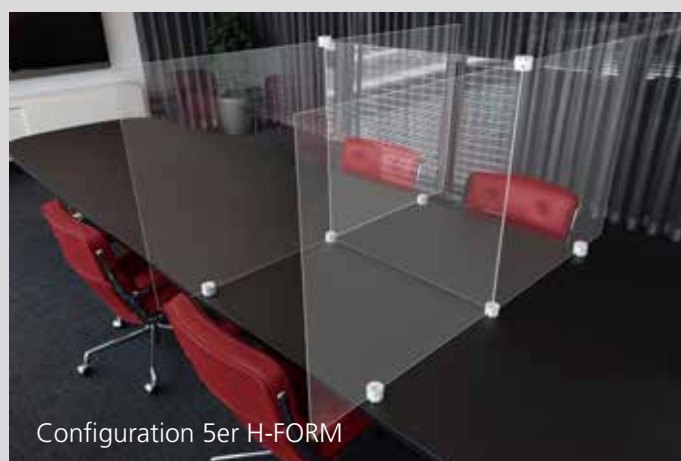

Configuration 5er H-FORM

# HYGIENICshield Premium



High quality solution consisting of solid aluminium profiles, hinges and acrylic glass panels. Functional folding system - ideal for conferences and meetings.

- Conference tables / Meeting rooms / Events
- Architect offices / Designer offices
- Agencies / Law firms / Consultation rooms

Height	910 mm
Rigid length	1610 mm
Swivel length	1710 mm
Foot length	445 mm
Pull-out panel	325 possible
Aluminium profile	30x30 mm
Acrylic glass	4 mm thick

**K1639.14**



- System suitable for meetings with 2 - 4 persons
- Length of the swivel sides variably adjustable with pull-out panels
- Robust version
- Swivelling and folding
- No tools required
- Folding panel movable on the main frame
- Panels can be fixated during transport



## **Application**

Mounting on counters, tables, equipment and plants in areas with high hygienic requirements.



Sales rooms



Clinics / Waiting rooms



Checkout desks



Hospitals



Medical technology / Laboratories



Foodstuff production

**Let our team advise you now:**



**Gerd Wiedemaier**

Special solutions Germany

Tel.: +49 7454 793-48  
gerd.wiedemaier@kipp.com



**Daniel Sauter**

Special solutions Germany

Tel.: +49 7454 793-7656  
daniel.sauter@kipp.com



**Klaus Bühler**

Contact person for dealers

Tel.: +49 7454 793-163  
klaus.buehler@kipp.com



**Hamit Ürgür**

Special solutions international

Tel.: +49 7454 793-7537  
hamit.uerguer@kipp.com

**HEINRICH KIPP WERK KG**

Heubergstrasse 2 | 72172 Sulz am Neckar | Tel. +49 7454 793-0 | info@kipp.com | www.kipp.com