

## Clamping grips high form

### Item description/product images



### Description

#### Product description:

These grips are distinguished by their unusual design. The high form permits high clamping forces while being gentle to the hand.

#### Material, version:

Grip black hard thermoplastic.

Coating black soft thermoplastic.

Tapped bush brass.

Screw electro zinc-plated steel grade 5.8.



#### Note:

SYMPA TOUCH high form clamping grips are available in 2 grip sizes with internal and external threads.

#### On request:

Other screw sizes, screw lengths, versions and colours.

### Drawings

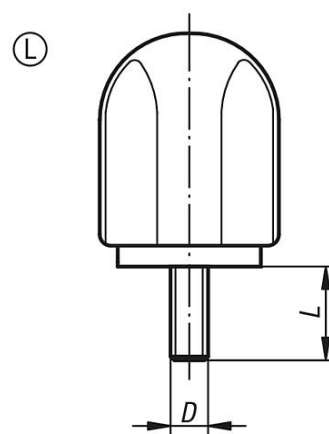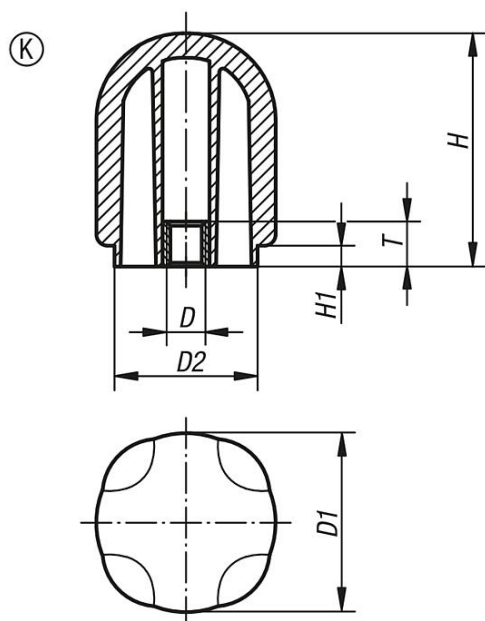

### Overview of items

#### Clamping grips high form with internal thread

| Order No.     | Form | D   | D1   | D2   | H    | H1  | T    | L  |
|---------------|------|-----|------|------|------|-----|------|----|
| K0280.4206    | K    | M6  | 42,7 | 34   | 55,6 | 4,8 | 12,5 | -  |
| K0280.4208    | K    | M8  | 42,7 | 34   | 55,6 | 4,8 | 12,5 | -  |
| K0280.4210    | K    | M10 | 42,7 | 34   | 55,6 | 4,8 | 12,5 | -  |
| K0280.4212    | K    | M12 | 42,7 | 34   | 55,6 | 4,8 | 12,5 | -  |
| K0280.4706    | K    | M6  | 47,8 | 38,1 | 62,2 | 5,6 | 12,5 | -  |
| K0280.4708    | K    | M8  | 47,8 | 38,1 | 62,2 | 5,6 | 12,5 | -  |
| K0280.4710    | K    | M10 | 47,8 | 38,1 | 62,2 | 5,6 | 12,5 | -  |
| K0280.4712    | K    | M12 | 47,8 | 38,1 | 62,2 | 5,6 | 12,5 | -  |
| K0280.4206X15 | L    | M6  | 42,7 | 34   | 55,6 | 4,8 | -    | 15 |

## Clamping grips high form

### Overview of items

| Order No.     | Form | D   | D1   | D2   | H    | H1  | T | L  |
|---------------|------|-----|------|------|------|-----|---|----|
| K0280.4206X20 | L    | M6  | 42,7 | 34   | 55,6 | 4,8 | - | 20 |
| K0280.4206X25 | L    | M6  | 42,7 | 34   | 55,6 | 4,8 | - | 25 |
| K0280.4206X35 | L    | M6  | 42,7 | 34   | 55,6 | 4,8 | - | 35 |
| K0280.4208X16 | L    | M8  | 42,7 | 34   | 55,6 | 4,8 | - | 16 |
| K0280.4208X25 | L    | M8  | 42,7 | 34   | 55,6 | 4,8 | - | 25 |
| K0280.4208X35 | L    | M8  | 42,7 | 34   | 55,6 | 4,8 | - | 35 |
| K0280.4210X20 | L    | M10 | 42,7 | 34   | 55,6 | 4,8 | - | 20 |
| K0280.4210X30 | L    | M10 | 42,7 | 34   | 55,6 | 4,8 | - | 30 |
| K0280.4210X40 | L    | M10 | 42,7 | 34   | 55,6 | 4,8 | - | 40 |
| K0280.4210X50 | L    | M10 | 42,7 | 34   | 55,6 | 4,8 | - | 50 |
| K0280.4706X20 | L    | M6  | 47,8 | 38,1 | 62,2 | 5,6 | - | 20 |
| K0280.4708X35 | L    | M8  | 47,8 | 38,1 | 62,2 | 5,6 | - | 35 |
| K0280.4710X40 | L    | M10 | 47,8 | 38,1 | 62,2 | 5,6 | - | 40 |
| K0280.4710X50 | L    | M10 | 47,8 | 38,1 | 62,2 | 5,6 | - | 50 |

### Clamping grips high form with external thread

| Order No.   | Form | D   | D1   | D2   | H    | H1  | L           |
|-------------|------|-----|------|------|------|-----|-------------|
| K0280.4206X | L    | M6  | 42,7 | 34   | 55,6 | 4,8 | 15/20/25/35 |
| K0280.4208X | L    | M8  | 42,7 | 34   | 55,6 | 4,8 | 16/25/35    |
| K0280.4210X | L    | M10 | 42,7 | 34   | 55,6 | 4,8 | 20/30/40/50 |
| K0280.4706X | L    | M6  | 47,8 | 38,1 | 62,2 | 5,6 | 20          |
| K0280.4708X | L    | M8  | 47,8 | 38,1 | 62,2 | 5,6 | 35          |
| K0280.4710X | L    | M10 | 47,8 | 38,1 | 62,2 | 5,6 | 40/50       |