

## Pull handle, oval aluminium, oblique

### Item description/product images



### Description

#### Product description:

These slanted pull handles are particularly suitable for mounting in places where space is limited. These handles are very strong and robust and can also be used where robust handling is required.

#### Material:

Aluminium EN AW-6063

#### Version:

Black or traffic red RAL 3020 powder-coated or bright.

#### Note:

The bright version can be painted or coated after assembly.

#### Application:

Where space is limited in machine and plant construction, toolmaking, furniture industry, rehabilitation and medical technology

#### Assembly:

From the rear.


#### Advantages:

Good access where space is limited.

Very stable and robust.

Retaining element for opening and closing covers, panels and hoods.

### Drawings

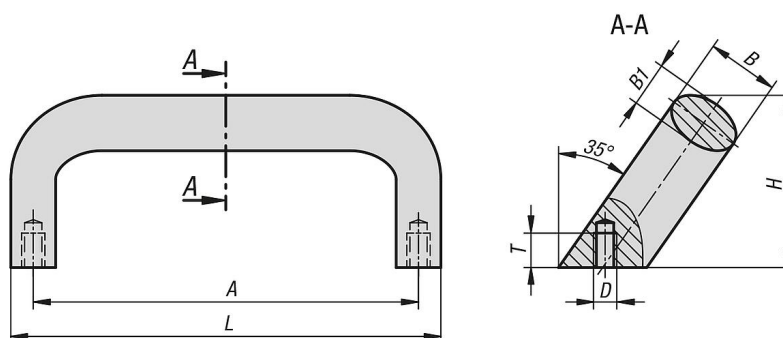

### Overview of items

#### Pull handles aluminium, oval, slanted

| Order No.     | Main colour | Surface finish body | A   | B  | B1 | D  | H  | L   | T  | Load capacity N |
|---------------|-------------|---------------------|-----|----|----|----|----|-----|----|-----------------|
| K1634.1000106 | black       | powder-coated       | 100 | 21 | 13 | M6 | 50 | 113 | 10 | 1000            |
| K1634.1120106 | black       | powder-coated       | 112 | 21 | 13 | M6 | 50 | 125 | 10 | 1000            |
| K1634.1200106 | black       | powder-coated       | 120 | 21 | 13 | M6 | 50 | 133 | 10 | 1000            |
| K1634.1280106 | black       | powder-coated       | 128 | 21 | 13 | M6 | 50 | 141 | 10 | 1000            |
| K1634.1600106 | black       | powder-coated       | 160 | 21 | 13 | M6 | 50 | 173 | 10 | 1000            |
| K1634.1120108 | black       | powder-coated       | 112 | 25 | 17 | M8 | 55 | 129 | 12 | 1000            |
| K1634.1200108 | black       | powder-coated       | 120 | 25 | 17 | M8 | 55 | 137 | 12 | 1000            |

## Pull handle, oval aluminium, oblique

### Overview of items

| Order No.     | Main colour          | Surface finish body | A   | B  | B1 | D  | H  | L   | T  | Load capacity N |
|---------------|----------------------|---------------------|-----|----|----|----|----|-----|----|-----------------|
| K1634.1280108 | black                | powder-coated       | 128 | 25 | 17 | M8 | 55 | 145 | 12 | 1000            |
| K1634.1600108 | black                | powder-coated       | 160 | 25 | 17 | M8 | 55 | 177 | 12 | 1000            |
| K1634.1800108 | black                | powder-coated       | 180 | 25 | 17 | M8 | 55 | 197 | 12 | 1000            |
| K1634.1008406 | traffic red RAL 3020 | powder-coated       | 100 | 21 | 13 | M6 | 50 | 113 | 10 | 1000            |
| K1634.1128406 | traffic red RAL 3020 | powder-coated       | 112 | 21 | 13 | M6 | 50 | 125 | 10 | 1000            |
| K1634.1208406 | traffic red RAL 3020 | powder-coated       | 120 | 21 | 13 | M6 | 50 | 133 | 10 | 1000            |
| K1634.1288406 | traffic red RAL 3020 | powder-coated       | 128 | 21 | 13 | M6 | 50 | 141 | 10 | 1000            |
| K1634.1608406 | traffic red RAL 3020 | powder-coated       | 160 | 21 | 13 | M6 | 50 | 173 | 10 | 1000            |
| K1634.1128408 | traffic red RAL 3020 | powder-coated       | 112 | 25 | 17 | M8 | 55 | 129 | 12 | 1000            |
| K1634.1208408 | traffic red RAL 3020 | powder-coated       | 120 | 25 | 17 | M8 | 55 | 137 | 12 | 1000            |
| K1634.1288408 | traffic red RAL 3020 | powder-coated       | 128 | 25 | 17 | M8 | 55 | 145 | 12 | 1000            |
| K1634.1608408 | traffic red RAL 3020 | powder-coated       | 160 | 25 | 17 | M8 | 55 | 177 | 12 | 1000            |
| K1634.1808408 | traffic red RAL 3020 | powder-coated       | 180 | 25 | 17 | M8 | 55 | 197 | 12 | 1000            |
| K1634.10006   | -                    | bright              | 100 | 21 | 13 | M6 | 50 | 113 | 10 | 1000            |
| K1634.11206   | -                    | bright              | 112 | 21 | 13 | M6 | 50 | 125 | 10 | 1000            |
| K1634.12006   | -                    | bright              | 120 | 21 | 13 | M6 | 50 | 133 | 10 | 1000            |
| K1634.12806   | -                    | bright              | 128 | 21 | 13 | M6 | 50 | 141 | 10 | 1000            |
| K1634.16006   | -                    | bright              | 160 | 21 | 13 | M6 | 50 | 173 | 10 | 1000            |
| K1634.11208   | -                    | bright              | 112 | 25 | 17 | M8 | 55 | 129 | 12 | 1000            |
| K1634.12008   | -                    | bright              | 120 | 25 | 17 | M8 | 55 | 137 | 12 | 1000            |
| K1634.12808   | -                    | bright              | 128 | 25 | 17 | M8 | 55 | 145 | 12 | 1000            |
| K1634.16008   | -                    | bright              | 160 | 25 | 17 | M8 | 55 | 177 | 12 | 1000            |
| K1634.18008   | -                    | bright              | 180 | 25 | 17 | M8 | 55 | 197 | 12 | 1000            |