


## Side clamps

### Item description/product images

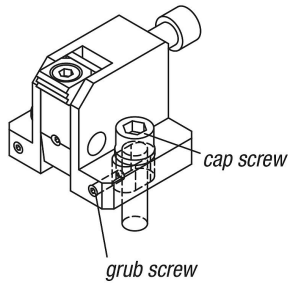

### Description

**Material:**

Housing and arm carbon steel.


Jaw tool steel.

**Version:**

Housing, black oxidised.

Arm and jaw tempered and black oxidised.

## Drawings

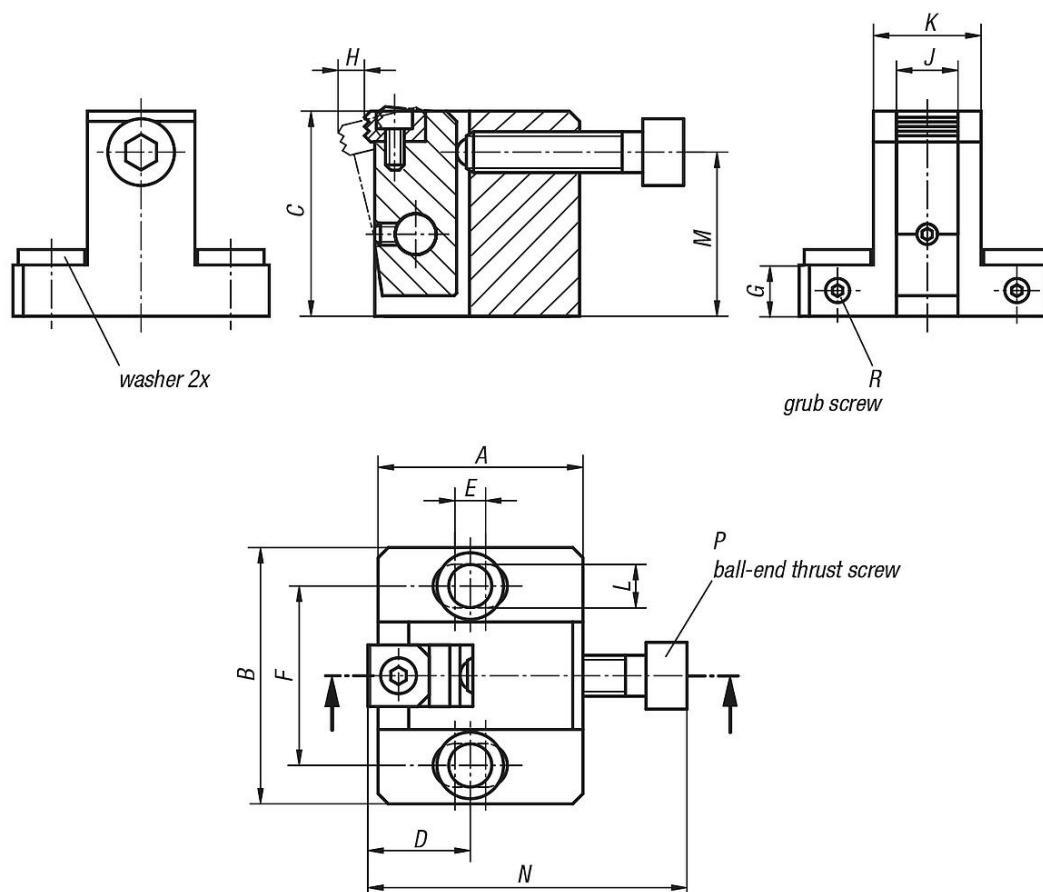

## Overview of items

## Side clamps

| Order No.    | A  | B  | C  | D  | E  | F  | G  | H    | J  | K  | L   | M  | N    | P        | R     | F=Retaining force N | Tightening torque Nm |
|--------------|----|----|----|----|----|----|----|------|----|----|-----|----|------|----------|-------|---------------------|----------------------|
| K0929.080400 | 40 | 50 | 40 | 20 | 6  | 35 | 10 | 5,3  | 12 | 21 | 8,5 | 32 | 62,5 | M8 x 35  | M4x10 | 15000               | 25                   |
| K0929.100500 | 50 | 65 | 50 | 25 | 8  | 45 | 12 | 7,1  | 16 | 27 | 11  | 40 | 74   | M10 x 40 | M4x12 | 27000               | 50                   |
| K0929.120600 | 60 | 70 | 60 | 30 | 10 | 50 | 15 | 8    | 20 | 31 | 13  | 48 | 91   | M12 x 50 | M5x15 | 38000               | 90                   |
| K0929.160800 | 80 | 90 | 80 | 40 | 15 | 65 | 20 | 10,2 | 25 | 39 | 17  | 64 | 115  | M16 x 60 | M6x20 | 46000               | 130                  |