

## Spring hinges steel or stainless steel, 120 mm, spring open

### Item description/product images



### Description

**Material:**

Steel or 1.4301 stainless steel.  
Tension spring stainless steel.

**Version:**

Steel bright or galvanised.  
Stainless steel bright.

**Note:**

Butt type hinges.  
Opening angle 270°.


**Spring torque:**

M(0°): 0.85 Nm / M(90°): 0.56 Nm / M(180°): 0.28 Nm

Form A: without holes

Form B: with holes

### Drawings

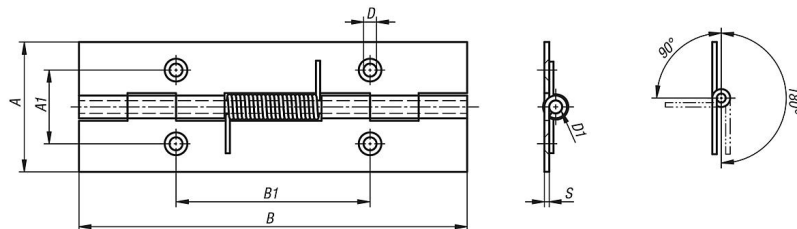

### Overview of items

Order No.	Form	Version	Main material	Base colour	A	A1	B	B1	D	D1	S
K1175.4012000	A	spring open	steel	bright	40	-	120	-	-	4	1,5
K1175.4012001	B	spring open	steel	Galvanized	40	22,7	120	60	4	4	1,5
K1175.14012000	A	spring open	stainless steel	bright	40	-	120	-	-	4	1,5
K1175.14012001	B	spring open	stainless steel	bright	40	22,7	120	60	4	4	1,5