


## Clamping balls with cup for workpiece stabiliser, Form C

### Item description/product images

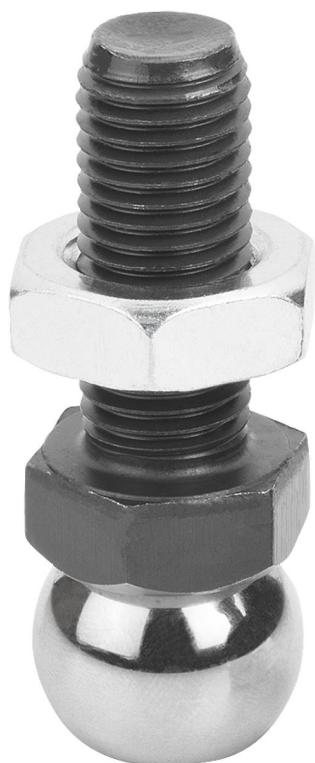

### Description

#### Material:

Steel.

#### Version:

DIN EN ISO 4017 hex head bolt , grade 8.8, black.

DIN EN ISO 4762 cap screw grade 8.8, black.

Clamping ball bright.


#### Note:

The clamping balls enable flexible connections between the workpiece and the workpiece stabiliser. The clamping balls provide a high degree of freedom on the workpiece.

#### Drawing reference:

1) DIN EN ISO 4762 M10 cap screw

### Drawings

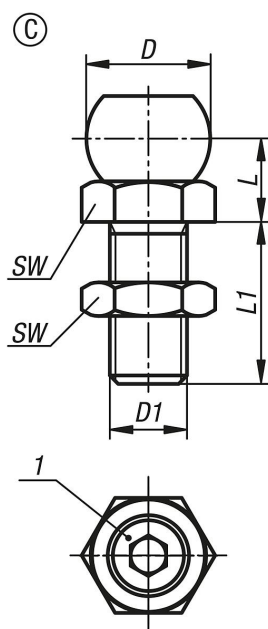

### Overview of items

Order No.	Form	Size	D	D1	L	L1	SW
K1193.3251240	C	25	25,4	M12	17,3	40	18
K1193.3251640	C	25	25,4	M16	19,8	40	24
K1193.3252050	C	25	25,4	M20	22,3	50	30
K1193.3252450	C	25	25,4	M24	24,8	50	36
K1193.3502450	C	50	50	M24	34,5	50	36

**Clamping balls with cup for workpiece stabiliser, Form C****Overview of items**

Order No.	Form	Size	D	D1	L	L1	SW
K1193.3503060	C	50	50	M30	34,5	60	46
K1193.3503670	C	50	50	M36	34,5	70	55