

## Tension levers with reamed hole, 0 degrees

### Item description/product images



### Description

#### Material:

Steel parts grade 5.8.  
Ball knob black plastic.

#### Version:

Black oxidised.


#### Note:

Tension levers can be used for simple clamping or control operations.  
Where applicable, there must be enough space available so that the grip can be rotated 360°.

#### On request:

Other female threads, reamed holes and special versions.  
Dimension "A" available in other lengths at extra charge.

### Drawings

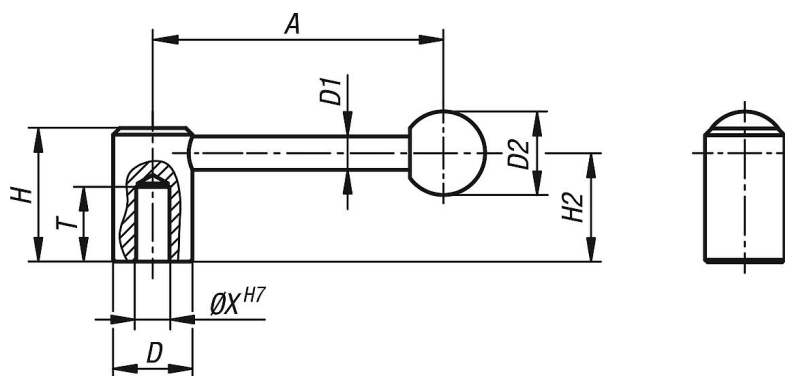

### Overview of items

Order No.	Kind of fastening	X	T	A=Handle length	D	D1	D2	H	H2
K0176.1102	reamed hole	10	22	88,1	24	10	25	40	32,5
K0176.1122	reamed hole	12	25	104	28	12	32	46	36,5
K0176.1142	reamed hole	14	25	104	28	12	32	46	36,5
K0176.1162	reamed hole	16	28	126,5	33	13	32	52	41
K0176.1202	reamed hole	20	32	128,5	41	13	32	61	49