

## R-clips similar to DIN 11024

### Item description/product images



### Description

#### Material:

Steel or stainless steel A2.

#### Version:

Steel electro zinc-plated.

Stainless steel bright.

#### Note:

R-clips are used for securing bolts and axles. They are easy to install and can be reused. The ends have no sharp edges.


Double coil R-clips have a flatter spring characteristics and are easier to install. The double coil allows a tether cable to be attached to prevent loss.

#### Drawing reference:

Form E: with single coil.

Form D: with double coil (coil direction can differ from the drawing).

### Drawings

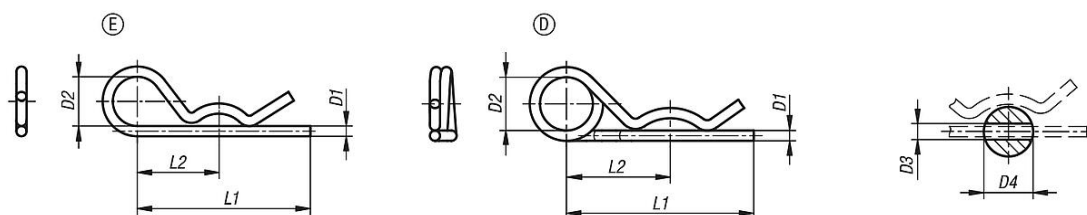

### Overview of items

#### R-clips similar to DIN 11024

| Order No.   | Main material      | Form | D1   | D2 | D3  | D4=for screw Ø | L1  | L2 |
|-------------|--------------------|------|------|----|-----|----------------|-----|----|
| K1137.11200 | steel              | E    | 2    | 10 | 2,5 | 9-14           | 50  | 25 |
| K1137.11300 | steel              | E    | 3    | 18 | 3,5 | 10-16          | 60  | 28 |
| K1137.11400 | steel              | E    | 4    | 20 | 4,5 | 16-20          | 60  | 30 |
| K1137.11500 | steel              | E    | 5    | 24 | 6   | 20-28          | 85  | 40 |
| K1137.11600 | steel              | E    | 6    | 30 | 7   | 28-40          | 105 | 50 |
| K1137.11700 | steel              | E    | 7    | 30 | 8   | 28-45          | 105 | 50 |
| K1137.21200 | stainless steel A2 | E    | 2    | 10 | 2,5 | 7-8            | 40  | 25 |
| K1137.21250 | stainless steel A2 | E    | 2,5  | 11 | 3   | 10-16          | 46  | 24 |
| K1137.21300 | stainless steel A2 | E    | 3    | 16 | 3,5 | 16-18          | 60  | 34 |
| K1137.21400 | stainless steel A2 | E    | 4    | 19 | 4,5 | 18-20          | 64  | 36 |
| K1137.21500 | stainless steel A2 | E    | 5    | 26 | 6   | 20-28          | 82  | 45 |
| K1137.21600 | stainless steel A2 | E    | 6    | 30 | 7   | 28-40          | 110 | 60 |
| K1137.12225 | steel              | D    | 2,25 | 20 | 2,5 | 9-11,2         | 42  | 24 |
| K1137.12280 | steel              | D    | 2,8  | 20 | 3,2 | 11,2-14        | 48  | 26 |
| K1137.12360 | steel              | D    | 3,6  | 20 | 4   | 14-20          | 64  | 32 |
| K1137.12450 | steel              | D    | 4,5  | 25 | 5   | 20-26          | 80  | 39 |
| K1137.12560 | steel              | D    | 5,6  | 25 | 6,3 | 26-34          | 97  | 45 |
| K1137.12630 | steel              | D    | 6,3  | 30 | 7   | 34-45          | 125 | 56 |
| K1137.12700 | steel              | D    | 7    | 30 | 8   | 45-56          | 150 | 63 |
| K1137.22225 | stainless steel A2 | D    | 2,25 | 20 | 2,5 | 7-9            | 42  | 24 |
| K1137.22280 | stainless steel A2 | D    | 2,8  | 20 | 3,2 | 11-14          | 48  | 26 |
| K1137.22360 | stainless steel A2 | D    | 3,6  | 20 | 4   | 14-20          | 64  | 32 |

## R-clips similar to DIN 11024

### Overview of items

| Order No.   | Main material      | Form | D1  | D2 | D3  | D4=for screw Ø | L1 | L2 |
|-------------|--------------------|------|-----|----|-----|----------------|----|----|
| K1137.22450 | stainless steel A2 | D    | 4,5 | 25 | 5   | 20-26          | 80 | 39 |
| K1137.22560 | stainless steel A2 | D    | 5,6 | 25 | 6,3 | 26-34          | 97 | 45 |