

Knurled knobs with arrow

Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	colza yellow RAL 1021	

Description

Material:

Knurled knob thermoplastic.
Washer aluminium.

Version:

Knurled knob black grey.
Washer, black anodised.

Note:


The arrow is engraved after anodizing. The set screw secures both the hub and the pressed-in washer. The H7 hole in the hub ensures a good tight fit on the shaft.

Δ Add the desired cap colour here. No colour code is required for black grey caps.

Drawing reference:

1) set screw

Drawings

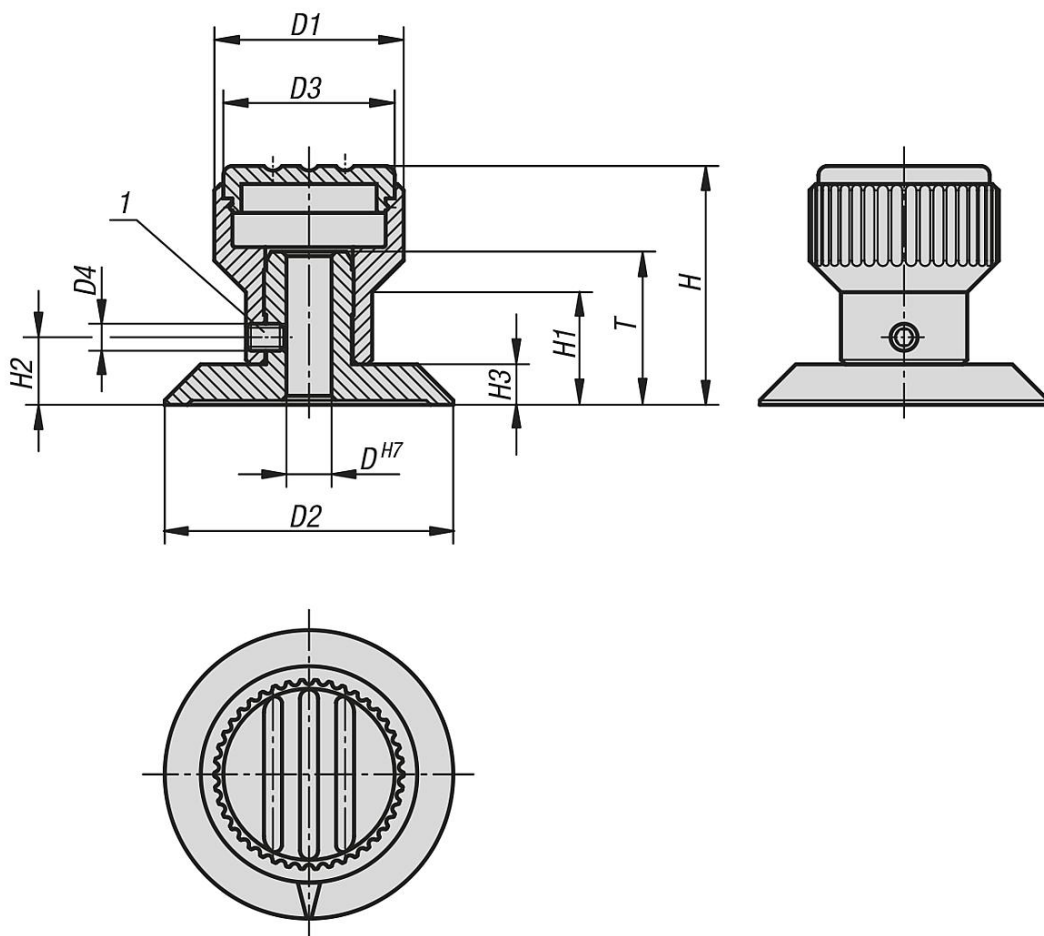

Knurled knobs with arrow

Overview of items

Knurled knobs with arrow

Order No.	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	T
K0249.105	black grey RAL 7021	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1051	orange RAL 2004	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1052	signal green RAL 6032	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1053	blue RAL5017	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1055	light grey RAL 7035	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1056	traffic red RAL 3020	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.1057	colza yellow RAL 1021	5	21	32	19	M3	26,5	12,5	7,5	4,5	17
K0249.206	black grey RAL 7021	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2061	orange RAL 2004	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2062	signal green RAL 6032	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2063	blue RAL5017	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2065	light grey RAL 7035	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2066	traffic red RAL 3020	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.2067	colza yellow RAL 1021	6	26	40	23	M4	31,5	15	9,5	5,5	20,5
K0249.308	black grey RAL 7021	8	34	52	31	M4	43	20	12	7	22
K0249.3081	orange RAL 2004	8	34	52	31	M4	43	20	12	7	22
K0249.3082	signal green RAL 6032	8	34	52	31	M4	43	20	12	7	22
K0249.3083	blue RAL5017	8	34	52	31	M4	43	20	12	7	22
K0249.3085	light grey RAL 7035	8	34	52	31	M4	43	20	12	7	22
K0249.3086	traffic red RAL 3020	8	34	52	31	M4	43	20	12	7	22
K0249.3087	colza yellow RAL 1021	8	34	52	31	M4	43	20	12	7	22