

Lip profiles PVC

Item description/product images



Description

Product description:

Conventional PVC sealing profiles for insertion into sealing ducts, slots or U-profiles.

The lip profiles reliably seal and protect the components from external influences.

Material:

PVC.

Version:

black.

Note:

Shore 57A $\pm$ 5.

Observe tolerances acc. to DIN 16941.

Application:

- Switchbox construction
- Machine and plant construction
- Automotive industry
- Construction and window fabrication

Assembly:

Quick, simple and smooth installation. When pressed in by hand, the lip profile jams into a gap or channel between two faces.

On request:



Other lengths.

Drawing reference:

1) Clamping range

Lip profiles PVC

Drawings

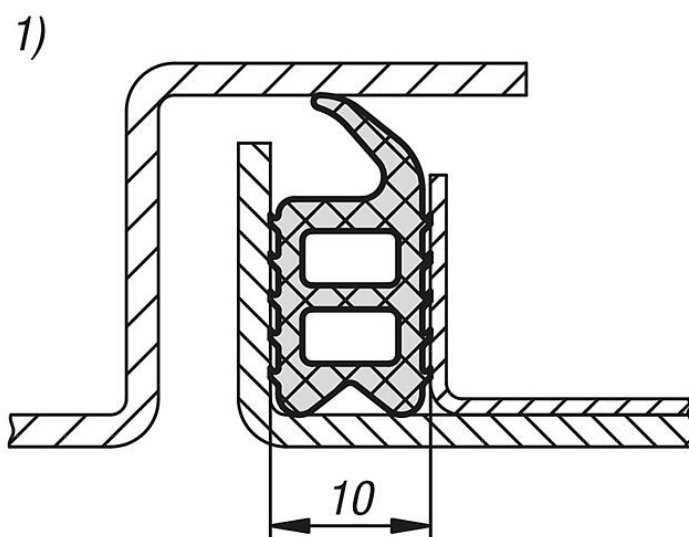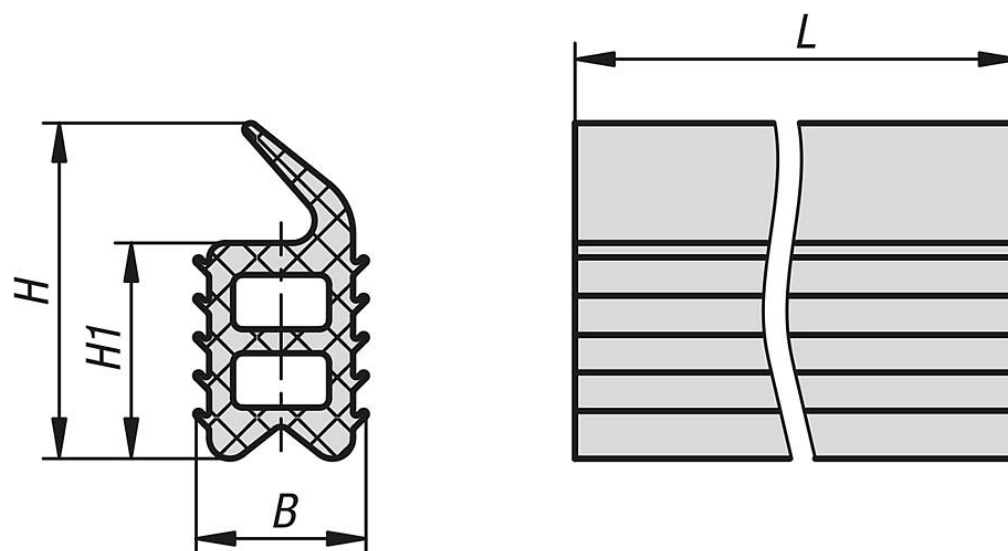

Overview of items

Lip profiles PVC

Order No.	B	H	H1	L	Clamping range mm
K2398.0170X2000	11	17	9,5	2000	10
K2398.0170X5000	11	17	9,5	5000	10
K2398.0170X10000	11	17	9,5	10000	10
K2398.0170X20000	11	17	9,5	20000	10
K2398.0195X2000	11	19,5	11,5	2000	10
K2398.0195X5000	11	19,5	11,5	5000	10
K2398.0195X10000	11	19,5	11,5	10000	10
K2398.0195X20000	11	19,5	11,5	20000	10

Lip profiles PVC

Overview of items

Order No.	B	H	H1	L	Clamping range mm
K2398.0215X2000	11	21,5	13,5	2000	10
K2398.0215X5000	11	21,5	13,5	5000	10
K2398.0215X10000	11	21,5	13,5	10000	10
K2398.0215X20000	11	21,5	13,5	20000	10
K2398.0275X2000	11	27,5	19,5	2000	10
K2398.0275X5000	11	27,5	19,5	5000	10
K2398.0275X10000	11	27,5	19,5	10000	10
K2398.0275X20000	11	27,5	19,5	20000	10