
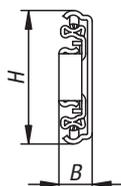
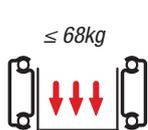


Instrucciones de montaje K2088

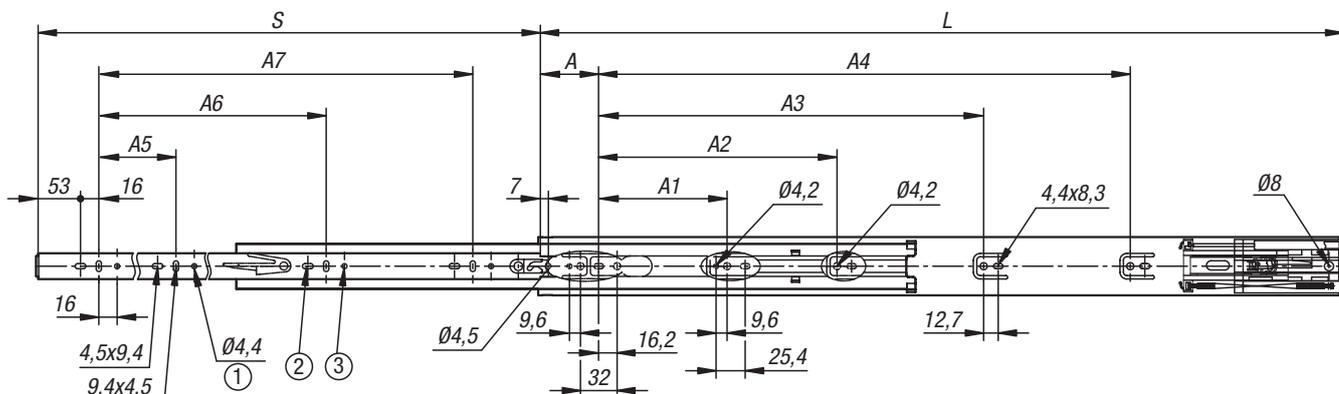

1) K2088.0300	2) K2088.0350	3) K2088.0400
---------------	---------------	---------------

Referencia	L	S	A1	A2	A3	A4	A5	A6	A7	Capacidad de carga por par kg
K2088.0300	300	275	-	96	-	-	192	-	-	35
K2088.0350	350	350	128	-	-	-	128	224	-	35
K2088.0400	400	400	128	192	-	-	160	288	-	50
K2088.0450	450	450	128	256	-	-	160	320	-	50
K2088.0500	500	500	128	224	288	-	192	384	-	60
K2088.0550	550	550	128	224	352	-	224	416	-	60
K2088.0600	600	600	128	224	352	-	256	480	-	68
K2088.0650	650	650	128	224	352	448	256	512	-	68
K2088.0700	700	700	128	224	352	480	256	448	576	68

Se deben utilizar todas las posiciones de fijación con vistas a alcanzar el máximo valor de carga.

No apto para el montaje plano.

El cajón no debe ser más ancho que la longitud del carril.

1,2,3 no tiene agujero de montaje.

Mantiene la jaula de bolas delante durante la fijación del cajón.

Instrucciones de montaje K2088



Fijación del carril

