


Instrucciones de montaje K2089

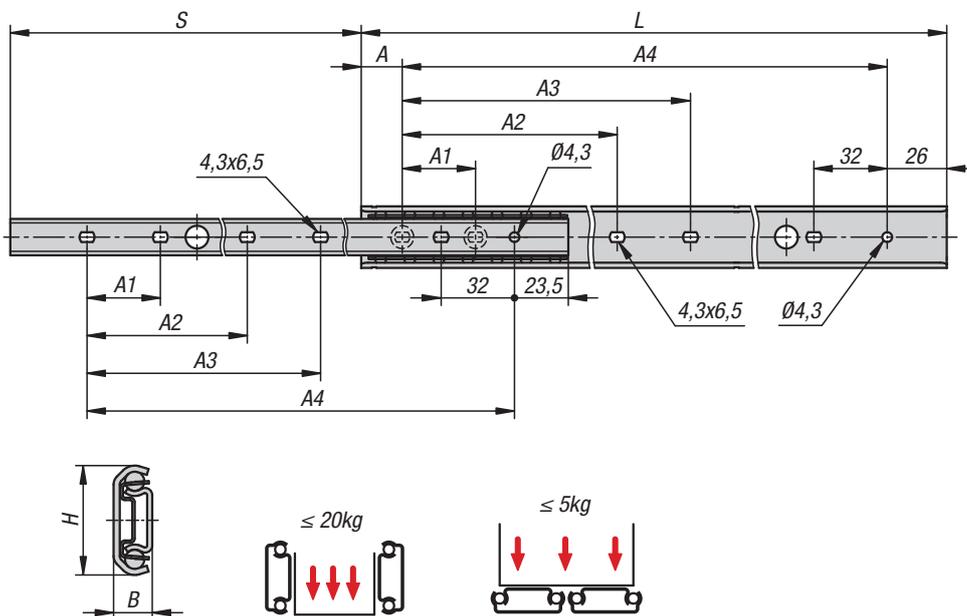

Referencia	L	S	A	A1	A2	A3	A4	Capacidad de carga por par kg
K2089.0200	200	145,2	14	32	-	-	160	13
K2089.0250	250	182,5	32	32	-	-	192	15
K2089.0300	300	219,8	18	32	128	-	256	18
K2089.0350	350	257,1	36	32	128	160	288	20
K2089.0400	400	294,4	22	32	160	192	352	20
K2089.0450	450	331,7	40	32	160	192	384	20
K2089.0500	500	369	26	32	192	224	448	18

Se deben utilizar todas las posiciones de fijación con vistas a alcanzar el máximo valor de carga.

Instalación del carril sobre o por debajo de la línea central del cajón.

No apto para el montaje plano.

Instrucciones de montaje K2089



Fijación del carril

