

## Press-in plugs

### Item description/product images



### Description

#### Material:

Housing and cap thermoplastic polyamide 66.

Air filter polyurethane (PU foam).

O-ring rubber (NBR).

#### Version:

Housing black.

Cap red.

Filter mesh 50 µm.

#### Temperature range:

Temperature resistant with oil up to 100°C.

#### Drawing reference:

Form A: without vent


Form B: with vent

Form C: with vent and air filter

1) O-ring

2) air filter Form C only

### Drawings

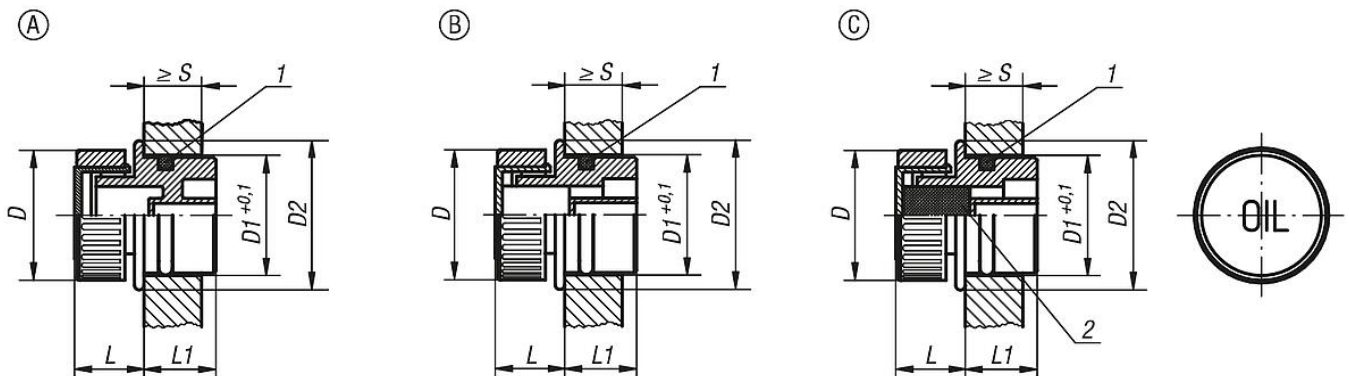

### Overview of items

### Press-in plugs

| Order No.   | Form | D  | D1 | D2 | L  | L1   | S<br>min. |
|-------------|------|----|----|----|----|------|-----------|
| K0451.13018 | A    | 30 | 18 | 23 | 14 | 14   | 8         |
| K0451.13020 | A    | 30 | 20 | 24 | 14 | 15,5 | 8         |
| K0451.13026 | A    | 30 | 26 | 30 | 14 | 16,5 | 9,5       |
| K0451.13030 | A    | 30 | 30 | 34 | 14 | 17   | 9,5       |
| K0451.23018 | B    | 30 | 18 | 23 | 14 | 14   | 8         |
| K0451.23020 | B    | 30 | 20 | 24 | 14 | 15,5 | 8         |
| K0451.23026 | B    | 30 | 26 | 30 | 14 | 16,5 | 9,5       |
| K0451.23030 | B    | 30 | 30 | 34 | 14 | 17   | 9,5       |
| K0451.33018 | C    | 30 | 18 | 23 | 14 | 14   | 8         |
| K0451.33020 | C    | 30 | 20 | 24 | 14 | 15,5 | 8         |
| K0451.33026 | C    | 30 | 26 | 30 | 14 | 16,5 | 9,5       |
| K0451.33030 | C    | 30 | 30 | 34 | 14 | 17   | 9,5       |

