

Рукоятки крестообразные согласно DIN 6335, форма L, с наружной резьбой

Описание товара/фотография продукта



Описание

Материал:


Дуропласт PF 31, черный.

Резьбовой винт, сталь оцинкованная.

Исполнение:

Отполированный до блеска.

Чертежи

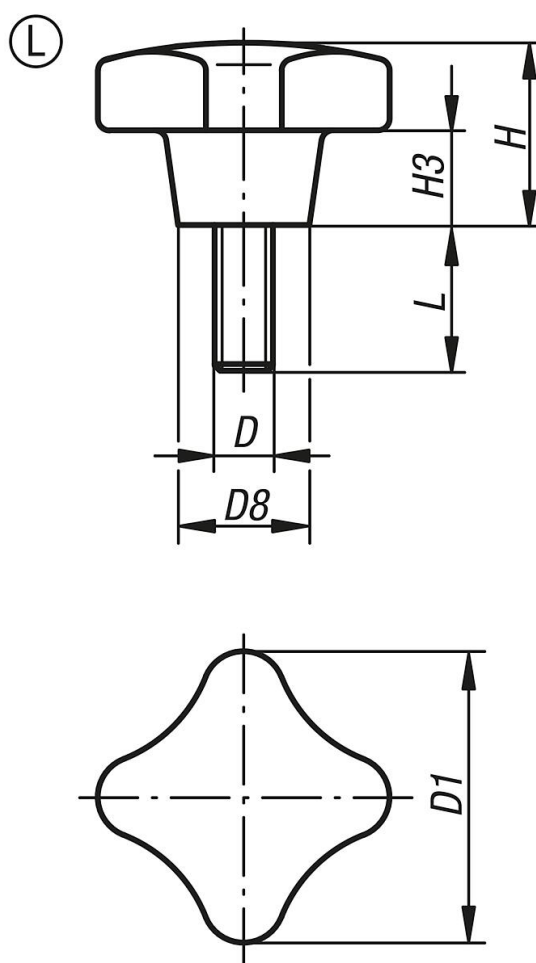

Обзор изделий

Номер заказа	Форма	D	D1	D8	H	H3	L
K0148.505X15	L	M5	25	12	15	6,5	15
K0148.505X20	L	M5	25	12	15	6,5	20
K0148.505X25	L	M5	25	12	15	6,5	25
K0148.505X30	L	M5	25	12	15	6,5	30
K0148.505X40	L	M5	25	12	16	6,5	40
K0148.505X50	L	M5	25	12	16	6,5	50
K0148.506X15	L	M6	32	14	20	10	15
K0148.506X20	L	M6	32	14	20	10	20
K0148.506X25	L	M6	32	14	20	10	25

Рукоятки крестообразные согласно DIN 6335, форма L, с наружной резьбой

Обзор изделий

Номер заказа	Форма	D	D1	D8	H	H3	L
K0148.506X30	L	M6	32	14	20	10	30
K0148.506X40	L	M6	32	14	20	10	40
K0148.506X50	L	M6	32	14	20	10	50
K0148.508X20	L	M8	40	18	26	13	20
K0148.508X25	L	M8	40	18	26	13	25
K0148.508X30	L	M8	40	18	26	13	30
K0148.508X35	L	M8	40	18	26	13	35
K0148.508X40	L	M8	40	18	26	13	40
K0148.508X45	L	M8	40	18	26	13	45
K0148.508X50	L	M8	40	18	26	13	50
K0148.510X20	L	M10	50	22	33	20	20
K0148.510X25	L	M10	50	22	33	20	25
K0148.510X30	L	M10	50	22	33	20	30
K0148.510X35	L	M10	50	22	33	20	35
K0148.510X40	L	M10	50	22	33	20	40
K0148.510X45	L	M10	50	22	33	20	45
K0148.510X50	L	M10	50	22	33	20	50
K0148.512X20	L	M12	63	27	40	25	20
K0148.512X30	L	M12	63	27	40	25	30
K0148.512X40	L	M12	63	27	40	25	40
K0148.512X50	L	M12	63	27	40	25	50
K0148.512X60	L	M12	63	27	40	25	60