

Spherical knobs revolving

Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	colza yellow RAL 1021	


Description

Version:

Trivalent blue passivated steel or bright stainless steel.

Circlips electro zinc-plated, including stainless steel version.

Drawings

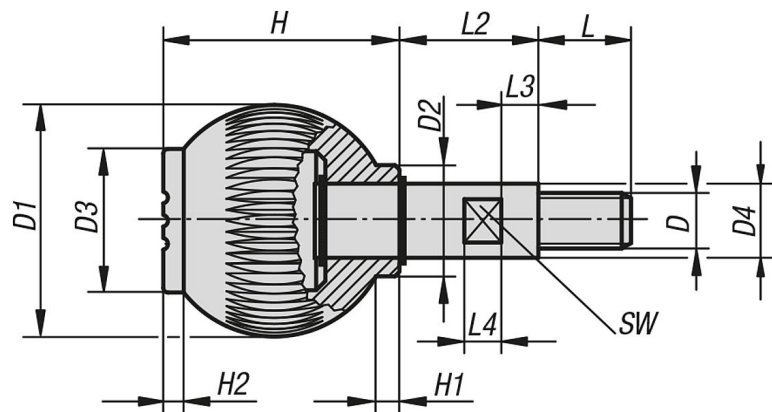

Overview of items

Spherical knobs revolving

Order No.	Component material	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	L	L2	L3	L4	SW
K0254.106	steel	black grey RAL 7021	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1061	steel	orange RAL 2004	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1062	steel	signal green RAL6032	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1063	steel	blue RAL5017	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1065	steel	light grey RAL 7035	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1066	steel	traffic red RAL 3020	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.1067	steel	colza yellow RAL 1021	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.208	steel	black grey RAL 7021	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.2081	steel	orange RAL 2004	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.2082	steel	signal green RAL6032	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.2083	steel	blue RAL5017	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.2085	steel	light grey RAL 7035	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8

Spherical knobs revolving

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	L	L2	L3	L4	SW
K0254.2086	steel	traffic red RAL 3020	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.2087	steel	colza yellow RAL 1021	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.310	steel	black grey RAL 7021	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3101	steel	orange RAL 2004	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3102	steel	signal green RAL6032	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3103	steel	blue RAL5017	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3105	steel	light grey RAL 7035	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3106	steel	traffic red RAL 3020	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.3107	steel	colza yellow RAL 1021	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.412	steel	black grey RAL 7021	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4121	steel	orange RAL 2004	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4122	steel	signal green RAL6032	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4123	steel	blue RAL5017	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4125	steel	light grey RAL 7035	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4126	steel	traffic red RAL 3020	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.4127	steel	colza yellow RAL 1021	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.0106	stainless steel	black grey RAL 7021	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01061	stainless steel	orange RAL 2004	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01062	stainless steel	signal green RAL6032	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01063	stainless steel	blue RAL5017	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01065	stainless steel	light grey RAL 7035	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01066	stainless steel	traffic red RAL 3020	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.01067	stainless steel	colza yellow RAL 1021	M6	25	12	17	8	25	3	2	10	15	5	5	7
K0254.0208	stainless steel	black grey RAL 7021	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02081	stainless steel	orange RAL 2004	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02082	stainless steel	signal green RAL6032	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02083	stainless steel	blue RAL5017	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02085	stainless steel	light grey RAL 7035	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02086	stainless steel	traffic red RAL 3020	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.02087	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	10	33	3,5	2,6	12	20	6	6	8
K0254.0310	stainless steel	black grey RAL 7021	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03101	stainless steel	orange RAL 2004	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03102	stainless steel	signal green RAL6032	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03103	stainless steel	blue RAL5017	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03105	stainless steel	light grey RAL 7035	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03106	stainless steel	traffic red RAL 3020	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.03107	stainless steel	colza yellow RAL 1021	M10	40	19	23	13	41	4	3	15	25	7	10	10
K0254.0412	stainless steel	black grey RAL 7021	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04121	stainless steel	orange RAL 2004	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04122	stainless steel	signal green RAL6032	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04123	stainless steel	blue RAL5017	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04125	stainless steel	light grey RAL 7035	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04126	stainless steel	traffic red RAL 3020	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13
K0254.04127	stainless steel	colza yellow RAL 1021	M12	50	24	31	16	51	5,5	4,5	20	30	8	8	13