


Spherical knobs

Item description/product images

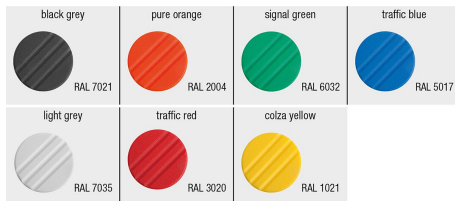

Description

Material:


Black thermoplastic.

Bush and screw 5.8 steel or 1.4305 stainless steel.

Version:

Steel trivalent blue passivated, stainless steel bright.

Drawings

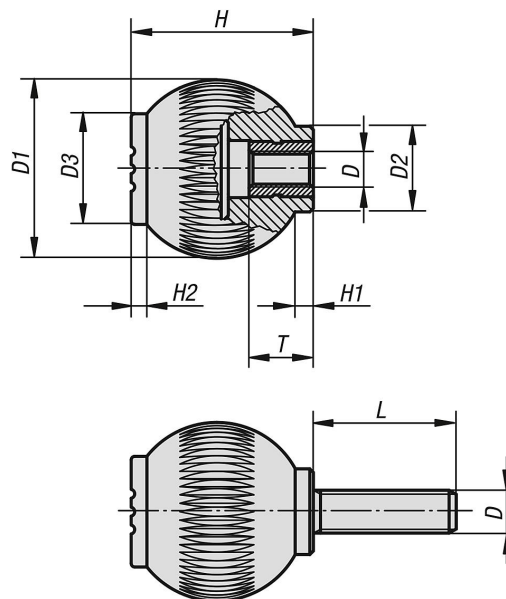

Overview of items

Spherical knobs

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.106	internal thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	-	10
K0253.1061	internal thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	-	10
K0253.1062	internal thread	steel	signal green RAL 6032	M6	25	12	17	25	3	2	-	10
K0253.1063	internal thread	steel	blue RAL5017	M6	25	12	17	25	3	2	-	10
K0253.1065	internal thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	-	10
K0253.1066	internal thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	-	10
K0253.1067	internal thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	-	10

Spherical knobs

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.208	internal thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2081	internal thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2082	internal thread	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2083	internal thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2085	internal thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2086	internal thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.2087	internal thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.310	internal thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	-	14
K0253.3101	internal thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	-	14
K0253.3102	internal thread	steel	signal green RAL 6032	M10	40	19	23	41	4	3	-	14
K0253.3103	internal thread	steel	blue RAL5017	M10	40	19	23	41	4	3	-	14
K0253.3105	internal thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	-	14
K0253.3106	internal thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	-	14
K0253.3107	internal thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	-	14
K0253.410	internal thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	-	14
K0253.4101	internal thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	-	14
K0253.4102	internal thread	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	-	14
K0253.4103	internal thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	-	14
K0253.4105	internal thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	-	14
K0253.4106	internal thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	-	14
K0253.4107	internal thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	-	14
K0253.412	internal thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	-	18
K0253.4121	internal thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	-	18
K0253.4122	internal thread	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	-	18
K0253.4123	internal thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	-	18
K0253.4125	internal thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	-	18
K0253.4126	internal thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	-	18
K0253.4127	internal thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	-	18
K0253.0106	internal thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	-	10
K0253.01061	internal thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	-	10
K0253.01062	internal thread	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	-	10
K0253.01063	internal thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	-	10
K0253.01065	internal thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	-	10
K0253.01066	internal thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	-	10
K0253.01067	internal thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	-	10
K0253.0208	internal thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02081	internal thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02082	internal thread	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02083	internal thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02085	internal thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02086	internal thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.02087	internal thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	-	14
K0253.0310	internal thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	-	14
K0253.03101	internal thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	-	14
K0253.03102	internal thread	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	-	14
K0253.03103	internal thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	-	14
K0253.03105	internal thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	-	14
K0253.03106	internal thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	-	14
K0253.03107	internal thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	-	14
K0253.0410	internal thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	-	14
K0253.04101	internal thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	-	14
K0253.04102	internal thread	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	-	14
K0253.04103	internal thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	-	14
K0253.04105	internal thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	-	14
K0253.04106	internal thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	-	14
K0253.04107	internal thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	-	14
K0253.0412	internal thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	-	18
K0253.04121	internal thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	-	18
K0253.04122	internal thread	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	-	18
K0253.04123	internal thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	-	18
K0253.04125	internal thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	-	18
K0253.04126	internal thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	-	18

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.04127	internal thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	-	18
K0253.106X15	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	15	-
K0253.1061X15	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	15	-
K0253.1062X15	external thread	steel	signal green RAL 6032	M6	25	12	17	25	3	2	15	-
K0253.1063X15	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	15	-
K0253.1065X15	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	15	10
K0253.1066X15	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15	10
K0253.1067X15	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15	10
K0253.106X20	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	20	-
K0253.1061X20	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	20	-
K0253.1062X20	external thread	steel	signal green RAL 6032	M6	25	12	17	25	3	2	20	-
K0253.1063X20	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	20	-
K0253.1065X20	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	20	10
K0253.1066X20	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20	10
K0253.1067X20	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20	10
K0253.106X25	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	25	-
K0253.1061X25	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	25	-
K0253.1062X25	external thread	steel	signal green RAL 6032	M6	25	12	17	25	3	2	25	-
K0253.1063X25	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	25	-
K0253.1065X25	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	25	10
K0253.1066X25	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25	10
K0253.1067X25	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25	10
K0253.106X30	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	30	-
K0253.1061X30	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	30	-
K0253.1062X30	external thread	steel	signal green RAL 6032	M6	25	12	17	25	3	2	30	-
K0253.1063X30	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	30	-
K0253.1065X30	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	30	10
K0253.1066X30	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30	10
K0253.1067X30	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30	10
K0253.208X20	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2081X20	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2082X20	external thread	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2083X20	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2085X20	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2086X20	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.2087X20	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.208X25	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2081X25	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2082X25	external thread	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2083X25	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2085X25	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2086X25	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.2087X25	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.208X30	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2081X30	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2082X30	external thread	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2083X30	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2085X30	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2086X30	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.2087X30	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.208X40	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2081X40	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2082X40	external thread	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2083X40	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2085X40	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2086X40	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.2087X40	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.310X20	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	20	-
K0253.3101X20	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	20	-
K0253.3102X20	external thread	steel	signal green RAL 6032	M10	40	19	23	41	4	3	20	-
K0253.3103X20	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	20	-
K0253.3105X20	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	20	14

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.3106X20	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20	14
K0253.3107X20	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20	14
K0253.310X30	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	30	-
K0253.3101X30	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	30	-
K0253.3102X30	external thread	steel	signal green RAL 6032	M10	40	19	23	41	4	3	30	-
K0253.3103X30	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	30	-
K0253.3105X30	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	30	14
K0253.3106X30	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30	14
K0253.3107X30	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30	14
K0253.310X40	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	40	-
K0253.3101X40	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	40	-
K0253.3102X40	external thread	steel	signal green RAL 6032	M10	40	19	23	41	4	3	40	-
K0253.3103X40	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	40	-
K0253.3105X40	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	40	14
K0253.3106X40	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40	14
K0253.3107X40	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40	14
K0253.410X20	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20	-
K0253.4101X20	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20	-
K0253.4102X20	external thread	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	20	-
K0253.4103X20	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20	-
K0253.4105X20	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20	14
K0253.4106X20	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20	14
K0253.4107X20	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20	14
K0253.410X30	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30	-
K0253.4101X30	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30	-
K0253.4102X30	external thread	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	30	-
K0253.4103X30	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30	-
K0253.4105X30	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30	14
K0253.4106X30	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30	14
K0253.4107X30	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30	14
K0253.410X40	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40	-
K0253.4101X40	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40	-
K0253.4102X40	external thread	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	40	-
K0253.4103X40	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40	-
K0253.4105X40	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40	14
K0253.4106X40	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40	14
K0253.4107X40	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40	14
K0253.412X20	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20	-
K0253.4121X20	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20	-
K0253.4122X20	external thread	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	20	-
K0253.4123X20	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20	-
K0253.4125X20	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20	18
K0253.4126X20	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20	18
K0253.4127X20	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20	18
K0253.412X30	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30	-
K0253.4121X30	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30	-
K0253.4122X30	external thread	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	30	-
K0253.4123X30	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30	-
K0253.4125X30	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30	18
K0253.4126X30	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30	18
K0253.4127X30	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30	18
K0253.412X40	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40	-
K0253.4121X40	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40	-
K0253.4122X40	external thread	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	40	-
K0253.4123X40	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40	-
K0253.4125X40	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40	18
K0253.4126X40	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40	18
K0253.4127X40	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40	18
K0253.0106X15	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	15	-
K0253.01061X15	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	15	-
K0253.01062X15	external thread	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	15	-
K0253.01063X15	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	15	-

Spherical knobs

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.01065X15	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	15	10
K0253.01066X15	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15	10
K0253.01067X15	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15	10
K0253.0106X20	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	20	-
K0253.01061X20	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	20	-
K0253.01062X20	external thread	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	20	-
K0253.01063X20	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	20	-
K0253.01065X20	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	20	10
K0253.01066X20	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20	10
K0253.01067X20	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20	10
K0253.0106X25	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	25	-
K0253.01061X25	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	25	-
K0253.01062X25	external thread	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	25	-
K0253.01063X25	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	25	-
K0253.01065X25	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	25	10
K0253.01066X25	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25	10
K0253.01067X25	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25	10
K0253.0106X30	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	30	-
K0253.01061X30	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	30	-
K0253.01062X30	external thread	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	30	-
K0253.01063X30	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	30	-
K0253.01065X30	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	30	10
K0253.01066X30	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30	10
K0253.01067X30	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30	10
K0253.0208X20	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02081X20	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02082X20	external thread	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02083X20	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02085X20	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02086X20	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.02087X20	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20	-
K0253.0208X25	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02081X25	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02082X25	external thread	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02083X25	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02085X25	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02086X25	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.02087X25	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25	-
K0253.0208X30	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02081X30	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02082X30	external thread	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02083X30	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02085X30	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02086X30	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.02087X30	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30	-
K0253.0208X40	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02081X40	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02082X40	external thread	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02083X40	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02085X40	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02086X40	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.02087X40	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40	-
K0253.0310X20	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	20	-
K0253.03101X20	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	20	-
K0253.03102X20	external thread	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	20	-
K0253.03103X20	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	20	-
K0253.03105X20	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	20	14
K0253.03106X20	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20	14
K0253.03107X20	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20	14
K0253.0310X30	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	30	-
K0253.03101X30	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	30	-
K0253.03102X30	external thread	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	30	-

Spherical knobs

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
K0253.03103X30	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	30	-
K0253.03105X30	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	30	14
K0253.03106X30	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30	14
K0253.03107X30	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30	14
K0253.0310X40	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	40	-
K0253.03101X40	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	40	-
K0253.03102X40	external thread	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	40	-
K0253.03103X40	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	40	-
K0253.03105X40	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	40	14
K0253.03106X40	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40	14
K0253.03107X40	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40	14
K0253.0410X20	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20	-
K0253.04101X20	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20	-
K0253.04102X20	external thread	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	20	-
K0253.04103X20	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20	-
K0253.04105X20	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20	14
K0253.04106X20	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20	14
K0253.04107X20	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20	14
K0253.0410X30	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30	-
K0253.04101X30	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30	-
K0253.04102X30	external thread	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	30	-
K0253.04103X30	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30	-
K0253.04105X30	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30	14
K0253.04106X30	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30	14
K0253.04107X30	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30	14
K0253.0410X40	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40	-
K0253.04101X40	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40	-
K0253.04102X40	external thread	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	40	-
K0253.04103X40	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40	-
K0253.04105X40	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40	14
K0253.04106X40	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40	14
K0253.04107X40	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40	14
K0253.0412X20	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20	-
K0253.04121X20	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20	-
K0253.04122X20	external thread	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	20	-
K0253.04123X20	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20	-
K0253.04125X20	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20	18
K0253.04126X20	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20	18
K0253.04127X20	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20	18
K0253.0412X30	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30	-
K0253.04121X30	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30	-
K0253.04122X30	external thread	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	30	-
K0253.04123X30	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30	-
K0253.04125X30	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30	18
K0253.04126X30	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30	18
K0253.04127X30	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30	18
K0253.0412X40	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40	-
K0253.04121X40	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40	-
K0253.04122X40	external thread	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	40	-
K0253.04123X40	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40	-
K0253.04125X40	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40	18
K0253.04126X40	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40	18
K0253.04127X40	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40	18