

## Quarter-turn locks, stainless steel with T-grip

### Item description/product images



### Description

**Material:**

Stainless steel 1.4401.

**Version:**

Bright.

Grip polished.

**Note:**

Quarter-turn lock with T-grip. For right or left mounting with 90° closing. The quarter-turn lock can be installed pre-assembled. Supplied with standard stainless-steel nut. The lockable quarter-turn locks are each supplied with 2 keys. Rating IP65.

Please order required tongue version separately. Every tongue can be combined with this housing.

The locks have a single key system, i.e. they can all be opened using the same key (cylinder lock 1333).

\*Dimension A results from the combination of the quarter turn lock and the tongue and is specified with the matching tongues.

**On request:**

Available for door thickness 20 and 40 mm.


**Accessory:**

Key for quarter-turn lock K1511.

Tongue for stainless steel quarter-turn lock K1340.

**Quarter-turn locks, stainless steel with T-grip**

**Drawings**

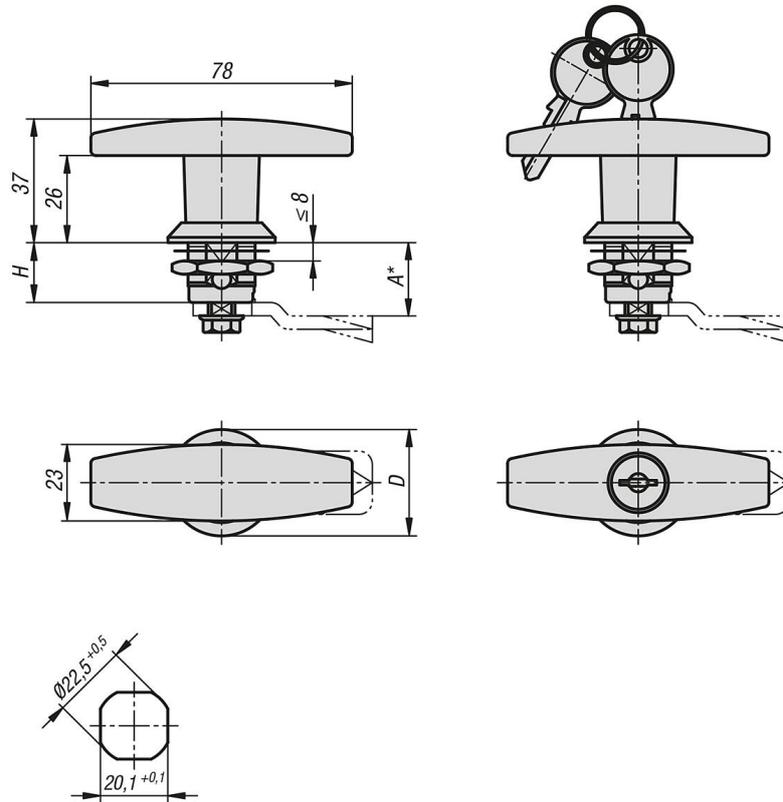

**Overview of items**

**Quarter-turn locks, stainless steel with T-grip**

Order No.	Actuation	D	H
K1356.1186	T-Grip	32	18
K1356.2186	lockable T-grip	32	18