


## Knurled knobs with grip

### Item description/product images

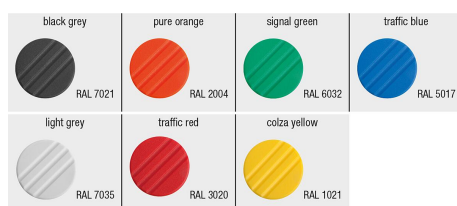

### Description

#### Material:

Black thermoplastic.  
Bush grade 5.8 steel.


#### Version:

Steel trivalent blue-passivated.

#### Drawing reference:

Form H: without locking grub screw  
Form M: with locking grub screw

### Drawings

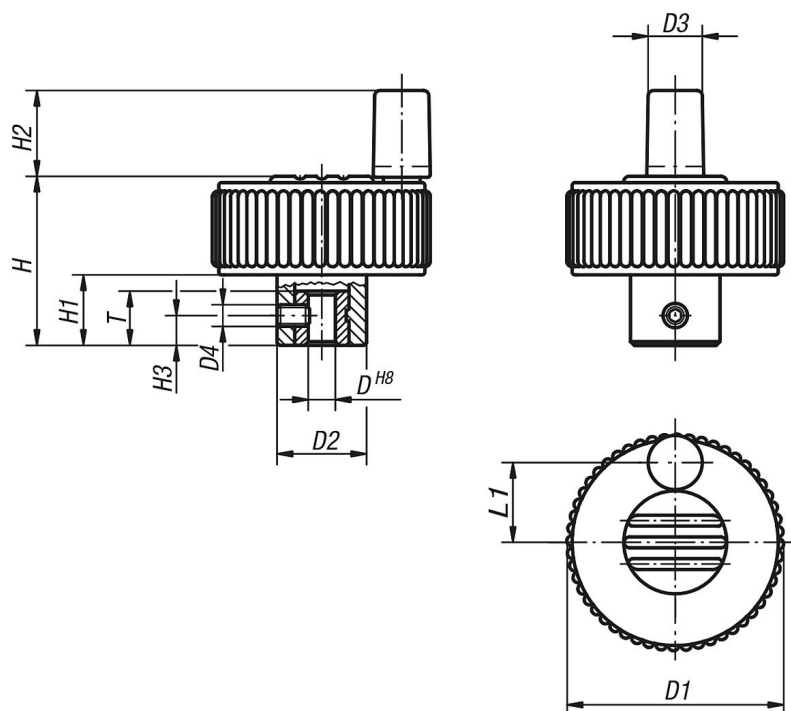

### Overview of items

#### Knurled knobs with grip

| Order No.   | Form | Colour Cap          | D   | D1 | D2   | D3 | D4 | H  | H1 | H2 | H3 | L1 | T  |
|-------------|------|---------------------|-----|----|------|----|----|----|----|----|----|----|----|
| K0262.2106  | H    | black grey RAL 7021 | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -  | 15 | 10 |
| K0262.21061 | H    | orange RAL 2004     | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -  | 15 | 10 |

## Knurled knobs with grip

### Overview of items

| Order No.   | Form | Colour<br>Cap         | D   | D1 | D2   | D3 | D4 | H  | H1 | H2 | H3  | L1   | T  |
|-------------|------|-----------------------|-----|----|------|----|----|----|----|----|-----|------|----|
| K0262.21062 | H    | signal green RAL6032  | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -   | 15   | 10 |
| K0262.21063 | H    | blue RAL5017          | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -   | 15   | 10 |
| K0262.21065 | H    | light grey RAL 7035   | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -   | 15   | 10 |
| K0262.21066 | H    | traffic red RAL 3020  | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -   | 15   | 10 |
| K0262.21067 | H    | colza yellow RAL 1021 | 6H8 | 40 | 16,5 | 10 | -  | 31 | 13 | 16 | -   | 15   | 10 |
| K0262.2206  | H    | black grey RAL 7021   | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22061 | H    | orange RAL 2004       | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22062 | H    | signal green RAL6032  | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22063 | H    | blue RAL5017          | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22065 | H    | light grey RAL 7035   | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22066 | H    | traffic red RAL 3020  | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.22067 | H    | colza yellow RAL 1021 | 6H8 | 50 | 18   | 10 | -  | 36 | 15 | 16 | -   | 18,5 | 10 |
| K0262.2308  | H    | black grey RAL 7021   | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23081 | H    | orange RAL 2004       | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23082 | H    | signal green RAL6032  | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23083 | H    | blue RAL5017          | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23085 | H    | light grey RAL 7035   | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23086 | H    | traffic red RAL 3020  | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.23087 | H    | colza yellow RAL 1021 | 8H8 | 63 | 22   | 10 | -  | 41 | 17 | 16 | -   | 25   | 14 |
| K0262.1106  | M    | black grey RAL 7021   | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11061 | M    | orange RAL 2004       | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11062 | M    | signal green RAL6032  | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11063 | M    | blue RAL5017          | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11065 | M    | light grey RAL 7035   | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11066 | M    | traffic red RAL 3020  | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.11067 | M    | colza yellow RAL 1021 | 6H8 | 40 | 16,5 | 10 | M4 | 31 | 13 | 16 | 5,5 | 15   | 10 |
| K0262.1206  | M    | black grey RAL 7021   | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12061 | M    | orange RAL 2004       | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12062 | M    | signal green RAL6032  | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12063 | M    | blue RAL5017          | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12065 | M    | light grey RAL 7035   | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12066 | M    | traffic red RAL 3020  | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.12067 | M    | colza yellow RAL 1021 | 6H8 | 50 | 18   | 10 | M4 | 36 | 15 | 16 | 5,5 | 18,5 | 10 |
| K0262.1308  | M    | black grey RAL 7021   | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13081 | M    | orange RAL 2004       | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13082 | M    | signal green RAL6032  | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13083 | M    | blue RAL5017          | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13085 | M    | light grey RAL 7035   | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13086 | M    | traffic red RAL 3020  | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |
| K0262.13087 | M    | colza yellow RAL 1021 | 8H8 | 63 | 22   | 10 | M4 | 41 | 17 | 16 | 8   | 25   | 14 |