

Cable grommet EPDM

Item description/product images



Description

Material:
EPDM.

Version:
black.


Note:

Grommets are used for cable routing in control cabinets, housings and fuse boxes. They permit the problem-free routing of cables through outlets and openings. They are easy to apply and offer protection against sharp edges. Additionally, the use of cable grommets provides a certain amount of strain relief on the cables.

EPDM has very good ageing resistance, even when exposed to UV and ozone (e.g. outdoors). Other positive properties of EPDM are its high elasticity and good chemical resistance. EPDM is resistant to oxygen and diluted acids, but not to mineral oil products.

Temperature range:
-40°C to +125°C.

Drawings

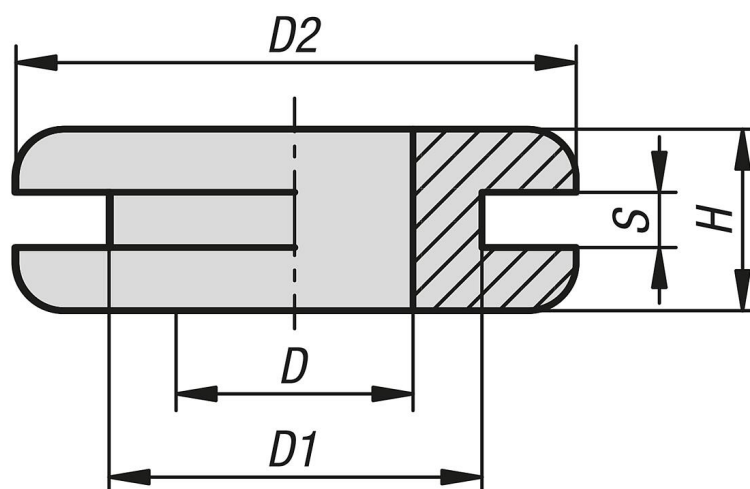

Overview of items

Cable grommet EPDM

Order No.	D	Assembly dimensions D1	D2	H	S
K2255.02005010	2	5	8	4	1
K2255.02005015	2	5	8	4,5	1,5
K2255.02005020	2	5	8	5	2
K2255.03005010	3	5	8	4	1
K2255.03005015	3	5	8	4,5	1,5
K2255.03005020	3	5	8	5	2
K2255.03007015	3	7	10	6,1	1,5

Cable grommet EPDM

Overview of items

Order No.	D	Assembly dimensions D1	D2	H	S
K2255.04008010	4	8	11	5	1
K2255.04008020	4	8	11	6	2
K2255.04008030	4	8	11	7	3
K2255.06008010	6	8	11	5	1
K2255.06008020	6	8	11	6	2
K2255.06009010	6	9	12	5	1
K2255.06009015	6	9	12	5,5	1,5
K2255.06009020	6	9	12	6	2
K2255.06009030	6	9	12	7	3
K2255.06009040	6	9	12	8	4
K2255.06010010	6	10	14	6	1
K2255.06010015	6	10	14	6,5	1,5
K2255.06010020	6	10	14	7	2
K2255.06010030	6	10	14	8	3
K2255.08010010	8	10	14	6	1
K2255.08010015	8	10	14	6,5	1,5
K2255.08010020	8	10	14	7	2
K2255.08010030	8	10	14	8	3
K2255.08011010	8	11	16	6	1
K2255.08011020	8	11	16	7	2
K2255.08011030	8	11	16	8	3
K2255.08011040	8	11	16	9	4
K2255.08012010	8	12	16	6	1
K2255.08012020	8	12	16	7	2
K2255.08012030	8	12	16	8	3
K2255.08012040	8	12	16	9	4
K2255.10012010	10	12	16	6	1
K2255.10012015	10	12	16	6,5	1,5
K2255.10012020	10	12	16	7	2
K2255.10012030	10	12	16	8	3
K2255.11014010	11	14	18	6	1
K2255.11014020	11	14	18	7	2
K2255.11014030	11	14	18	8	3
K2255.11015010	11	15	20	6	1
K2255.11015020	11	15	20	7	2
K2255.11015030	11	15	20	8	3
K2255.11015040	11	15	20	9	4
K2255.12018010	12	18	22	6	1
K2255.12018020	12	18	22	7	2
K2255.12018030	12	18	22	8	3
K2255.12018040	12	18	22	9	4
K2255.16022010	16	22	27	7	1
K2255.16022015	16	22	27	7,5	1,5
K2255.16022020	16	22	27	8	2
K2255.16022030	16	22	27	9	3
K2255.16022040	16	22	27	10	4
K2255.21027010	21	27	34	9	1
K2255.21027020	21	27	34	10	2
K2255.21027030	21	27	34	11	3
K2255.21027040	21	27	34	12	4
K2255.31040010	31	40	48	12	1
K2255.31040020	31	40	48	13	2
K2255.31040030	31	40	48	14	3
K2255.31040040	31	40	48	15	4
K2255.41052010	41	52	60	13	1
K2255.41052020	41	52	60	14	2
K2255.41052030	41	52	60	15	3
K2255.41052040	41	52	60	16	4

