

## Clamping levers, die-cast zinc, flat with internal thread, threaded insert black oxidised steel

Item description/product images



lift to  
disengage



### Description

#### Material:

Handle die-cast zinc DIN EN 12844.

Steel parts grade 5.8.

#### Version:

Handle powder-coated.


Steel parts black oxidised.

#### On request:

Other threads, colours and special versions.

Dimension "H1" available in other lengths at extra charge.

### Drawings

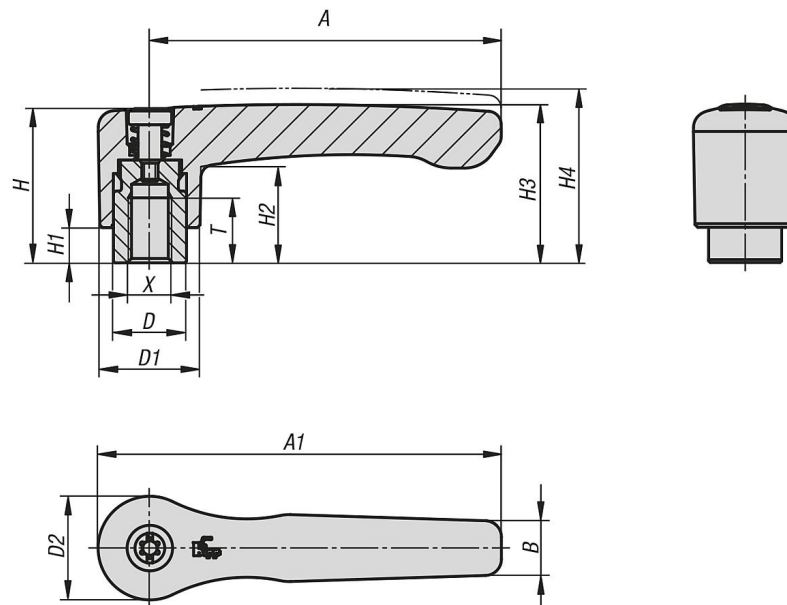

### Overview of items

### Clamping levers, flat with internal thread

# Clamping levers, die-cast zinc, flat with internal thread, threaded insert black oxidised steel

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
<b>K0737.2061</b>	jet black RAL 9005	satin finish	2	M6	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.2081</b>	jet black RAL 9005	satin finish	2	M8	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.3081</b>	jet black RAL 9005	satin finish	3	M8	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.3101</b>	jet black RAL 9005	satin finish	3	M10	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.206181</b>	jet black RAL 9005	textured matt	2	M6	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.208181</b>	jet black RAL 9005	textured matt	2	M8	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.308181</b>	jet black RAL 9005	textured matt	3	M8	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.310181</b>	jet black RAL 9005	textured matt	3	M10	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.206182</b>	orange RAL 2004	textured matt	2	M6	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.208182</b>	orange RAL 2004	textured matt	2	M8	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.308182</b>	orange RAL 2004	textured matt	3	M8	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.310182</b>	orange RAL 2004	textured matt	3	M10	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.206184</b>	traffic red RAL 3020	textured matt	2	M6	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.208184</b>	traffic red RAL 3020	textured matt	2	M8	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
<b>K0737.308184</b>	traffic red RAL 3020	textured matt	3	M8	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
<b>K0737.310184</b>	traffic red RAL 3020	textured matt	3	M10	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22