

Clamping levers, die-cast zinc, flat with external thread, threaded pin stainless steel

Item description/product images



lift to
disengage



Description

Material:

Handle die-cast zinc DIN EN 12844.

Steel parts stainless steel 1.4305.

Version:

Handle powder-coated.

Stainless steel parts bright.

Note:

Where $L \geq 60$ mm the thread length is always 60 mm.

On request:

Other threads, screw lengths, colours and special versions.


Dimension "H1" available in other lengths at extra charge.

Drawing reference:

1) flat point DIN EN ISO 4753

Clamping levers, die-cast zinc, flat with external thread, threaded pin stainless steel

Drawings

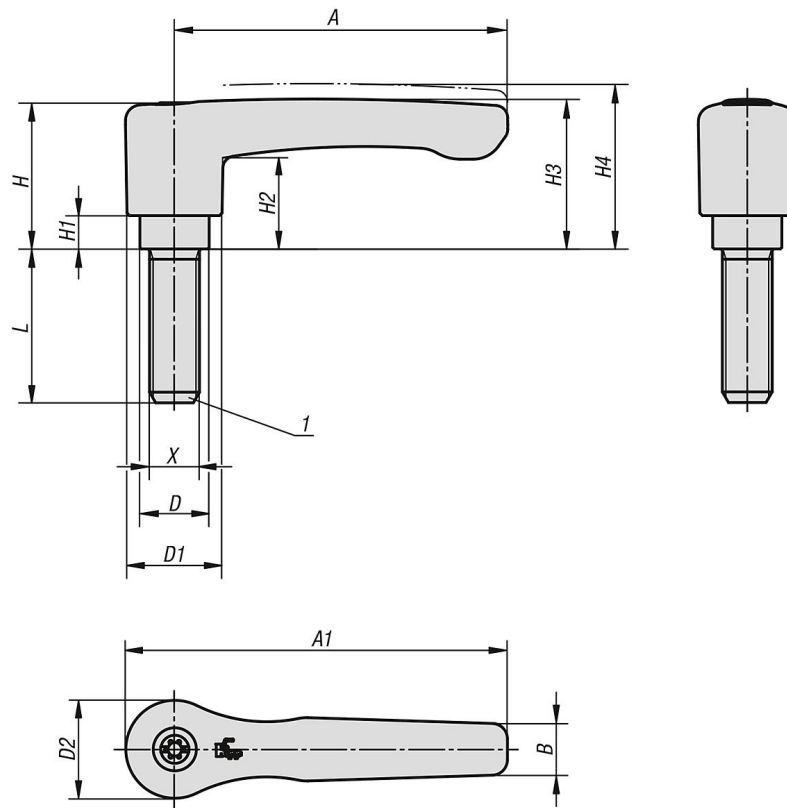

Overview of items

Clamping levers, flat with external thread, stainless steel

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0738.2061X15	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.2061X20	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.2061X25	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.2061X30	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.2061X40	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.2061X50	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.2061X60	jet black RAL 9005	satin finish	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.2081X15	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.2081X20	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.2081X25	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.2081X30	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.2081X40	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.2081X50	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.2081X60	jet black RAL 9005	satin finish	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.2101X20	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.2101X25	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.2101X30	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.2101X40	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.2101X50	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.2101X60	jet black RAL 9005	satin finish	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.3081X20	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.3081X25	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.3081X30	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.3081X40	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.3081X50	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.3081X60	jet black RAL 9005	satin finish	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60

Clamping levers, die-cast zinc, flat with external thread, threaded pin stainless steel

Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0738.3101X20	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.3101X25	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.3101X30	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.3101X40	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.3101X50	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.3101X60	jet black RAL 9005	satin finish	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.206181X15	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.206181X20	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.206181X25	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.206181X30	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.206181X40	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.206181X50	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.206181X60	jet black RAL 9005	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.208181X15	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.208181X20	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.208181X25	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.208181X30	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.208181X40	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.208181X50	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.208181X60	jet black RAL 9005	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.210181X20	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.210181X25	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.210181X30	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.210181X40	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.210181X50	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.210181X60	jet black RAL 9005	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.308181X20	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.308181X25	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.308181X30	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.308181X40	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.308181X50	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.308181X60	jet black RAL 9005	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.310181X20	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.310181X25	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.310181X30	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.310181X40	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.310181X50	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.310181X60	jet black RAL 9005	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.206182X15	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.206182X20	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.206182X25	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.206182X30	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.206182X40	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.206182X50	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.206182X60	orange RAL 2004	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.208182X15	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.208182X20	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.208182X25	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.208182X30	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.208182X40	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.208182X50	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.208182X60	orange RAL 2004	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.210182X20	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.210182X25	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.210182X30	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.210182X40	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.210182X50	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.210182X60	orange RAL 2004	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.308182X20	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.308182X25	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.308182X30	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.308182X40	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40

Clamping levers, die-cast zinc, flat with external thread, threaded pin stainless steel

Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
K0738.308182X50	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.308182X60	orange RAL 2004	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.310182X20	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.310182X25	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.310182X30	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.310182X40	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.310182X50	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.310182X60	orange RAL 2004	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.206184X15	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.206184X20	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.206184X25	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.206184X30	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.206184X40	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.206184X50	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.206184X60	traffic red RAL 3020	textured matt	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.208184X15	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
K0738.208184X20	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.208184X25	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.208184X30	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.208184X40	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.208184X50	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.208184X60	traffic red RAL 3020	textured matt	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.210184X20	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
K0738.210184X25	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
K0738.210184X30	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
K0738.210184X40	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
K0738.210184X50	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
K0738.210184X60	traffic red RAL 3020	textured matt	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
K0738.308184X20	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.308184X25	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.308184X30	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.308184X40	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.308184X50	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.308184X60	traffic red RAL 3020	textured matt	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
K0738.310184X20	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
K0738.310184X25	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
K0738.310184X30	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
K0738.310184X40	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
K0738.310184X50	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
K0738.310184X60	traffic red RAL 3020	textured matt	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60