


Hexagon nuts DIN 934, stainless steel

Item description/product images

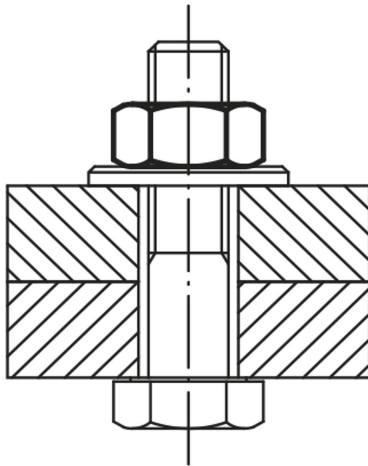

Description

Material:

Stainless steel A2 or stainless steel A4.

Version:


Stainless steel A2-70, bright.

Stainless steel A4-70, bright.

On request:

DIN ISO 272 spanner sizes.

Drawings

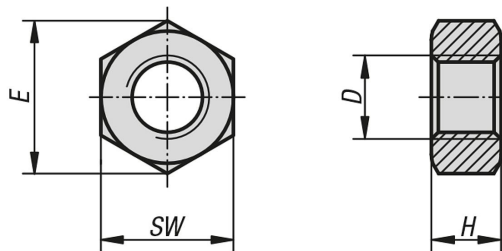

Overview of items

Order No.	Main material	Grade	D	E	H	SW	DIN
K1145.1025	stainless steel A2	70	M2,5	5,45	2	5	DIN 934
K1145.103	stainless steel A2	70	M3	6,01	2,4	5,5	DIN 934
K1145.104	stainless steel A2	70	M4	7,66	3,2	7	DIN 934
K1145.105	stainless steel A2	70	M5	8,79	4	8	DIN 934
K1145.106	stainless steel A2	70	M6	11,05	5	10	DIN 934
K1145.108	stainless steel A2	70	M8	14,38	6,5	13	DIN 934
K1145.110	stainless steel A2	70	M10	18,9	8	17	DIN 934

Hexagon nuts DIN 934, stainless steel

Overview of items

Order No.	Main material	Grade	D	E	H	SW	DIN
K1145.112	stainless steel A2	70	M12	21,1	10	19	DIN 934
K1145.116	stainless steel A2	70	M16	26,76	13	24	DIN 934
K1145.120	stainless steel A2	70	M20	32,95	16	30	DIN 934
K1145.130	stainless steel A2	70	M30	50,9	24	46	DIN 934
K1145.136	stainless steel A2	70	M36	60,8	29	55	DIN 934
K1145.114	stainless steel A2	70	M14	23,9	11	22	DIN 934
K1145.122	stainless steel A2	70	M22	35	18	32	DIN 934
K1145.124	stainless steel A2	70	M24	39,6	19	36	DIN 934
K1145.127	stainless steel A2	70	M27	45,2	22	41	DIN 934
K1145.133	stainless steel A2	70	M33	55,4	26	50	DIN 934
K1145.5025	stainless steel A4	70	M2,5	5,45	2	5	DIN 934
K1145.603	stainless steel A4	70	M3	6,01	2,4	5,5	DIN 934
K1145.604	stainless steel A4	70	M4	7,66	3,2	7	DIN 934
K1145.605	stainless steel A4	70	M5	8,79	4	8	DIN 934
K1145.606	stainless steel A4	70	M6	11,05	5	10	DIN 934
K1145.608	stainless steel A4	70	M8	14,38	6,5	13	DIN 934
K1145.610	stainless steel A4	70	M10	18,9	8	17	DIN 934
K1145.612	stainless steel A4	70	M12	21,1	10	19	DIN 934
K1145.614	stainless steel A4	70	M14	23,9	11	22	DIN 934
K1145.616	stainless steel A4	70	M16	26,76	13	24	DIN 934
K1145.620	stainless steel A4	70	M20	32,95	16	30	DIN 934
K1145.622	stainless steel A4	70	M22	35	18	32	DIN 934
K1145.624	stainless steel A4	70	M24	39,6	19	36	DIN 934
K1145.627	stainless steel A4	70	M27	45,2	22	41	DIN 934
K1145.630	stainless steel A4	70	M30	50,9	24	46	DIN 934
K1145.633	stainless steel A4	70	M33	55,4	26	50	DIN 934
K1145.636	stainless steel A4	70	M36	60,8	29	55	DIN 934