

D-Shackles

Item description/product images



Description

Material:

Steel.

Version:


D form

Note:

Shackles and bolts may vary in colour.

Paint may cause the thread to be stiff.

Drawings

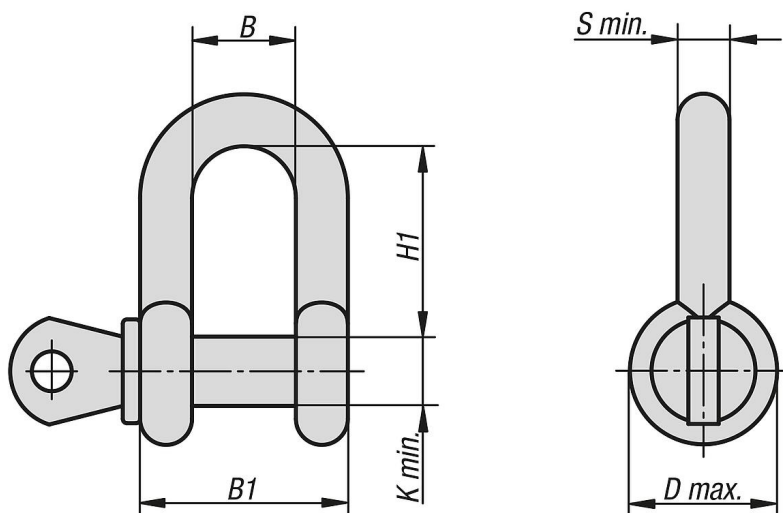

Overview of items

D-Shackles

Order No.	B	B1	D max.	S min.	K min.	H1	Inches	Permissible load kg
K1059.0050008	12	26	22	6	8	24,6	1/4	500
K1059.0075010	13,5	29	25,5	8	9,5	27,2	5/16	750
K1059.0100011	16,8	36	28,5	9,5	11	32,5	3/8	1000
K1059.0150012	19	40	31,5	11	12,5	37,6	7/16	1500
K1059.0200016	20,6	47	35	12,5	15,5	40,7	1/2	2000
K1059.0325019	27	59	47,5	15,5	19	50	5/8	3250
K1059.0475022	31,8	70	54	19	22	59,5	3/4	4750
K1059.0650025	36,6	80	60	22	25	71	7/8	6500
K1059.0850028	43	93	66,5	25	28,5	80,5	1	8500

