

## Magnets raw NdFeB, block form

### Item description/product images



### Description

**Material:**  
NdFeB N35 (neodymium).

**Version:**  
nickel-plated.


**Note:**  
Unshielded system.

**Temperature range:**  
max. 80°C.

**Assembly:**  
The magnets can be mounted by press-fit or gluing.

**Drawing reference:**  
1) magnetic face

### Drawings

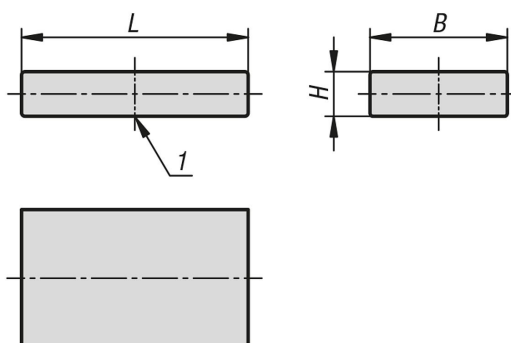

### Overview of items

#### Magnets raw, NdFeB, block form

| Order No.  | B         | H        | L        | Magnetic force N |
|------------|-----------|----------|----------|------------------|
| K1406.0704 | 4 ±0,1    | 1,5 ±0,1 | 7,5 ±0,1 | 5                |
| K1406.0706 | 6 ±0,1    | 2 ±0,1   | 7,5 ±0,1 | 8                |
| K1406.1007 | 7,5 ±0,1  | 2 ±0,1   | 10 ±0,1  | 11               |
| K1406.1209 | 9,5 ±0,1  | 2,5 ±0,1 | 12 ±0,1  | 17               |
| K1406.1612 | 12,5 ±0,1 | 2,5 ±0,1 | 16 ±0,1  | 24               |
| K1406.1816 | 16,5 ±0,1 | 4 ±0,1   | 18 ±0,1  | 50               |
| K1406.2620 | 20,3 ±0,1 | 5 ±0,1   | 26 ±0,1  | 77               |
| K1406.3326 | 26 ±0,1   | 6,5 ±0,1 | 33 ±0,1  | 125              |

