


Knurled knobs Form K, with tapped bush, with cap

Item description/product images

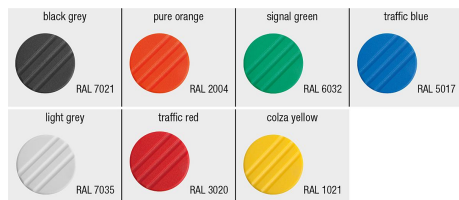


Description

Material:
Black thermoplastic.
Bush grade 5.8 steel.

Version:
Steel trivalent blue-passivated.

Drawings

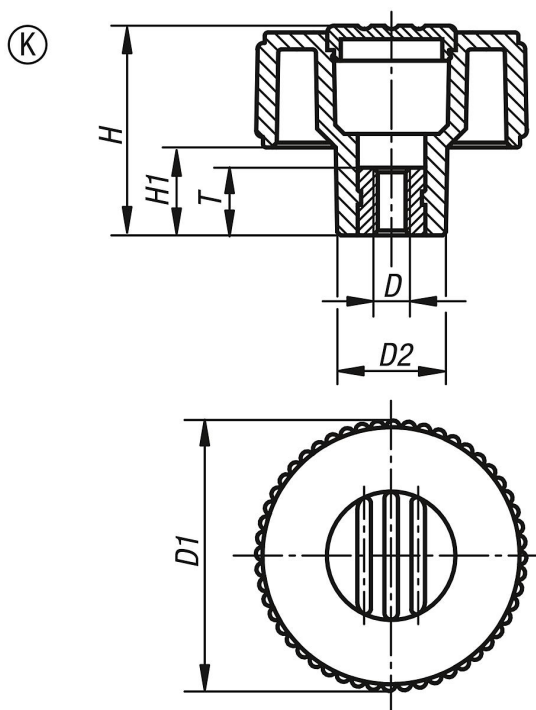

Overview of items

Knurled knobs Form K, with tapped bush, with cap

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T
K0260.2105	K	black grey RAL 7021	1	M5	40	16,5	31	13	10
K0260.21051	K	orange RAL 2004	1	M5	40	16,5	31	13	10
K0260.21052	K	signal green RAL6032	1	M5	40	16,5	31	13	10
K0260.21053	K	blue RAL5017	1	M5	40	16,5	31	13	10
K0260.21055	K	light grey RAL 7035	1	M5	40	16,5	31	13	10
K0260.21056	K	traffic red RAL 3020	1	M5	40	16,5	31	13	10
K0260.21057	K	colza yellow RAL 1021	1	M5	40	16,5	31	13	10
K0260.2106	K	black grey RAL 7021	1	M6	40	16,5	31	13	10
K0260.21061	K	orange RAL 2004	1	M6	40	16,5	31	13	10
K0260.21062	K	signal green RAL6032	1	M6	40	16,5	31	13	10
K0260.21063	K	blue RAL5017	1	M6	40	16,5	31	13	10

Knurled knobs Form K, with tapped bush, with cap

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T
K0260.21065	K	light grey RAL 7035	1	M6	40	16,5	31	13	10
K0260.21066	K	traffic red RAL 3020	1	M6	40	16,5	31	13	10
K0260.21067	K	colza yellow RAL 1021	1	M6	40	16,5	31	13	10
K0260.2108	K	black grey RAL 7021	1	M8	40	16,5	31	13	14
K0260.21081	K	orange RAL 2004	1	M8	40	16,5	31	13	14
K0260.21082	K	signal green RAL6032	1	M8	40	16,5	31	13	14
K0260.21083	K	blue RAL5017	1	M8	40	16,5	31	13	14
K0260.21085	K	light grey RAL 7035	1	M8	40	16,5	31	13	14
K0260.21086	K	traffic red RAL 3020	1	M8	40	16,5	31	13	14
K0260.21087	K	colza yellow RAL 1021	1	M8	40	16,5	31	13	14
K0260.2208	K	black grey RAL 7021	2	M8	50	18	36	15	14
K0260.22081	K	orange RAL 2004	2	M8	50	18	36	15	14
K0260.22082	K	signal green RAL6032	2	M8	50	18	36	15	14
K0260.22083	K	blue RAL5017	2	M8	50	18	36	15	14
K0260.22085	K	light grey RAL 7035	2	M8	50	18	36	15	14
K0260.22086	K	traffic red RAL 3020	2	M8	50	18	36	15	14
K0260.22087	K	colza yellow RAL 1021	2	M8	50	18	36	15	14
K0260.2210	K	black grey RAL 7021	2	M10	50	18	36	15	14
K0260.22101	K	orange RAL 2004	2	M10	50	18	36	15	14
K0260.22102	K	signal green RAL6032	2	M10	50	18	36	15	14
K0260.22103	K	blue RAL5017	2	M10	50	18	36	15	14
K0260.22105	K	light grey RAL 7035	2	M10	50	18	36	15	14
K0260.22106	K	traffic red RAL 3020	2	M10	50	18	36	15	14
K0260.22107	K	colza yellow RAL 1021	2	M10	50	18	36	15	14
K0260.2310	K	black grey RAL 7021	3	M10	63	22	41	17	14
K0260.23101	K	orange RAL 2004	3	M10	63	22	41	17	14
K0260.23102	K	signal green RAL6032	3	M10	63	22	41	17	14
K0260.23103	K	blue RAL5017	3	M10	63	22	41	17	14
K0260.23105	K	light grey RAL 7035	3	M10	63	22	41	17	14
K0260.23106	K	traffic red RAL 3020	3	M10	63	22	41	17	14
K0260.23107	K	colza yellow RAL 1021	3	M10	63	22	41	17	14
K0260.2312	K	black grey RAL 7021	3	M12	63	22	41	17	18
K0260.23121	K	orange RAL 2004	3	M12	63	22	41	17	18
K0260.23122	K	signal green RAL6032	3	M12	63	22	41	17	18
K0260.23123	K	blue RAL5017	3	M12	63	22	41	17	18
K0260.23125	K	light grey RAL 7035	3	M12	63	22	41	17	18
K0260.23126	K	traffic red RAL 3020	3	M12	63	22	41	17	18
K0260.23127	K	colza yellow RAL 1021	3	M12	63	22	41	17	18