

# Magnets with internal thread NdFeB, rectangular, with rubber protective jacket

Item description/product images



## Description

### Material:

Housing steel.

Magnetic core NdFeB (neodymium).

Rubber protective jacket TPE.

### Version:

Housing, electro zinc-plated.

Black protective rubber jacket.

### Note:

Magnet with internal thread. Shielded system. With rubber protective jacket for protecting sensitive surfaces. The coefficient of friction is increased by the rubber jacket so that high lateral friction is achieved.

### Temperature range:

max. 60°C.


### Assembly:

Optimum hold on thin plate with sensitive surfaces.

### Drawing reference:

1) magnetic face

## Drawings

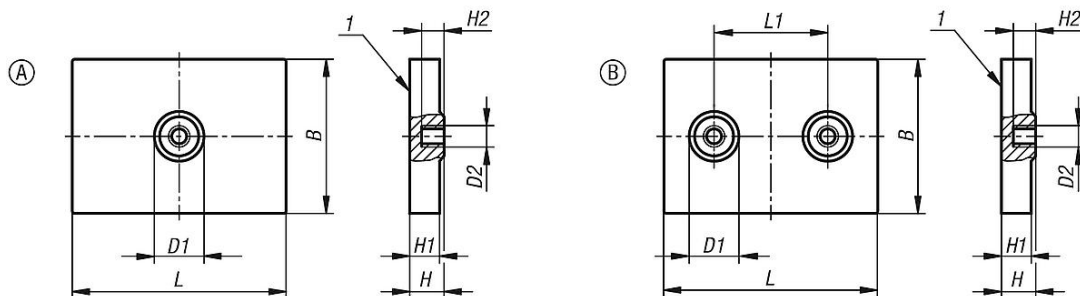

## Overview of items

### Magnets with internal thread, NdFeB, rectangular, with rubber protective jacket

Order No.	Form	B	D1	D2	H	H1	H2	L	L1	Magnetic force N
K1396.14331	A	31	10	M4	6,9	6	4,5	43	-	105
K1396.24331	B	31	10	M4	6,9	6	4,5	43	25	146