




Mounting instructions K2097

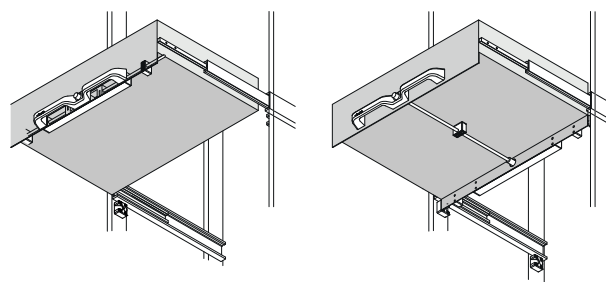


K2097.060
K2097.120

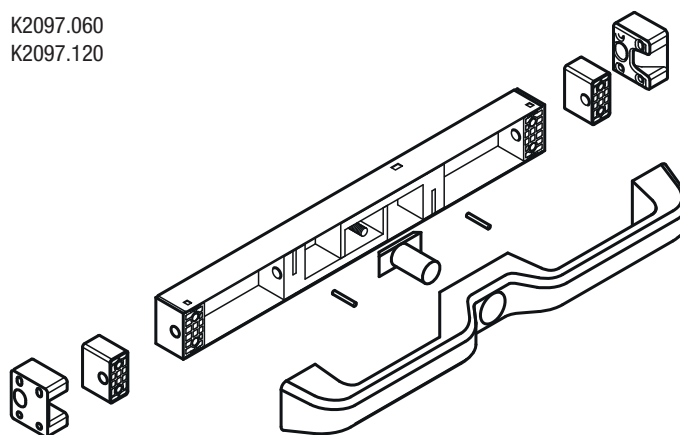


K2097.91

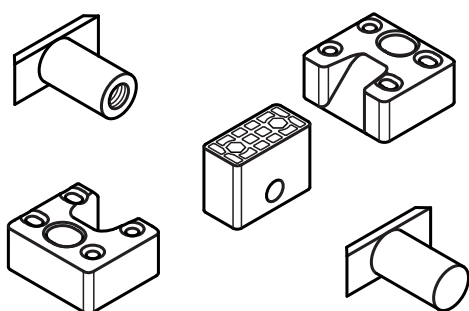


K2097.900500
K2097.900750
K2097.910500
K2097.910750



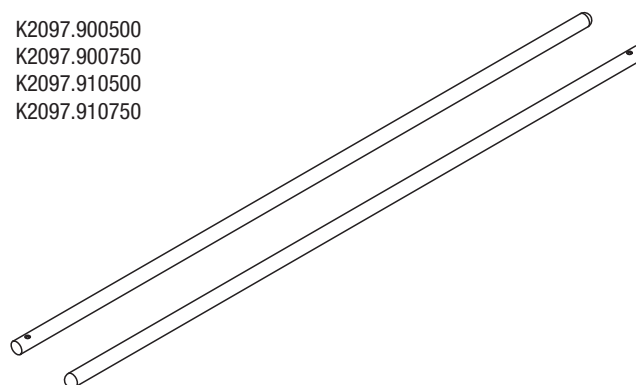




K2097.60 + K2097.900500 or K2097.910500
K2097.120 + K2097.900750 or K2097.910750


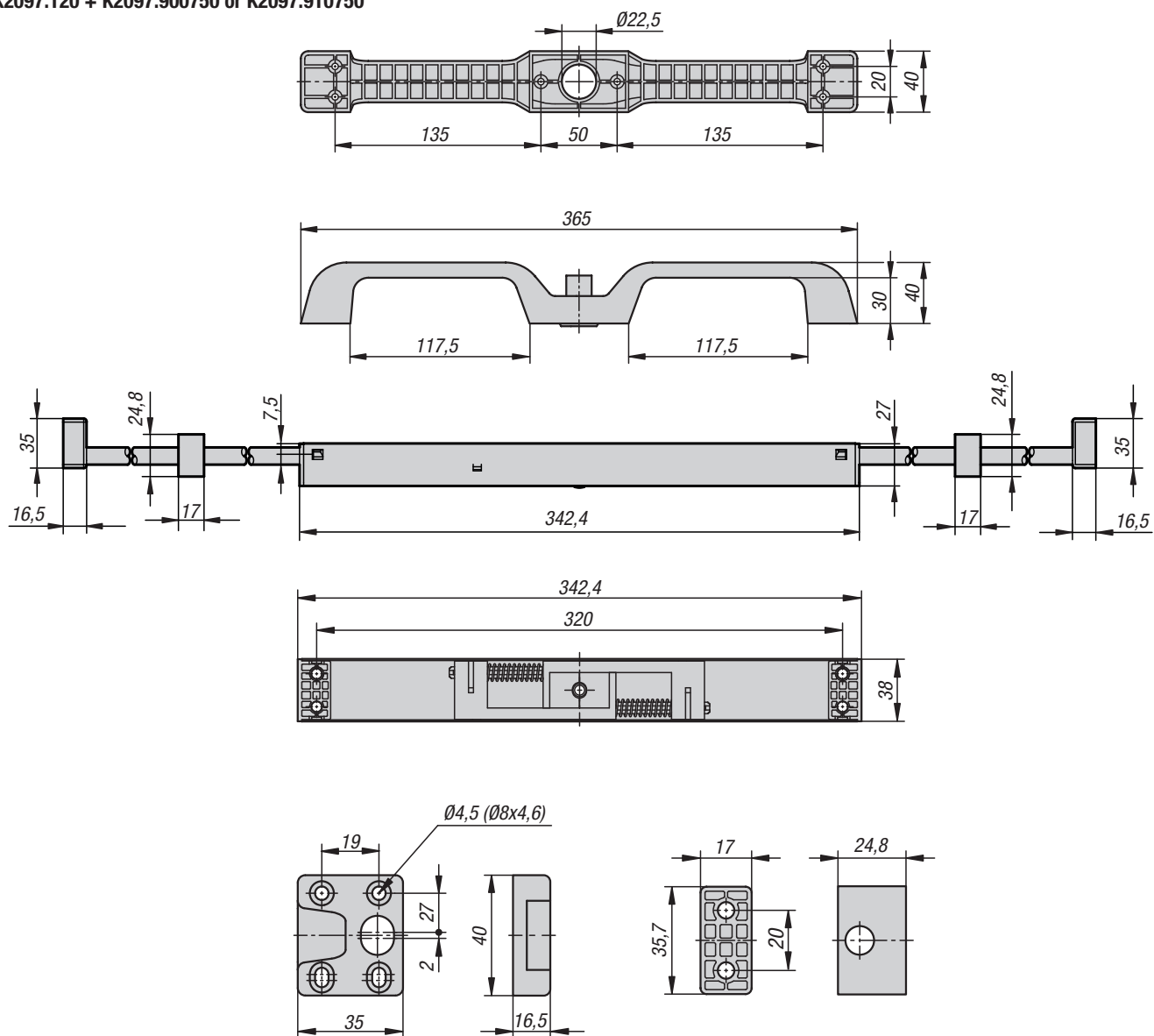


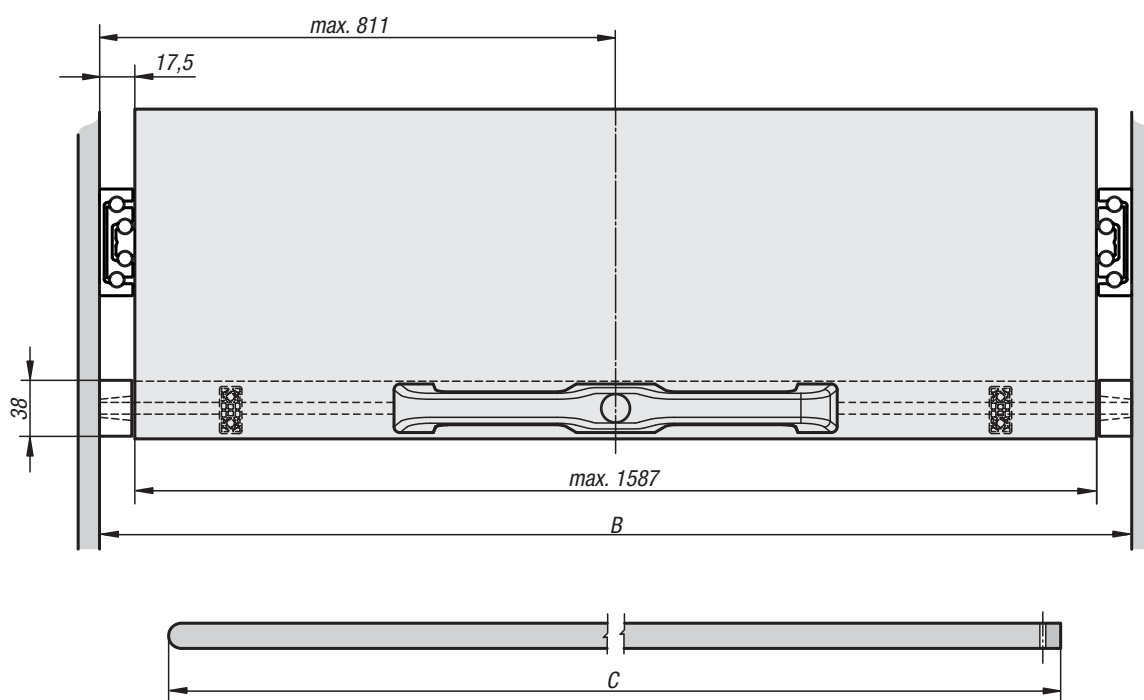

 $C = (B - 122,3) / 2$
 $C < 500$
 $C > 500$

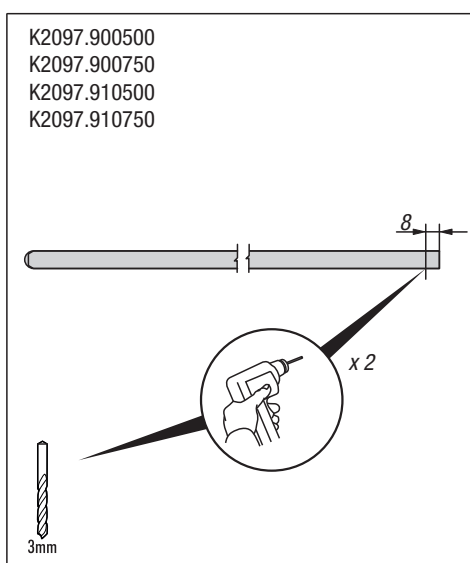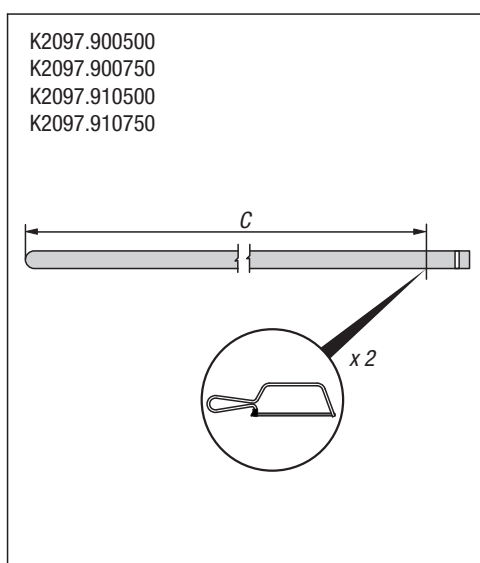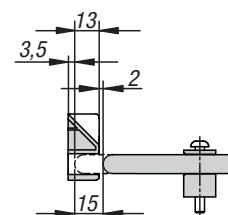

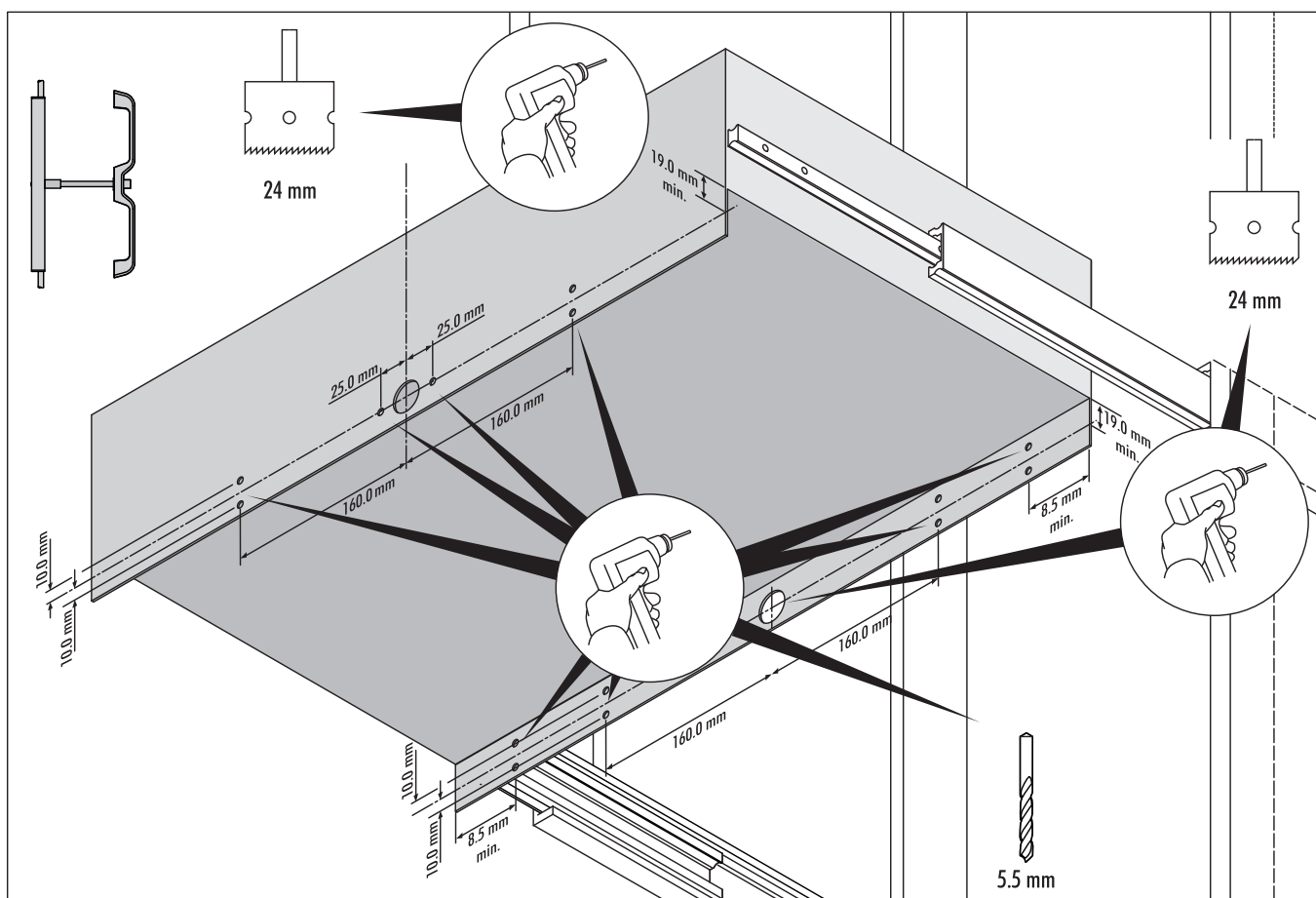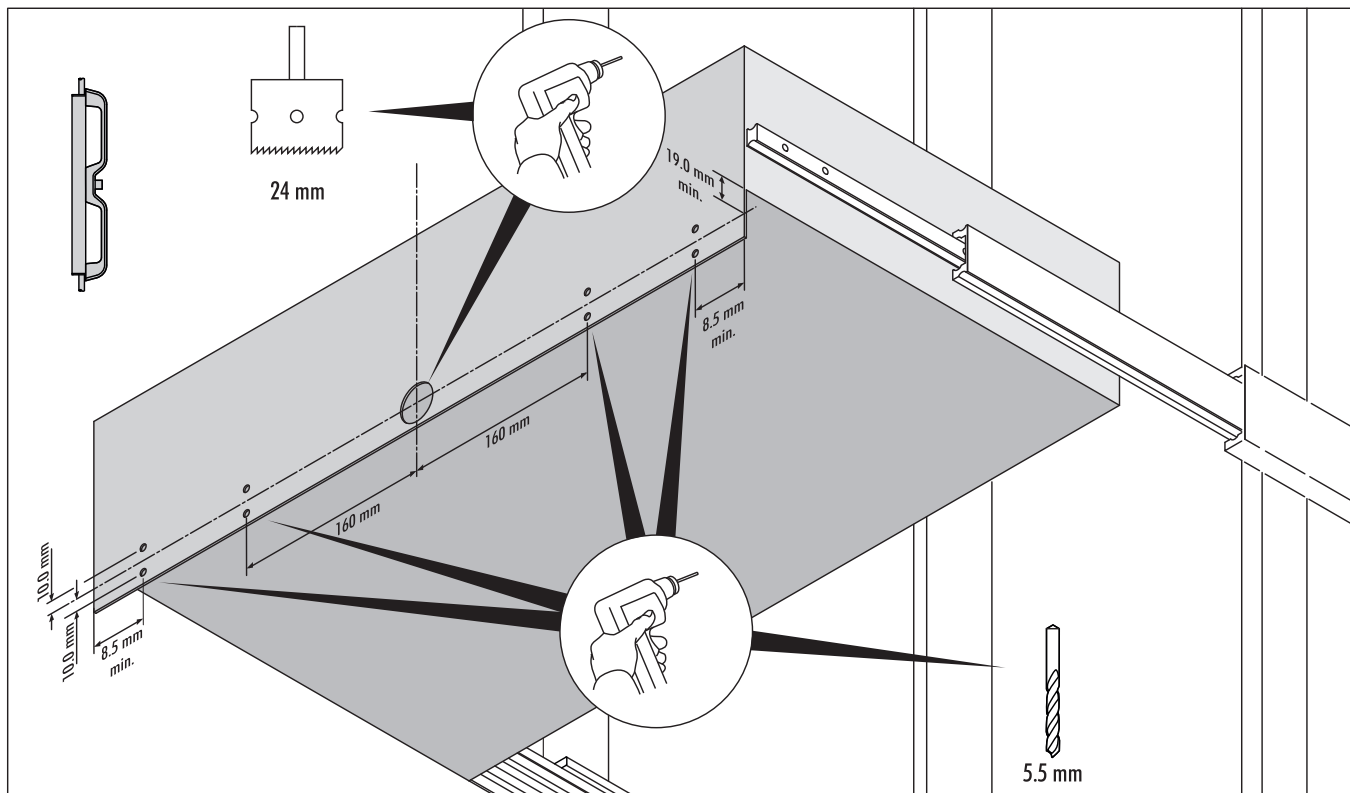

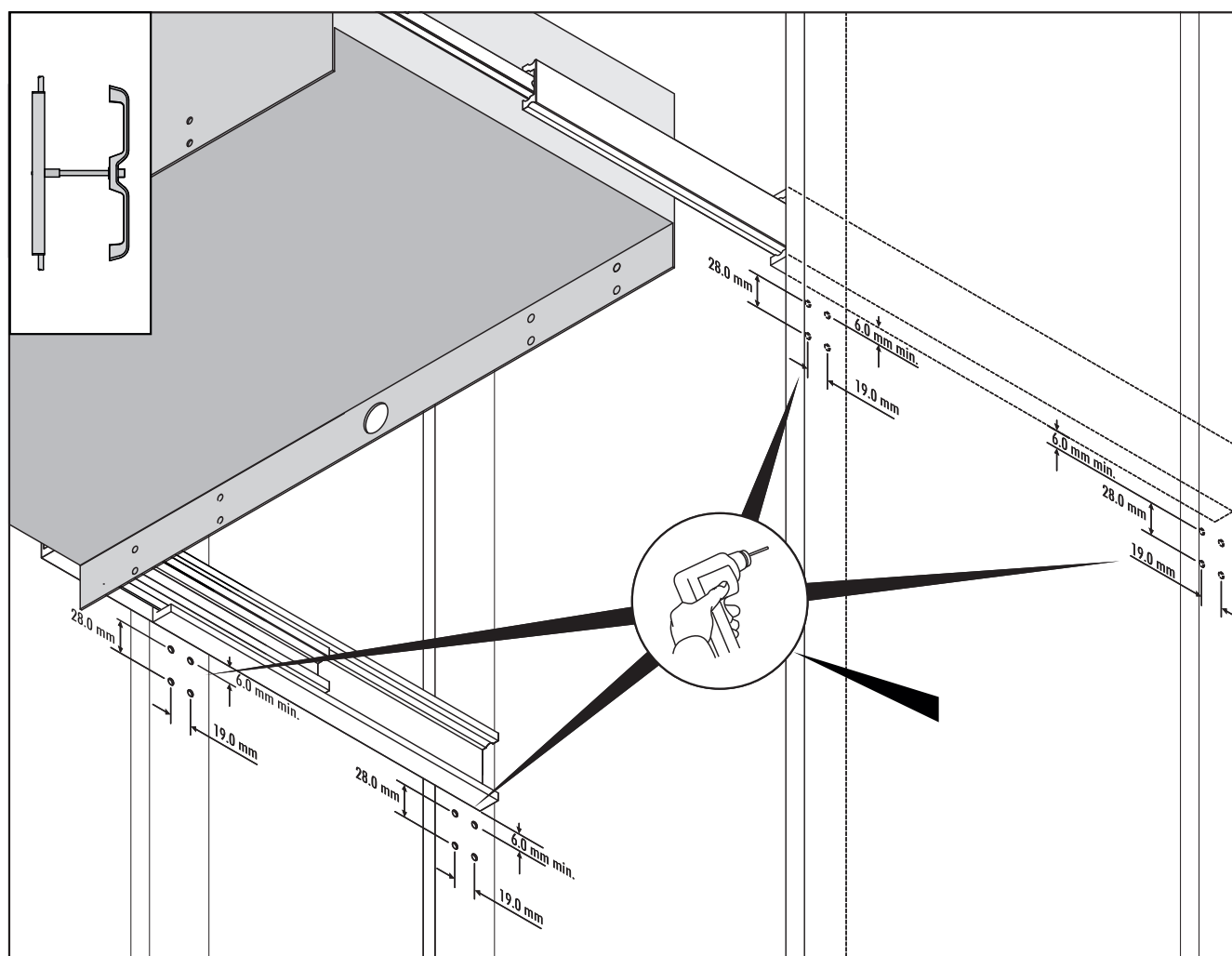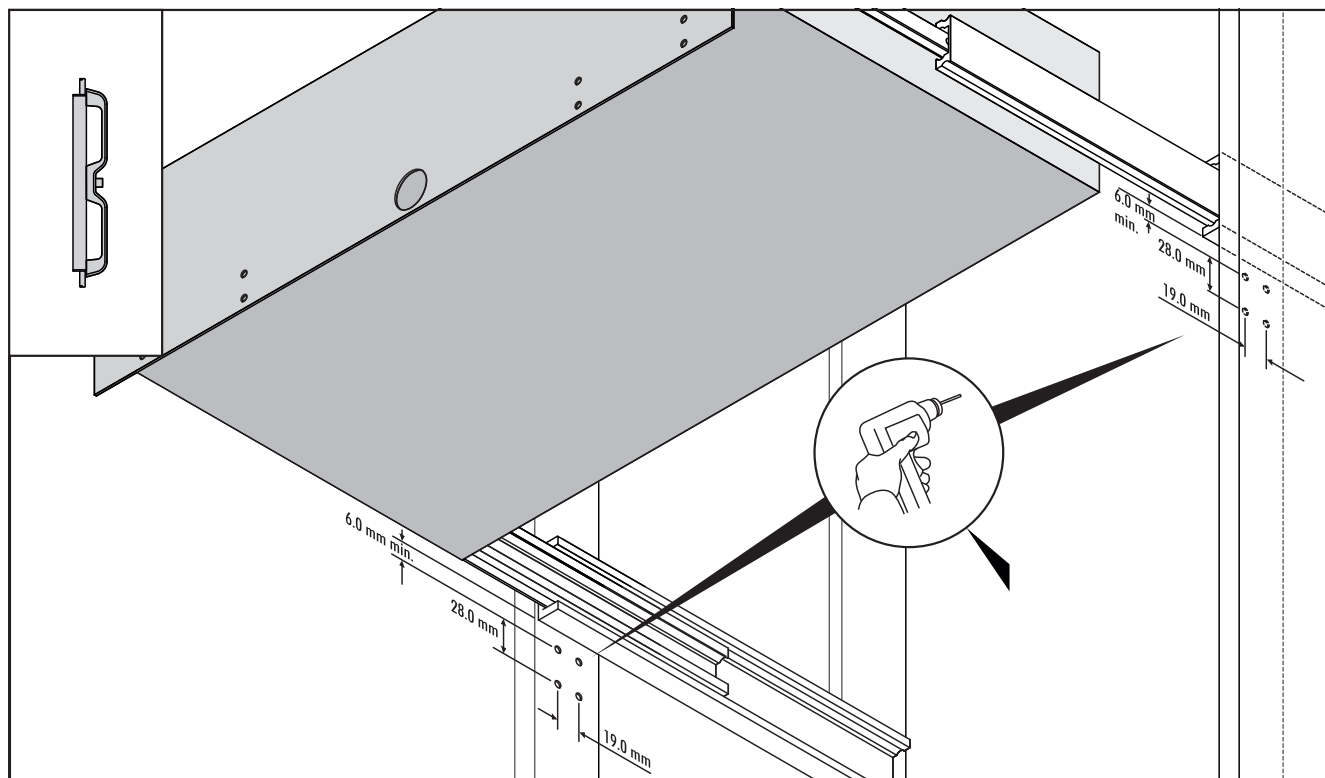

Situation-specific drilling and fastening

