

Clamping levers, plastic with internal thread, threaded insert black oxidised steel

Item description/product images



Description

Material:

Handle fibreglass reinforced plastic with die-cast zinc toothed ring.
Steel parts grade 5.8.

Version:

Steel parts black oxidised.

On request:

Other threads and special versions.

Dimension "H1" available in other lengths at extra charge.

Clamping levers, plastic with internal thread, threaded insert black oxidised steel

Item description/product images




Clamping levers, plastic with internal thread, threaded insert black oxidised steel

Item description/product images

lift to
disengage



Drawings

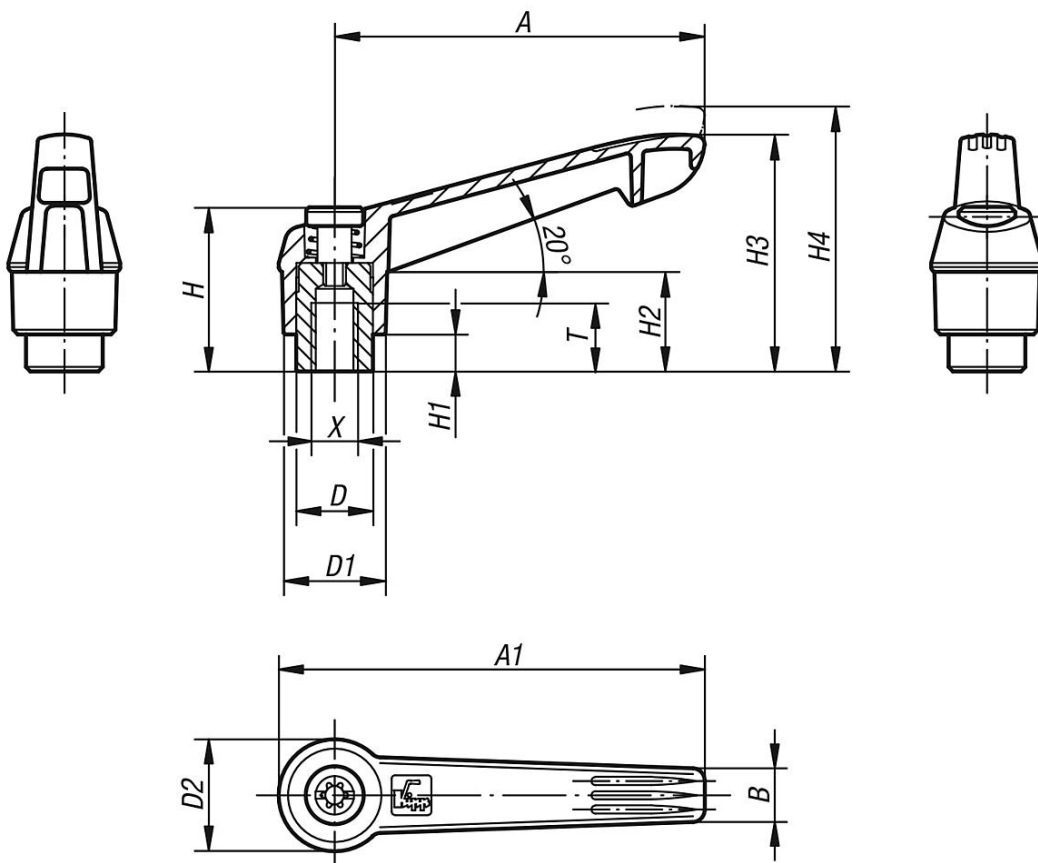

Overview of items

Clamping levers with plastic handle, female thread

Clamping levers, plastic with internal thread, threaded insert black oxidised steel

Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
K0269.1041	black grey RAL 7021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.1042	orange RAL 2004	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10416	colza yellow RAL 1021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10484	traffic red RAL 3020	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10486	signal green RAL 6032	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10487	traffic blue RAL 5017	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10488	light grey RAL 7035	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.1051	black grey RAL 7021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.1052	orange RAL 2004	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10516	colza yellow RAL 1021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10584	traffic red RAL 3020	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10586	signal green RAL 6032	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10587	traffic blue RAL 5017	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10588	light grey RAL 7035	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.1061	black grey RAL 7021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.1062	orange RAL 2004	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10616	colza yellow RAL 1021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10684	traffic red RAL 3020	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10686	signal green RAL 6032	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10687	traffic blue RAL 5017	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.10688	light grey RAL 7035	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0269.2061	black grey RAL 7021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.2062	orange RAL 2004	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20616	colza yellow RAL 1021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20684	traffic red RAL 3020	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20686	signal green RAL 6032	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20687	traffic blue RAL 5017	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20688	light grey RAL 7035	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.2081	black grey RAL 7021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.2082	orange RAL 2004	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20816	colza yellow RAL 1021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20884	traffic red RAL 3020	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20886	signal green RAL 6032	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20887	traffic blue RAL 5017	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.20888	light grey RAL 7035	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0269.3081	black grey RAL 7021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.3082	orange RAL 2004	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.30816	colza yellow RAL 1021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.30884	traffic red RAL 3020	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.30886	signal green RAL 6032	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.30887	traffic blue RAL 5017	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.30888	light grey RAL 7035	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.3101	black grey RAL 7021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.3102	orange RAL 2004	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.31016	colza yellow RAL 1021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.31084	traffic red RAL 3020	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.31086	signal green RAL 6032	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.31087	traffic blue RAL 5017	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.31088	light grey RAL 7035	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0269.4101	black grey RAL 7021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.4102	orange RAL 2004	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41016	colza yellow RAL 1021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41084	traffic red RAL 3020	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41086	signal green RAL 6032	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41087	traffic blue RAL 5017	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41088	light grey RAL 7035	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.4121	black grey RAL 7021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.4122	orange RAL 2004	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41216	colza yellow RAL 1021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41284	traffic red RAL 3020	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41286	signal green RAL 6032	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.41287	traffic blue RAL 5017	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24

Clamping levers, plastic with internal thread, threaded insert black oxidised steel

Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
K0269.41288	light grey RAL 7035	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0269.5121	black grey RAL 7021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.5122	orange RAL 2004	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51216	colza yellow RAL 1021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51284	traffic red RAL 3020	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51286	signal green RAL 6032	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51287	traffic blue RAL 5017	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51288	light grey RAL 7035	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.5161	black grey RAL 7021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.5162	orange RAL 2004	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51616	colza yellow RAL 1021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51684	traffic red RAL 3020	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51686	signal green RAL 6032	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51687	traffic blue RAL 5017	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
K0269.51688	light grey RAL 7035	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26