


Lateral spring plungers with threaded sleeve

Item description/product images

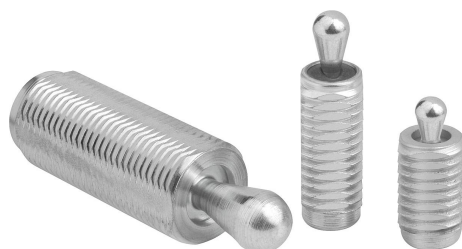

Description

Material:

Steel.

Version:

Thrust pin steel, hardened and electro zinc-plated.

Sleeve blue electro zinc-plated.



Note:

Lateral spring plungers with threaded sleeve can be individually adjusted to suit the part being held. The threaded sleeve is also suitable for screwing into thin sheet metal as it can be fastened with one or two nuts.

W and Z are customer specified.


Drawing reference:

1) assembly tool

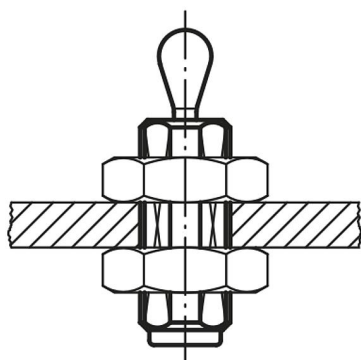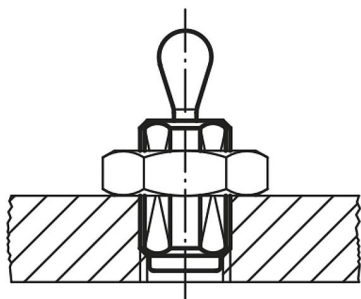

Lateral spring plungers with threaded sleeve

Drawings

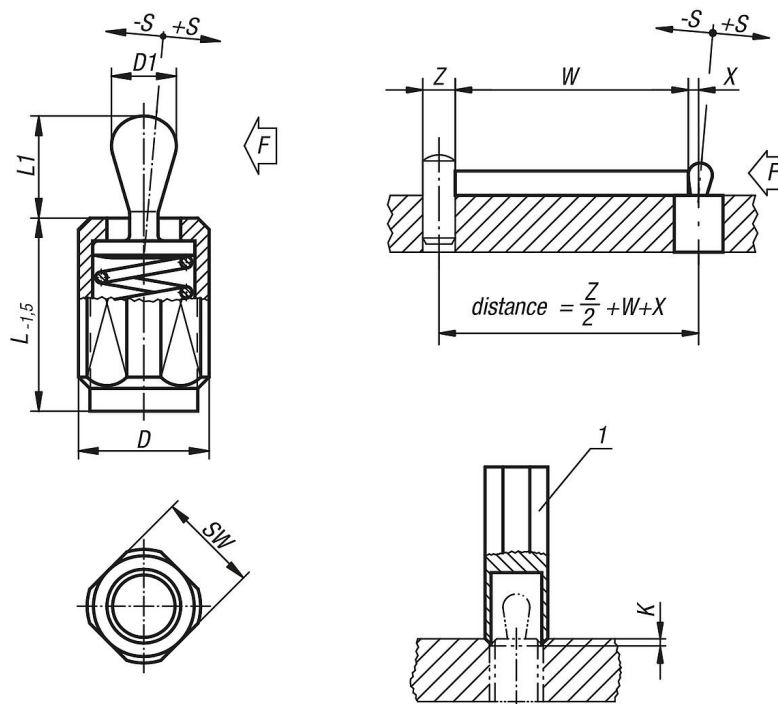

Overview of items

Lateral spring plungers without seal

Order No.	Version 2	D	D1	K	L	L1	±S	SW	X	F ca.N	Order No. assembly tool
K0371.1020X12	without seal	M12	5	2x60°	11,5	6,7	0,8	10	1,6	20	K0371.06
K0371.1020X20	without seal	M12	5	2x60°	19	6,7	0,8	10	1,6	20	K0371.06
K0371.1020X27	without seal	M12	5	2x60°	26,5	6,7	0,8	10	1,6	20	K0371.06
K0371.1050X12	without seal	M12	5	2x60°	11,5	6,7	0,8	10	1,6	50	K0371.06
K0371.1050X20	without seal	M12	5	2x60°	19	6,7	0,8	10	1,6	50	K0371.06
K0371.1050X27	without seal	M12	5	2x60°	26,5	6,7	0,8	10	1,6	50	K0371.06
K0371.1100X12	without seal	M12	5	2x60°	11,5	6,7	0,8	10	1,6	100	K0371.06
K0371.1100X20	without seal	M12	5	2x60°	19	6,7	0,8	10	1,6	100	K0371.06
K0371.1100X27	without seal	M12	5	2x60°	26,5	6,7	0,8	10	1,6	100	K0371.06
K0371.1040X12	without seal	M12	6	2x60°	11,5	10,7	1	10	1,8	40	K0371.06
K0371.1040X20	without seal	M12	6	2x60°	19	10,7	1	10	1,8	40	K0371.06
K0371.1040X27	without seal	M12	6	2x60°	26,5	10,7	1	10	1,8	40	K0371.06
K0371.1075X12	without seal	M12	6	2x60°	11,5	10,7	1	10	1,8	75	K0371.06
K0371.1075X20	without seal	M12	6	2x60°	19	10,7	1	10	1,8	75	K0371.06
K0371.1075X27	without seal	M12	6	2x60°	26,5	10,7	1	10	1,8	75	K0371.06
K0371.1150X12	without seal	M12	6	2x60°	11,5	10,7	1	10	1,8	100	K0371.06
K0371.1150X20	without seal	M12	6	2x60°	19	10,7	1	10	1,8	100	K0371.06
K0371.1150X27	without seal	M12	6	2x60°	26,5	10,7	1	10	1,8	100	K0371.06
K0371.1100X16	without seal	M18X1,5	10	2,5x60°	18	16,7	1,6	16	3,2	100	K0371.10
K0371.1100X29	without seal	M18X1,5	10	2,5x60°	31,5	16,7	1,6	16	3,2	100	K0371.10
K0371.1100X43	without seal	M18X1,5	10	2,5x60°	45	16,7	1,6	16	3,2	100	K0371.10
K0371.1200X16	without seal	M18X1,5	10	2,5x60°	18	16,7	1,6	16	3,2	150	K0371.10
K0371.1200X29	without seal	M18X1,5	10	2,5x60°	31,5	16,7	1,6	16	3,2	150	K0371.10
K0371.1200X43	without seal	M18X1,5	10	2,5x60°	45	16,7	1,6	16	3,2	150	K0371.10
K0371.1300X16	without seal	M18X1,5	10	2,5x60°	18	16,7	1,6	16	3,2	200	K0371.10
K0371.1300X29	without seal	M18X1,5	10	2,5x60°	31,5	16,7	1,6	16	3,2	200	K0371.10
K0371.1300X43	without seal	M18X1,5	10	2,5x60°	45	16,7	1,6	16	3,2	200	K0371.10

Lateral spring plungers with threaded sleeve

Overview of items

Lateral spring plungers with seal

Order No.	Version 2	D	D1	K	L	L1	±S	SW	X	F ca.N	Order No. assembly tool
K0371.3020X12	with seal	M12	5	2x60°	11,5	6	0,8	10	1,6	20	K0371.06
K0371.3020X20	with seal	M12	5	2x60°	19	6	0,8	10	1,6	20	K0371.06
K0371.3020X27	with seal	M12	5	2x60°	26,5	6	0,8	10	1,6	20	K0371.06
K0371.3050X12	with seal	M12	5	2x60°	11,5	6	0,8	10	1,6	50	K0371.06
K0371.3050X20	with seal	M12	5	2x60°	19	6	0,8	10	1,6	50	K0371.06
K0371.3050X27	with seal	M12	5	2x60°	26,5	6	0,8	10	1,6	50	K0371.06
K0371.3100X12	with seal	M12	5	2x60°	11,5	6	0,8	10	1,6	100	K0371.06
K0371.3100X20	with seal	M12	5	2x60°	19	6	0,8	10	1,6	100	K0371.06
K0371.3100X27	with seal	M12	5	2x60°	26,5	6	0,8	10	1,6	100	K0371.06
K0371.3040X12	with seal	M12	6	2x60°	11,5	10	1	10	1,8	40	K0371.06
K0371.3040X20	with seal	M12	6	2x60°	19	10	1	10	1,8	40	K0371.06
K0371.3040X27	with seal	M12	6	2x60°	26,5	10	1	10	1,8	40	K0371.06
K0371.3075X12	with seal	M12	6	2x60°	11,5	10	1	10	1,8	75	K0371.06
K0371.3075X20	with seal	M12	6	2x60°	19	10	1	10	1,8	75	K0371.06
K0371.3075X27	with seal	M12	6	2x60°	26,5	10	1	10	1,8	75	K0371.06
K0371.3150X12	with seal	M12	6	2x60°	11,5	10	1	10	1,8	100	K0371.06
K0371.3150X20	with seal	M12	6	2x60°	19	10	1	10	1,8	100	K0371.06
K0371.3150X27	with seal	M12	6	2x60°	26,5	10	1	10	1,8	100	K0371.06
K0371.3100X16	with seal	M18X1,5	10	2,5x60°	18	16	1,6	16	3,2	100	K0371.10
K0371.3100X29	with seal	M18X1,5	10	2,5x60°	31,5	16	1,6	16	3,2	100	K0371.10
K0371.3100X43	with seal	M18X1,5	10	2,5x60°	45	16	1,6	16	3,2	100	K0371.10
K0371.3200X16	with seal	M18X1,5	10	2,5x60°	18	16	1,6	16	3,2	150	K0371.10
K0371.3200X29	with seal	M18X1,5	10	2,5x60°	31,5	16	1,6	16	3,2	150	K0371.10
K0371.3200X43	with seal	M18X1,5	10	2,5x60°	45	16	1,6	16	3,2	150	K0371.10
K0371.3300X16	with seal	M18X1,5	10	2,5x60°	18	16	1,6	16	3,2	200	K0371.10
K0371.3300X29	with seal	M18X1,5	10	2,5x60°	31,5	16	1,6	16	3,2	200	K0371.10
K0371.3300X43	with seal	M18X1,5	10	2,5x60°	45	16	1,6	16	3,2	200	K0371.10