

Threaded rods steel and stainless steel DIN 976-1

Item description/product images



Description

Material:

Steel or stainless steel A2.

Version:

Grade 4.6, electro zinc-plated.

Grade 8.8 bright or electro zinc-plated.

Bright stainless steel.


Note:

Threaded rods are only available in 1000 mm lengths.

Threaded rods size M3 and M4 may be slightly bent when delivered.

The blank version may, for technical reasons have a grey to black surface.

Drawings

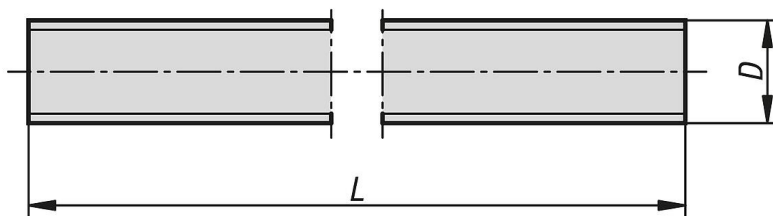

Overview of items

Threaded rods steel and stainless steel DIN 976-1

Order No.	Main material	Surface finish body	Version 1	Grade	D	L
K1960.031	steel	galvanised	RH thread	4.6	M3	1000
K1960.041	steel	galvanised	RH thread	4.6	M4	1000
K1960.051	steel	galvanised	RH thread	4.6	M5	1000
K1960.061	steel	galvanised	RH thread	4.6	M6	1000
K1960.081	steel	galvanised	RH thread	4.6	M8	1000
K1960.101	steel	galvanised	RH thread	4.6	M10	1000
K1960.121	steel	galvanised	RH thread	4.6	M12	1000
K1960.161	steel	galvanised	RH thread	4.6	M16	1000
K1960.201	steel	galvanised	RH thread	4.6	M20	1000
K1960.241	steel	galvanised	RH thread	4.6	M24	1000
K1960.301	steel	galvanised	RH thread	4.6	M30	1000
K1960.361	steel	galvanised	RH thread	4.6	M36	1000
K1960.1041	steel	galvanised	LH thread	4.6	M4	1000
K1960.1051	steel	galvanised	LH thread	4.6	M5	1000
K1960.1061	steel	galvanised	LH thread	4.6	M6	1000
K1960.1081	steel	galvanised	LH thread	4.6	M8	1000
K1960.1101	steel	galvanised	LH thread	4.6	M10	1000
K1960.1121	steel	galvanised	LH thread	4.6	M12	1000
K1960.1161	steel	galvanised	LH thread	4.6	M16	1000
K1960.1201	steel	galvanised	LH thread	4.6	M20	1000
K1960.1241	steel	galvanised	LH thread	4.6	M24	1000
K1960.1301	steel	galvanised	LH thread	4.6	M30	1000
K1960.05	steel	bright	RH thread	8.8	M5	1000
K1960.06	steel	bright	RH thread	8.8	M6	1000
K1960.08	steel	bright	RH thread	8.8	M8	1000

Threaded rods steel and stainless steel DIN 976-1

Overview of items

Order No.	Main material	Surface finish body	Version 1	Grade	D	L
K1960.10	steel	bright	RH thread	8.8	M10	1000
K1960.12	steel	bright	RH thread	8.8	M12	1000
K1960.14	steel	bright	RH thread	8.8	M14	1000
K1960.16	steel	bright	RH thread	8.8	M16	1000
K1960.18	steel	bright	RH thread	8.8	M18	1000
K1960.20	steel	bright	RH thread	8.8	M20	1000
K1960.22	steel	bright	RH thread	8.8	M22	1000
K1960.24	steel	bright	RH thread	8.8	M24	1000
K1960.043	steel	galvanised	RH thread	8.8	M4	1000
K1960.053	steel	galvanised	RH thread	8.8	M5	1000
K1960.063	steel	galvanised	RH thread	8.8	M6	1000
K1960.083	steel	galvanised	RH thread	8.8	M8	1000
K1960.103	steel	galvanised	RH thread	8.8	M10	1000
K1960.123	steel	galvanised	RH thread	8.8	M12	1000
K1960.143	steel	galvanised	RH thread	8.8	M14	1000
K1960.163	steel	galvanised	RH thread	8.8	M16	1000
K1960.183	steel	galvanised	RH thread	8.8	M18	1000
K1960.203	steel	galvanised	RH thread	8.8	M20	1000
K1960.223	steel	galvanised	RH thread	8.8	M22	1000
K1960.243	steel	galvanised	RH thread	8.8	M24	1000
K1960.303	steel	galvanised	RH thread	8.8	M30	1000
K1960.363	steel	galvanised	RH thread	8.8	M36	1000
K1960.1063	steel	galvanised	LH thread	8.8	M6	1000
K1960.1083	steel	galvanised	LH thread	8.8	M8	1000
K1960.1103	steel	galvanised	LH thread	8.8	M10	1000
K1960.1123	steel	galvanised	LH thread	8.8	M12	1000
K1960.1163	steel	galvanised	LH thread	8.8	M16	1000
K1960.1203	steel	galvanised	LH thread	8.8	M20	1000
K1960.1243	steel	galvanised	LH thread	8.8	M24	1000
K1960.1303	steel	galvanised	LH thread	8.8	M30	1000
K1960.1363	steel	galvanised	LH thread	8.8	M36	1000
K1960.052	stainless steel A2	bright	RH thread	70	M5	1000
K1960.062	stainless steel A2	bright	RH thread	70	M6	1000
K1960.082	stainless steel A2	bright	RH thread	70	M8	1000
K1960.102	stainless steel A2	bright	RH thread	70	M10	1000
K1960.122	stainless steel A2	bright	RH thread	70	M12	1000
K1960.162	stainless steel A2	bright	RH thread	70	M16	1000
K1960.182	stainless steel A2	bright	RH thread	70	M18	1000
K1960.202	stainless steel A2	bright	RH thread	70	M20	1000
K1960.222	stainless steel A2	bright	RH thread	70	M22	1000
K1960.242	stainless steel A2	bright	RH thread	70	M24	1000
K1960.1042	stainless steel A2	bright	LH thread	70	M4	1000
K1960.1052	stainless steel A2	bright	LH thread	70	M5	1000
K1960.1062	stainless steel A2	bright	LH thread	70	M6	1000
K1960.1082	stainless steel A2	bright	LH thread	70	M8	1000
K1960.1102	stainless steel A2	bright	LH thread	70	M10	1000
K1960.1122	stainless steel A2	bright	LH thread	70	M12	1000
K1960.1162	stainless steel A2	bright	LH thread	70	M16	1000
K1960.1202	stainless steel A2	bright	LH thread	70	M20	1000
K1960.1242	stainless steel A2	bright	LH thread	70	M24	1000