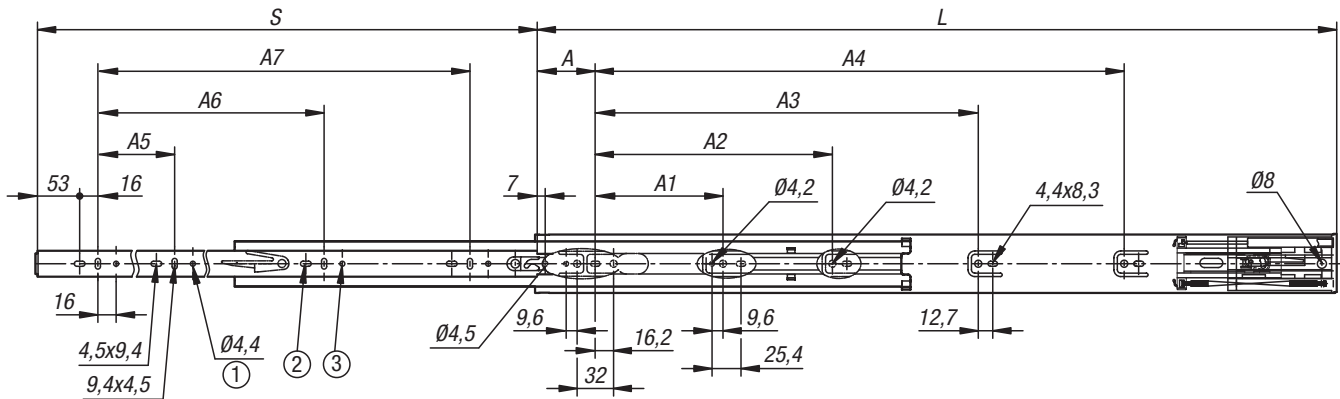


1) K2088.0300	2) K2088.0350	3) K2088.0400
---------------	---------------	---------------

주문 번호	L	S	A1	A2	A3	A4	A5	A6	A7	하중 쌍 당 kg
K2088.0300	300	275	-	96	-	-	192	-	-	35
K2088.0350	350	350	128	-	-	-	128	224	-	35
K2088.0400	400	400	128	192	-	-	160	288	-	50
K2088.0450	450	450	128	256	-	-	160	320	-	50
K2088.0500	500	500	128	224	288	-	192	384	-	60
K2088.0550	550	550	128	224	352	-	224	416	-	60
K2088.0600	600	600	128	224	352	-	256	480	-	68
K2088.0650	650	650	128	224	352	448	256	512	-	68
K2088.0700	700	700	128	224	352	480	256	448	576	68

최대 하중 값을 달성하려면 모든 장착 위치를 사용해야 합니다.

평평한 장착에 적합하지 않음.

서랍은 레일 길이보다 넓어서는 안 됩니다.

1,2,3에는 조립 구멍 없음.

서랍 부착 시 볼 케이스를 전면에 고정하십시오.

레일 고정

