


## Item description/product images

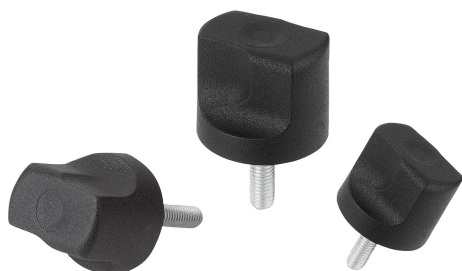

## Description


**Material:**

Thermoplastic black. Screw steel or stainless steel.

**Version:**

Screw blue passivated steel or bright stainless steel.

## Drawings

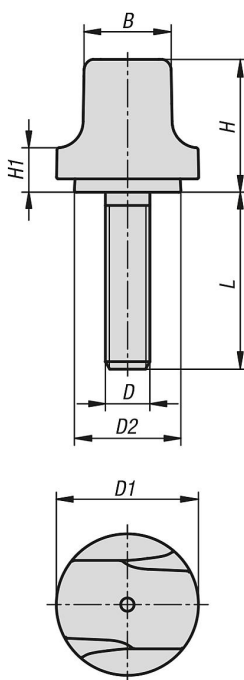

## Overview of items

## Grip screws

Order No.	Material	B	D	D1	D2	H	H1	L
K1126.103X8	steel	10	M3	16	12	15	5	8
K1126.103X10	steel	10	M3	16	12	15	5	10
K1126.103X12	steel	10	M3	16	12	15	5	12
K1126.103X15	steel	10	M3	16	12	15	5	15
K1126.104X10	steel	10	M4	16	12	15	5	10
K1126.104X15	steel	10	M4	16	12	15	5	15
K1126.104X20	steel	10	M4	16	12	15	5	20
K1126.105X10	steel	10	M5	16	12	15	5	10
K1126.105X15	steel	10	M5	16	12	15	5	15
K1126.105X20	steel	10	M5	16	12	15	5	20
K1126.204X10	steel	12,3	M4	20	15	18,5	6	10
K1126.204X15	steel	12,3	M4	20	15	18,5	6	15
K1126.204X20	steel	12,3	M4	20	15	18,5	6	20
K1126.205X10	steel	12,3	M5	20	15	18,5	6	10
K1126.205X15	steel	12,3	M5	20	15	18,5	6	15
K1126.205X20	steel	12,3	M5	20	15	18,5	6	20
K1126.205X25	steel	12,3	M5	20	15	18,5	6	25

## Overview of items

Order No.	Material	B	D	D1	D2	H	H1	L
K1126.206X10	steel	12,3	M6	20	15	18,5	6	10
K1126.206X15	steel	12,3	M6	20	15	18,5	6	15
K1126.206X20	steel	12,3	M6	20	15	18,5	6	20
K1126.206X25	steel	12,3	M6	20	15	18,5	6	25
K1126.305X10	steel	15,3	M5	25	18,7	22,9	7,3	10
K1126.305X15	steel	15,3	M5	25	18,7	22,9	7,3	15
K1126.305X20	steel	15,3	M5	25	18,7	22,9	7,3	20
K1126.305X25	steel	15,3	M5	25	18,7	22,9	7,3	25
K1126.306X10	steel	15,3	M6	25	18,7	22,9	7,3	10
K1126.306X15	steel	15,3	M6	25	18,7	22,9	7,3	15
K1126.306X20	steel	15,3	M6	25	18,7	22,9	7,3	20
K1126.306X25	steel	15,3	M6	25	18,7	22,9	7,3	25
K1126.308X15	steel	15,3	M8	25	18,7	22,9	7,3	15
K1126.308X20	steel	15,3	M8	25	18,7	22,9	7,3	20
K1126.308X25	steel	15,3	M8	25	18,7	22,9	7,3	25
K1126.308X30	steel	15,3	M8	25	18,7	22,9	7,3	30
K1126.1003X8	stainless steel	10	M3	16	12	15	5	8
K1126.1003X10	stainless steel	10	M3	16	12	15	5	10
K1126.1003X12	stainless steel	10	M3	16	12	15	5	12
K1126.1003X15	stainless steel	10	M3	16	12	15	5	15
K1126.1004X10	stainless steel	10	M4	16	12	15	5	10
K1126.1004X15	stainless steel	10	M4	16	12	15	5	15
K1126.1004X20	stainless steel	10	M4	16	12	15	5	20
K1126.1005X10	stainless steel	10	M5	16	12	15	5	10
K1126.1005X15	stainless steel	10	M5	16	12	15	5	15
K1126.1005X20	stainless steel	10	M5	16	12	15	5	20
K1126.2004X10	stainless steel	12,3	M4	20	15	18,5	6	10
K1126.2004X15	stainless steel	12,3	M4	20	15	18,5	6	15
K1126.2004X20	stainless steel	12,3	M4	20	15	18,5	6	20
K1126.2005X10	stainless steel	12,3	M5	20	15	18,5	6	10
K1126.2005X15	stainless steel	12,3	M5	20	15	18,5	6	15
K1126.2005X20	stainless steel	12,3	M5	20	15	18,5	6	20
K1126.2005X25	stainless steel	12,3	M5	20	15	18,5	6	25
K1126.2006X10	stainless steel	12,3	M6	20	15	18,5	6	10
K1126.2006X15	stainless steel	12,3	M6	20	15	18,5	6	15
K1126.2006X20	stainless steel	12,3	M6	20	15	18,5	6	20
K1126.2006X25	stainless steel	12,3	M6	20	15	18,5	6	25
K1126.3005X10	stainless steel	15,3	M5	25	18,7	22,9	7,3	10
K1126.3005X15	stainless steel	15,3	M5	25	18,7	22,9	7,3	15
K1126.3005X20	stainless steel	15,3	M5	25	18,7	22,9	7,3	20
K1126.3005X25	stainless steel	15,3	M5	25	18,7	22,9	7,3	25
K1126.3006X10	stainless steel	15,3	M6	25	18,7	22,9	7,3	10
K1126.3006X15	stainless steel	15,3	M6	25	18,7	22,9	7,3	15
K1126.3006X20	stainless steel	15,3	M6	25	18,7	22,9	7,3	20
K1126.3006X25	stainless steel	15,3	M6	25	18,7	22,9	7,3	25
K1126.3008X15	stainless steel	15,3	M8	25	18,7	22,9	7,3	15
K1126.3008X20	stainless steel	15,3	M8	25	18,7	22,9	7,3	20
K1126.3008X25	stainless steel	15,3	M8	25	18,7	22,9	7,3	25
K1126.3008X30	stainless steel	15,3	M8	25	18,7	22,9	7,3	30