

## Knurled knobs

### Item description/product images



|                        |                         |                          |                          |
|------------------------|-------------------------|--------------------------|--------------------------|
| black grey<br>RAL 7021 | pure orange<br>RAL 2004 | signal green<br>RAL 6032 | traffic blue<br>RAL 5017 |
| light grey<br>RAL 7035 | traffic red<br>RAL 3020 | colza yellow<br>RAL 1021 |                          |

### Description

#### Material:


Black thermoplastic.

Bush and screw 5.8 steel or 1.4305 stainless steel.

#### Version:

Steel trivalent blue passivated, stainless steel bright.

### Drawings

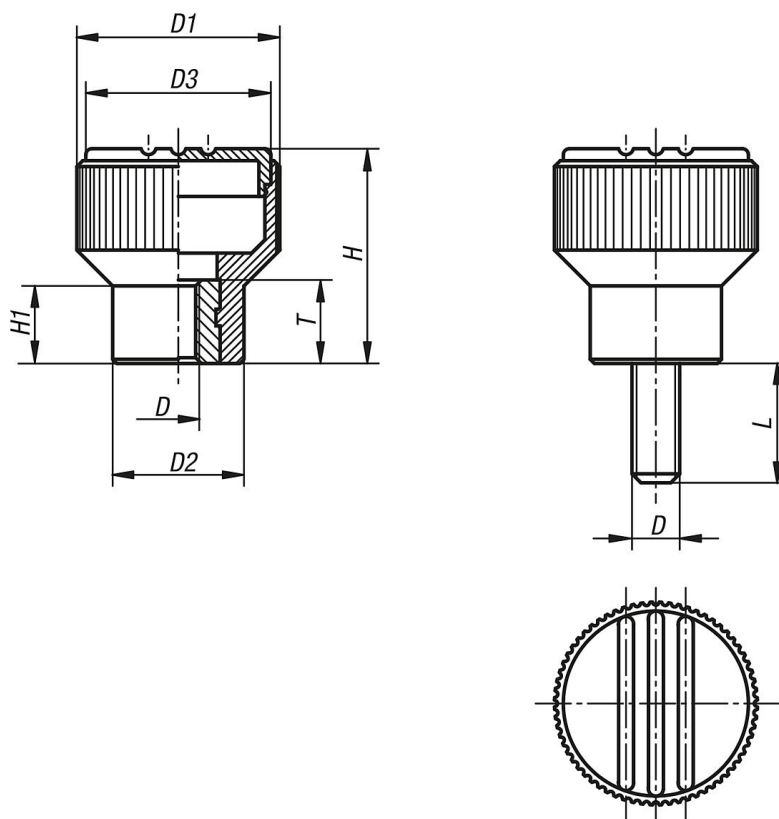

### Overview of items

### Knurled knobs

## Overview of items

| Order No.   | Bush material   | Colour Cap            | D   | D1 | D2 | D3 | H  | H1  | T  | L |
|-------------|-----------------|-----------------------|-----|----|----|----|----|-----|----|---|
| K0247.104   | steel           | black grey RAL 7021   | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1041  | steel           | orange RAL 2004       | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1042  | steel           | signal green RAL6032  | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1043  | steel           | blue RAL5017          | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1045  | steel           | light grey RAL 7035   | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1046  | steel           | traffic red RAL 3020  | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1047  | steel           | colza yellow RAL 1021 | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.105   | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1051  | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1052  | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1053  | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1055  | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1056  | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1057  | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.106   | steel           | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1061  | steel           | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1062  | steel           | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1063  | steel           | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1065  | steel           | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1066  | steel           | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.1067  | steel           | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.208   | steel           | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2081  | steel           | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2082  | steel           | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2083  | steel           | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2085  | steel           | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2086  | steel           | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.2087  | steel           | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | - |
| K0247.308   | steel           | black grey RAL 7021   | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3081  | steel           | orange RAL 2004       | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3082  | steel           | signal green RAL6032  | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3083  | steel           | blue RAL5017          | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3085  | steel           | light grey RAL 7035   | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3086  | steel           | traffic red RAL 3020  | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3087  | steel           | colza yellow RAL 1021 | M8  | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.310   | steel           | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3101  | steel           | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3102  | steel           | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3103  | steel           | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3105  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3106  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.3107  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 14 | - |
| K0247.0104  | stainless steel | black grey RAL 7021   | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01041 | stainless steel | orange RAL 2004       | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01042 | stainless steel | signal green RAL6032  | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01043 | stainless steel | blue RAL5017          | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01045 | stainless steel | light grey RAL 7035   | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01046 | stainless steel | traffic red RAL 3020  | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01047 | stainless steel | colza yellow RAL 1021 | M4  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.0105  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01051 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01052 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01053 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01055 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01056 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01057 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.0106  | stainless steel | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01061 | stainless steel | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01062 | stainless steel | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01063 | stainless steel | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01065 | stainless steel | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |
| K0247.01066 | stainless steel | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | 10 | - |

## Overview of items

| Order No.     | Bush material   | Colour Cap            | D   | D1 | D2 | D3 | H  | H1  | T  | L  |
|---------------|-----------------|-----------------------|-----|----|----|----|----|-----|----|----|
| K0247.01067   | stainless steel | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | 10 | -  |
| K0247.0208    | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02081   | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02082   | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02083   | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02085   | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02086   | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.02087   | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 14 | -  |
| K0247.0308    | stainless steel | black grey RAL 7021   | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03081   | stainless steel | orange RAL 2004       | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03082   | stainless steel | signal green RAL6032  | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03083   | stainless steel | blue RAL5017          | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03085   | stainless steel | light grey RAL 7035   | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03086   | stainless steel | traffic red RAL 3020  | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03087   | stainless steel | colza yellow RAL 1021 | M8  | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.0310    | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03101   | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03102   | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03103   | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03105   | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03106   | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.03107   | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 14 | -  |
| K0247.105X10  | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1051X10 | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1052X10 | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1053X10 | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1055X10 | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1056X10 | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.1057X10 | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | -  | 10 |
| K0247.105X12  | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1051X12 | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1052X12 | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1053X12 | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1055X12 | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1056X12 | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.1057X12 | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | -  | 12 |
| K0247.105X15  | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1051X15 | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1052X15 | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1053X15 | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1055X15 | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1056X15 | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1057X15 | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.105X20  | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1051X20 | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1052X20 | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1053X20 | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1055X20 | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1056X20 | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.1057X20 | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | -  | 20 |
| K0247.105X25  | steel           | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1051X25 | steel           | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1052X25 | steel           | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1053X25 | steel           | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1055X25 | steel           | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1056X25 | steel           | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.1057X25 | steel           | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | -  | 25 |
| K0247.106X15  | steel           | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1061X15 | steel           | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1062X15 | steel           | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1063X15 | steel           | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | -  | 15 |
| K0247.1065X15 | steel           | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | -  | 15 |

## Overview of items

| Order No.     | Bush material | Colour Cap            | D   | D1 | D2 | D3 | H  | H1  | T | L  |
|---------------|---------------|-----------------------|-----|----|----|----|----|-----|---|----|
| K0247.1066X15 | steel         | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 15 |
| K0247.1067X15 | steel         | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 15 |
| K0247.106X20  | steel         | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1061X20 | steel         | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1062X20 | steel         | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1063X20 | steel         | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1065X20 | steel         | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1066X20 | steel         | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.1067X20 | steel         | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 20 |
| K0247.106X25  | steel         | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1061X25 | steel         | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1062X25 | steel         | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1063X25 | steel         | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1065X25 | steel         | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1066X25 | steel         | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.1067X25 | steel         | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.106X30  | steel         | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1061X30 | steel         | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1062X30 | steel         | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1063X30 | steel         | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1065X30 | steel         | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1066X30 | steel         | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.1067X30 | steel         | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.208X20  | steel         | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2081X20 | steel         | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2082X20 | steel         | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2083X20 | steel         | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2085X20 | steel         | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2086X20 | steel         | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.2087X20 | steel         | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.208X25  | steel         | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2081X25 | steel         | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2082X25 | steel         | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2083X25 | steel         | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2085X25 | steel         | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2086X25 | steel         | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.2087X25 | steel         | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.208X30  | steel         | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2081X30 | steel         | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2082X30 | steel         | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2083X30 | steel         | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2085X30 | steel         | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2086X30 | steel         | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.2087X30 | steel         | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.208X40  | steel         | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2081X40 | steel         | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2082X40 | steel         | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2083X40 | steel         | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2085X40 | steel         | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2086X40 | steel         | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.2087X40 | steel         | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.310X20  | steel         | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3101X20 | steel         | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3102X20 | steel         | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3103X20 | steel         | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3105X20 | steel         | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3106X20 | steel         | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.3107X20 | steel         | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.310X30  | steel         | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.3101X30 | steel         | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.3102X30 | steel         | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.3103X30 | steel         | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |

## Overview of items

| Order No.      | Bush material   | Colour Cap            | D   | D1 | D2 | D3 | H  | H1 | T | L  |
|----------------|-----------------|-----------------------|-----|----|----|----|----|----|---|----|
| K0247.3105X30  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13 | - | 30 |
| K0247.3106X30  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13 | - | 30 |
| K0247.3107X30  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13 | - | 30 |
| K0247.310X40   | steel           | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3101X40  | steel           | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3102X40  | steel           | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3103X40  | steel           | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3105X40  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3106X40  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.3107X40  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13 | - | 40 |
| K0247.0105X10  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01051X10 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01052X10 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01053X10 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01055X10 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01056X10 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.01057X10 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8  | - | 10 |
| K0247.0105X12  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01051X12 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01052X12 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01053X12 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01055X12 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01056X12 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.01057X12 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8  | - | 12 |
| K0247.0105X15  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01051X15 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01052X15 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01053X15 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01055X15 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01056X15 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01057X15 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.0105X20  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01051X20 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01052X20 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01053X20 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01055X20 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01056X20 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01057X20 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.0105X25  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01051X25 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01052X25 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01053X25 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01055X25 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01056X25 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01057X25 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.0106X15  | stainless steel | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01061X15 | stainless steel | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01062X15 | stainless steel | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01063X15 | stainless steel | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01065X15 | stainless steel | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01066X15 | stainless steel | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.01067X15 | stainless steel | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8  | - | 15 |
| K0247.0106X20  | stainless steel | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01061X20 | stainless steel | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01062X20 | stainless steel | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01063X20 | stainless steel | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01065X20 | stainless steel | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01066X20 | stainless steel | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.01067X20 | stainless steel | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8  | - | 20 |
| K0247.0106X25  | stainless steel | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01061X25 | stainless steel | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8  | - | 25 |
| K0247.01062X25 | stainless steel | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8  | - | 25 |

## Overview of items

| Order No.      | Bush material   | Colour Cap            | D   | D1 | D2 | D3 | H  | H1  | T | L  |
|----------------|-----------------|-----------------------|-----|----|----|----|----|-----|---|----|
| K0247.01063X25 | stainless steel | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.01065X25 | stainless steel | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.01066X25 | stainless steel | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.01067X25 | stainless steel | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 25 |
| K0247.0106X30  | stainless steel | black grey RAL 7021   | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01061X30 | stainless steel | orange RAL 2004       | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01062X30 | stainless steel | signal green RAL6032  | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01063X30 | stainless steel | blue RAL5017          | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01065X30 | stainless steel | light grey RAL 7035   | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01066X30 | stainless steel | traffic red RAL 3020  | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.01067X30 | stainless steel | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | - | 30 |
| K0247.0208X20  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02081X20 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02082X20 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02083X20 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02085X20 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02086X20 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.02087X20 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 20 |
| K0247.0208X25  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02081X25 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02082X25 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02083X25 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02085X25 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02086X25 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.02087X25 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 25 |
| K0247.0208X30  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02081X30 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02082X30 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02083X30 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02085X30 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02086X30 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.02087X30 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 30 |
| K0247.0208X40  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02081X40 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02082X40 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02083X40 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02085X40 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02086X40 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.02087X40 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | - | 40 |
| K0247.0310X20  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03101X20 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03102X20 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03103X20 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03105X20 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03106X20 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.03107X20 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | - | 20 |
| K0247.0310X30  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03101X30 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03102X30 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03103X30 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03105X30 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03106X30 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.03107X30 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | - | 30 |
| K0247.0310X40  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03101X40 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03102X40 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03103X40 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03105X40 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03106X40 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |
| K0247.03107X40 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | - | 40 |

