

Tongue steel, with stop

Item description/product images



Description

Material:

Steel.

Version:

Electro zinc-plated.

Note:


*A in mm by housing length H=18 mm, H=30 mm and H=50 mm.

Accessory:

Quarter-turn lock zinc, lockable K2216.

quarter-turn lock zinc, lockable, long version K2217.

Drawings

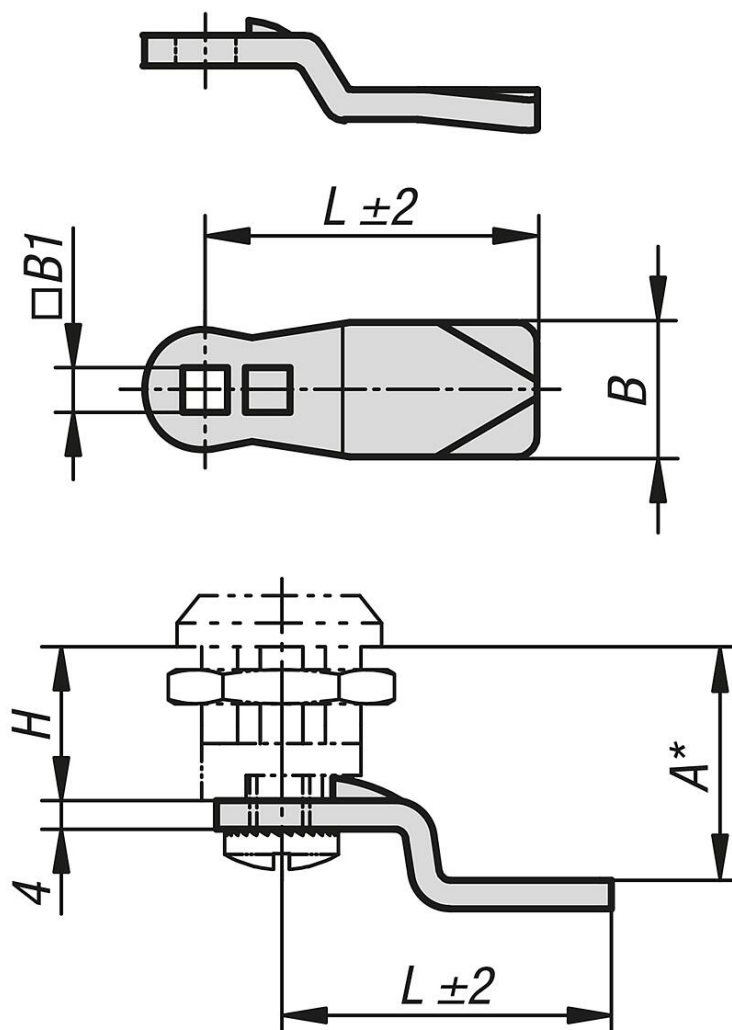

Overview of items

Tongue steel, with stop

Overview of items

Tongue steel, with stop

Order No.	Version 2	A for housing length H=18	A for housing length H=30	A for housing length H=50	B	B1	L
K2218.13506	offset upwards	6	18	38	19	8,1	35
K2218.13508	offset upwards	8	20	40	19	8,1	35
K2218.13510	offset upwards	10	22	42	19	8,1	35
K2218.13513	offset upwards	13	25	45	19	8,1	35
K2218.13514	offset upwards	14	26	46	19	8,1	35
K2218.13516	offset upwards	16	28	48	19	8,1	35
K2218.13518	straight	18	30	50	19	8,1	35
K2218.13520	offset downwards	20	32	52	19	8,1	35
K2218.13522	offset downwards	22	34	54	19	8,1	35
K2218.13524	offset downwards	24	36	56	19	8,1	35
K2218.13526	offset downwards	26	38	58	19	8,1	35
K2218.13528	offset downwards	28	40	60	19	8,1	35
K2218.14504	offset upwards	4	16	36	19	8,1	45
K2218.14506	offset upwards	6	18	38	19	8,1	45
K2218.14508	offset upwards	8	20	40	19	8,1	45
K2218.14510	offset upwards	10	22	42	19	8,1	45
K2218.14513	offset upwards	13	25	45	19	8,1	45
K2218.14514	offset upwards	14	26	46	19	8,1	45
K2218.14516	offset upwards	16	28	48	19	8,1	45
K2218.14518	straight	18	30	50	19	8,1	45
K2218.14520	offset downwards	20	32	52	19	8,1	45
K2218.14522	offset downwards	22	34	54	19	8,1	45
K2218.14524	offset downwards	24	36	56	19	8,1	45
K2218.14526	offset downwards	26	38	58	19	8,1	45
K2218.14528	offset downwards	28	40	60	19	8,1	45
K2218.14530	offset downwards	30	42	62	19	8,1	45
K2218.14532	offset downwards	32	44	64	19	8,1	45
K2218.14534	offset downwards	34	46	66	19	8,1	45
K2218.14536	offset downwards	36	48	68	19	8,1	45
K2218.14538	offset downwards	38	50	70	19	8,1	45
K2218.14540	offset downwards	40	52	72	19	8,1	45
K2218.14542	offset downwards	42	54	74	19	8,1	45