

# Knurled knobs

## Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	coiza yellow RAL 1021	

## Description

**Material:**


Black thermoplastic.

Bush and screw 5.8 steel or 1.4305 stainless steel.

**Version:**

Steel trivalent blue passivated, stainless steel bright.

## Drawings

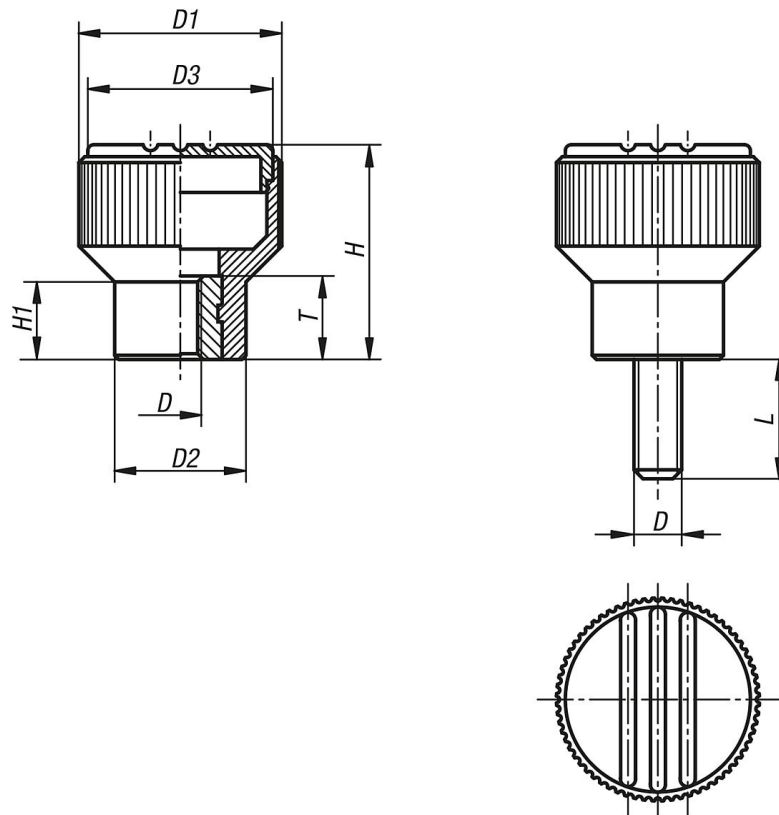

## Overview of items

### Knurled knobs

## Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
K0247.104	steel	black grey RAL 7021	M4	21	14	19	22	8	10	-
K0247.1041	steel	orange RAL 2004	M4	21	14	19	22	8	10	-
K0247.1042	steel	signal green RAL6032	M4	21	14	19	22	8	10	-
K0247.1043	steel	blue RAL5017	M4	21	14	19	22	8	10	-
K0247.1045	steel	light grey RAL 7035	M4	21	14	19	22	8	10	-
K0247.1046	steel	traffic red RAL 3020	M4	21	14	19	22	8	10	-
K0247.1047	steel	colza yellow RAL 1021	M4	21	14	19	22	8	10	-
K0247.105	steel	black grey RAL 7021	M5	21	14	19	22	8	10	-
K0247.1051	steel	orange RAL 2004	M5	21	14	19	22	8	10	-
K0247.1052	steel	signal green RAL6032	M5	21	14	19	22	8	10	-
K0247.1053	steel	blue RAL5017	M5	21	14	19	22	8	10	-
K0247.1055	steel	light grey RAL 7035	M5	21	14	19	22	8	10	-
K0247.1056	steel	traffic red RAL 3020	M5	21	14	19	22	8	10	-
K0247.1057	steel	colza yellow RAL 1021	M5	21	14	19	22	8	10	-
K0247.106	steel	black grey RAL 7021	M6	21	14	19	22	8	10	-
K0247.1061	steel	orange RAL 2004	M6	21	14	19	22	8	10	-
K0247.1062	steel	signal green RAL6032	M6	21	14	19	22	8	10	-
K0247.1063	steel	blue RAL5017	M6	21	14	19	22	8	10	-
K0247.1065	steel	light grey RAL 7035	M6	21	14	19	22	8	10	-
K0247.1066	steel	traffic red RAL 3020	M6	21	14	19	22	8	10	-
K0247.1067	steel	colza yellow RAL 1021	M6	21	14	19	22	8	10	-
K0247.208	steel	black grey RAL 7021	M8	26	18	23	26	9,5	14	-
K0247.2081	steel	orange RAL 2004	M8	26	18	23	26	9,5	14	-
K0247.2082	steel	signal green RAL6032	M8	26	18	23	26	9,5	14	-
K0247.2083	steel	blue RAL5017	M8	26	18	23	26	9,5	14	-
K0247.2085	steel	light grey RAL 7035	M8	26	18	23	26	9,5	14	-
K0247.2086	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	14	-
K0247.2087	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	14	-
K0247.308	steel	black grey RAL 7021	M8	34	22	31	36	13	14	-
K0247.3081	steel	orange RAL 2004	M8	34	22	31	36	13	14	-
K0247.3082	steel	signal green RAL6032	M8	34	22	31	36	13	14	-
K0247.3083	steel	blue RAL5017	M8	34	22	31	36	13	14	-
K0247.3085	steel	light grey RAL 7035	M8	34	22	31	36	13	14	-
K0247.3086	steel	traffic red RAL 3020	M8	34	22	31	36	13	14	-
K0247.3087	steel	colza yellow RAL 1021	M8	34	22	31	36	13	14	-
K0247.310	steel	black grey RAL 7021	M10	34	22	31	36	13	14	-
K0247.3101	steel	orange RAL 2004	M10	34	22	31	36	13	14	-
K0247.3102	steel	signal green RAL6032	M10	34	22	31	36	13	14	-
K0247.3103	steel	blue RAL5017	M10	34	22	31	36	13	14	-
K0247.3105	steel	light grey RAL 7035	M10	34	22	31	36	13	14	-
K0247.3106	steel	traffic red RAL 3020	M10	34	22	31	36	13	14	-
K0247.3107	steel	colza yellow RAL 1021	M10	34	22	31	36	13	14	-
K0247.0104	stainless steel	black grey RAL 7021	M4	21	14	19	22	8	10	-
K0247.01041	stainless steel	orange RAL 2004	M4	21	14	19	22	8	10	-
K0247.01042	stainless steel	signal green RAL6032	M4	21	14	19	22	8	10	-
K0247.01043	stainless steel	blue RAL5017	M4	21	14	19	22	8	10	-
K0247.01045	stainless steel	light grey RAL 7035	M4	21	14	19	22	8	10	-
K0247.01046	stainless steel	traffic red RAL 3020	M4	21	14	19	22	8	10	-
K0247.01047	stainless steel	colza yellow RAL 1021	M4	21	14	19	22	8	10	-
K0247.0105	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	10	-
K0247.01051	stainless steel	orange RAL 2004	M5	21	14	19	22	8	10	-
K0247.01052	stainless steel	signal green RAL6032	M5	21	14	19	22	8	10	-
K0247.01053	stainless steel	blue RAL5017	M5	21	14	19	22	8	10	-
K0247.01055	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	10	-
K0247.01056	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	10	-
K0247.01057	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	10	-
K0247.0106	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	10	-
K0247.01061	stainless steel	orange RAL 2004	M6	21	14	19	22	8	10	-
K0247.01062	stainless steel	signal green RAL6032	M6	21	14	19	22	8	10	-
K0247.01063	stainless steel	blue RAL5017	M6	21	14	19	22	8	10	-
K0247.01065	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	10	-
K0247.01066	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	10	-

## Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
K0247.01067	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	10	-
K0247.0208	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	14	-
K0247.02081	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	14	-
K0247.02082	stainless steel	signal green RAL6032	M8	26	18	23	26	9,5	14	-
K0247.02083	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	14	-
K0247.02085	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	14	-
K0247.02086	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	14	-
K0247.02087	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	14	-
K0247.0308	stainless steel	black grey RAL 7021	M8	34	22	31	36	13	14	-
K0247.03081	stainless steel	orange RAL 2004	M8	34	22	31	36	13	14	-
K0247.03082	stainless steel	signal green RAL6032	M8	34	22	31	36	13	14	-
K0247.03083	stainless steel	blue RAL5017	M8	34	22	31	36	13	14	-
K0247.03085	stainless steel	light grey RAL 7035	M8	34	22	31	36	13	14	-
K0247.03086	stainless steel	traffic red RAL 3020	M8	34	22	31	36	13	14	-
K0247.03087	stainless steel	colza yellow RAL 1021	M8	34	22	31	36	13	14	-
K0247.0310	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	14	-
K0247.03101	stainless steel	orange RAL 2004	M10	34	22	31	36	13	14	-
K0247.03102	stainless steel	signal green RAL6032	M10	34	22	31	36	13	14	-
K0247.03103	stainless steel	blue RAL5017	M10	34	22	31	36	13	14	-
K0247.03105	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	14	-
K0247.03106	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	14	-
K0247.03107	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	14	-
K0247.105X10	steel	black grey RAL 7021	M5	21	14	19	22	8	-	10
K0247.1051X10	steel	orange RAL 2004	M5	21	14	19	22	8	-	10
K0247.1052X10	steel	signal green RAL6032	M5	21	14	19	22	8	-	10
K0247.1053X10	steel	blue RAL5017	M5	21	14	19	22	8	-	10
K0247.1055X10	steel	light grey RAL 7035	M5	21	14	19	22	8	-	10
K0247.1056X10	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	10
K0247.1057X10	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	10
K0247.105X12	steel	black grey RAL 7021	M5	21	14	19	22	8	-	12
K0247.1051X12	steel	orange RAL 2004	M5	21	14	19	22	8	-	12
K0247.1052X12	steel	signal green RAL6032	M5	21	14	19	22	8	-	12
K0247.1053X12	steel	blue RAL5017	M5	21	14	19	22	8	-	12
K0247.1055X12	steel	light grey RAL 7035	M5	21	14	19	22	8	-	12
K0247.1056X12	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	12
K0247.1057X12	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	12
K0247.105X15	steel	black grey RAL 7021	M5	21	14	19	22	8	-	15
K0247.1051X15	steel	orange RAL 2004	M5	21	14	19	22	8	-	15
K0247.1052X15	steel	signal green RAL6032	M5	21	14	19	22	8	-	15
K0247.1053X15	steel	blue RAL5017	M5	21	14	19	22	8	-	15
K0247.1055X15	steel	light grey RAL 7035	M5	21	14	19	22	8	-	15
K0247.1056X15	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	15
K0247.1057X15	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	15
K0247.105X20	steel	black grey RAL 7021	M5	21	14	19	22	8	-	20
K0247.1051X20	steel	orange RAL 2004	M5	21	14	19	22	8	-	20
K0247.1052X20	steel	signal green RAL6032	M5	21	14	19	22	8	-	20
K0247.1053X20	steel	blue RAL5017	M5	21	14	19	22	8	-	20
K0247.1055X20	steel	light grey RAL 7035	M5	21	14	19	22	8	-	20
K0247.1056X20	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	20
K0247.1057X20	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	20
K0247.105X25	steel	black grey RAL 7021	M5	21	14	19	22	8	-	25
K0247.1051X25	steel	orange RAL 2004	M5	21	14	19	22	8	-	25
K0247.1052X25	steel	signal green RAL6032	M5	21	14	19	22	8	-	25
K0247.1053X25	steel	blue RAL5017	M5	21	14	19	22	8	-	25
K0247.1055X25	steel	light grey RAL 7035	M5	21	14	19	22	8	-	25
K0247.1056X25	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	25
K0247.1057X25	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	25
K0247.106X15	steel	black grey RAL 7021	M6	21	14	19	22	8	-	15
K0247.1061X15	steel	orange RAL 2004	M6	21	14	19	22	8	-	15
K0247.1062X15	steel	signal green RAL6032	M6	21	14	19	22	8	-	15
K0247.1063X15	steel	blue RAL5017	M6	21	14	19	22	8	-	15
K0247.1065X15	steel	light grey RAL 7035	M6	21	14	19	22	8	-	15

## Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
K0247.1066X15	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	15
K0247.1067X15	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	15
K0247.106X20	steel	black grey RAL 7021	M6	21	14	19	22	8	-	20
K0247.1061X20	steel	orange RAL 2004	M6	21	14	19	22	8	-	20
K0247.1062X20	steel	signal green RAL6032	M6	21	14	19	22	8	-	20
K0247.1063X20	steel	blue RAL5017	M6	21	14	19	22	8	-	20
K0247.1065X20	steel	light grey RAL 7035	M6	21	14	19	22	8	-	20
K0247.1066X20	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	20
K0247.1067X20	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	20
K0247.106X25	steel	black grey RAL 7021	M6	21	14	19	22	8	-	25
K0247.1061X25	steel	orange RAL 2004	M6	21	14	19	22	8	-	25
K0247.1062X25	steel	signal green RAL6032	M6	21	14	19	22	8	-	25
K0247.1063X25	steel	blue RAL5017	M6	21	14	19	22	8	-	25
K0247.1065X25	steel	light grey RAL 7035	M6	21	14	19	22	8	-	25
K0247.1066X25	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	25
K0247.1067X25	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	25
K0247.106X30	steel	black grey RAL 7021	M6	21	14	19	22	8	-	30
K0247.1061X30	steel	orange RAL 2004	M6	21	14	19	22	8	-	30
K0247.1062X30	steel	signal green RAL6032	M6	21	14	19	22	8	-	30
K0247.1063X30	steel	blue RAL5017	M6	21	14	19	22	8	-	30
K0247.1065X30	steel	light grey RAL 7035	M6	21	14	19	22	8	-	30
K0247.1066X30	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	30
K0247.1067X30	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	30
K0247.208X20	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	20
K0247.2081X20	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	20
K0247.2082X20	steel	signal green RAL6032	M8	26	18	23	26	9,5	-	20
K0247.2083X20	steel	blue RAL5017	M8	26	18	23	26	9,5	-	20
K0247.2085X20	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	20
K0247.2086X20	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	20
K0247.2087X20	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	20
K0247.208X25	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	25
K0247.2081X25	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	25
K0247.2082X25	steel	signal green RAL6032	M8	26	18	23	26	9,5	-	25
K0247.2083X25	steel	blue RAL5017	M8	26	18	23	26	9,5	-	25
K0247.2085X25	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	25
K0247.2086X25	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	25
K0247.2087X25	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	25
K0247.208X30	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	30
K0247.2081X30	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	30
K0247.2082X30	steel	signal green RAL6032	M8	26	18	23	26	9,5	-	30
K0247.2083X30	steel	blue RAL5017	M8	26	18	23	26	9,5	-	30
K0247.2085X30	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	30
K0247.2086X30	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	30
K0247.2087X30	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	30
K0247.208X40	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	40
K0247.2081X40	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	40
K0247.2082X40	steel	signal green RAL6032	M8	26	18	23	26	9,5	-	40
K0247.2083X40	steel	blue RAL5017	M8	26	18	23	26	9,5	-	40
K0247.2085X40	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	40
K0247.2086X40	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	40
K0247.2087X40	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	40
K0247.310X20	steel	black grey RAL 7021	M10	34	22	31	36	13	-	20
K0247.3101X20	steel	orange RAL 2004	M10	34	22	31	36	13	-	20
K0247.3102X20	steel	signal green RAL6032	M10	34	22	31	36	13	-	20
K0247.3103X20	steel	blue RAL5017	M10	34	22	31	36	13	-	20
K0247.3105X20	steel	light grey RAL 7035	M10	34	22	31	36	13	-	20
K0247.3106X20	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	20
K0247.3107X20	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	20
K0247.310X30	steel	black grey RAL 7021	M10	34	22	31	36	13	-	30
K0247.3101X30	steel	orange RAL 2004	M10	34	22	31	36	13	-	30
K0247.3102X30	steel	signal green RAL6032	M10	34	22	31	36	13	-	30
K0247.3103X30	steel	blue RAL5017	M10	34	22	31	36	13	-	30

## Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
K0247.3105X30	steel	light grey RAL 7035	M10	34	22	31	36	13	-	30
K0247.3106X30	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	30
K0247.3107X30	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	30
K0247.310X40	steel	black grey RAL 7021	M10	34	22	31	36	13	-	40
K0247.3101X40	steel	orange RAL 2004	M10	34	22	31	36	13	-	40
K0247.3102X40	steel	signal green RAL6032	M10	34	22	31	36	13	-	40
K0247.3103X40	steel	blue RAL5017	M10	34	22	31	36	13	-	40
K0247.3105X40	steel	light grey RAL 7035	M10	34	22	31	36	13	-	40
K0247.3106X40	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	40
K0247.3107X40	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	40
K0247.0105X10	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	10
K0247.01051X10	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	10
K0247.01052X10	stainless steel	signal green RAL6032	M5	21	14	19	22	8	-	10
K0247.01053X10	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	10
K0247.01055X10	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	10
K0247.01056X10	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	10
K0247.01057X10	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	10
K0247.0105X12	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	12
K0247.01051X12	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	12
K0247.01052X12	stainless steel	signal green RAL6032	M5	21	14	19	22	8	-	12
K0247.01053X12	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	12
K0247.01055X12	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	12
K0247.01056X12	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	12
K0247.01057X12	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	12
K0247.0105X15	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	15
K0247.01051X15	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	15
K0247.01052X15	stainless steel	signal green RAL6032	M5	21	14	19	22	8	-	15
K0247.01053X15	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	15
K0247.01055X15	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	15
K0247.01056X15	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	15
K0247.01057X15	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	15
K0247.0105X20	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	20
K0247.01051X20	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	20
K0247.01052X20	stainless steel	signal green RAL6032	M5	21	14	19	22	8	-	20
K0247.01053X20	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	20
K0247.01055X20	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	20
K0247.01056X20	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	20
K0247.01057X20	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	20
K0247.0105X25	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	25
K0247.01051X25	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	25
K0247.01052X25	stainless steel	signal green RAL6032	M5	21	14	19	22	8	-	25
K0247.01053X25	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	25
K0247.01055X25	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	25
K0247.01056X25	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	25
K0247.01057X25	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	25
K0247.0106X15	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	15
K0247.01061X15	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	15
K0247.01062X15	stainless steel	signal green RAL6032	M6	21	14	19	22	8	-	15
K0247.01063X15	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	15
K0247.01065X15	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	15
K0247.01066X15	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	15
K0247.01067X15	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	15
K0247.0106X20	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	20
K0247.01061X20	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	20
K0247.01062X20	stainless steel	signal green RAL6032	M6	21	14	19	22	8	-	20
K0247.01063X20	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	20
K0247.01065X20	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	20
K0247.01066X20	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	20
K0247.01067X20	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	20
K0247.0106X25	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	25
K0247.01061X25	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	25
K0247.01062X25	stainless steel	signal green RAL6032	M6	21	14	19	22	8	-	25

## Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
K0247.01063X25	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	25
K0247.01065X25	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	25
K0247.01066X25	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	25
K0247.01067X25	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	25
K0247.0106X30	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	30
K0247.01061X30	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	30
K0247.01062X30	stainless steel	signal green RAL6032	M6	21	14	19	22	8	-	30
K0247.01063X30	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	30
K0247.01065X30	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	30
K0247.01066X30	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	30
K0247.01067X30	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	30
K0247.0208X20	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	20
K0247.02081X20	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	20
K0247.02082X20	stainless steel	signal green RAL6032	M8	26	18	23	26	9,5	-	20
K0247.02083X20	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	20
K0247.02085X20	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	20
K0247.02086X20	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	20
K0247.02087X20	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	20
K0247.0208X25	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	25
K0247.02081X25	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	25
K0247.02082X25	stainless steel	signal green RAL6032	M8	26	18	23	26	9,5	-	25
K0247.02083X25	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	25
K0247.02085X25	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	25
K0247.02086X25	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	25
K0247.02087X25	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	25
K0247.0208X30	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	30
K0247.02081X30	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	30
K0247.02082X30	stainless steel	signal green RAL6032	M8	26	18	23	26	9,5	-	30
K0247.02083X30	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	30
K0247.02085X30	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	30
K0247.02086X30	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	30
K0247.02087X30	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	30
K0247.0208X40	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	40
K0247.02081X40	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	40
K0247.02082X40	stainless steel	signal green RAL6032	M8	26	18	23	26	9,5	-	40
K0247.02083X40	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	40
K0247.02085X40	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	40
K0247.02086X40	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	40
K0247.02087X40	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	40
K0247.0310X20	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	20
K0247.03101X20	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	20
K0247.03102X20	stainless steel	signal green RAL6032	M10	34	22	31	36	13	-	20
K0247.03103X20	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	20
K0247.03105X20	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	20
K0247.03106X20	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	20
K0247.03107X20	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	20
K0247.0310X30	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	30
K0247.03101X30	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	30
K0247.03102X30	stainless steel	signal green RAL6032	M10	34	22	31	36	13	-	30
K0247.03103X30	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	30
K0247.03105X30	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	30
K0247.03106X30	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	30
K0247.03107X30	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	30
K0247.0310X40	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	40
K0247.03101X40	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	40
K0247.03102X40	stainless steel	signal green RAL6032	M10	34	22	31	36	13	-	40
K0247.03103X40	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	40
K0247.03105X40	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	40
K0247.03106X40	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	40
K0247.03107X40	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	40

