

## Knurled knobs with external thread

### Item description/product images



### Description


#### Material:

Black thermoplastic.


Bush and screw 5.8 steel or 1.4305 stainless steel.

#### Version:

Steel trivalent blue passivated, stainless steel bright.

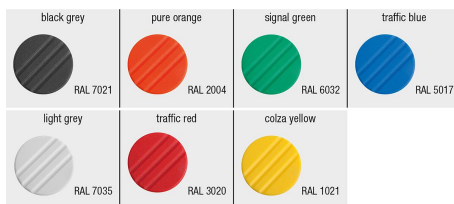

### Drawings

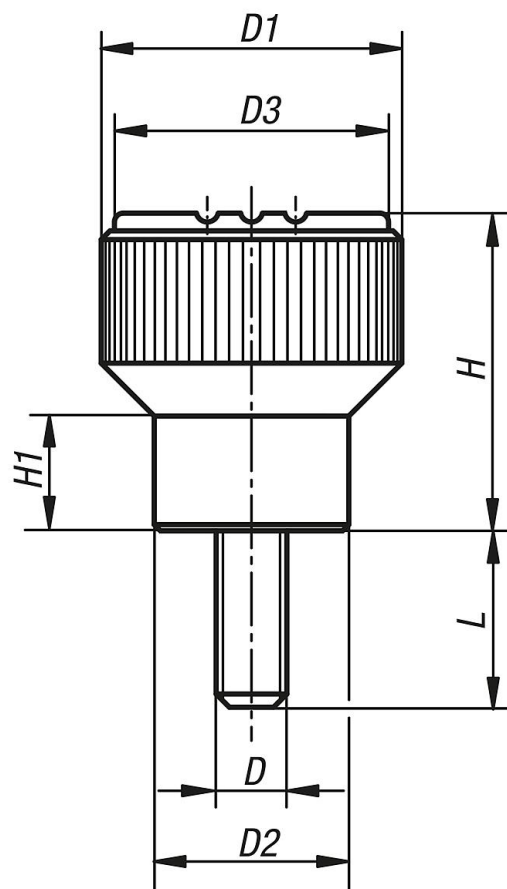

# Knurled knobs with external thread

## Overview of items

| Order No.     | Material | Colour<br>Cap         | D  | D1 | D2 | D3 | H  | H1 | L  |
|---------------|----------|-----------------------|----|----|----|----|----|----|----|
| K0247.105X10  | steel    | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1051X10 | steel    | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1052X10 | steel    | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1053X10 | steel    | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1055X10 | steel    | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1056X10 | steel    | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.1057X10 | steel    | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8  | 10 |
| K0247.105X12  | steel    | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1051X12 | steel    | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1052X12 | steel    | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1053X12 | steel    | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1055X12 | steel    | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1056X12 | steel    | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.1057X12 | steel    | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8  | 12 |
| K0247.105X15  | steel    | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1051X15 | steel    | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1052X15 | steel    | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1053X15 | steel    | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1055X15 | steel    | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1056X15 | steel    | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1057X15 | steel    | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.105X20  | steel    | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1051X20 | steel    | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1052X20 | steel    | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1053X20 | steel    | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1055X20 | steel    | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1056X20 | steel    | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1057X20 | steel    | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.105X25  | steel    | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1051X25 | steel    | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1052X25 | steel    | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1053X25 | steel    | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1055X25 | steel    | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1056X25 | steel    | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1057X25 | steel    | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.106X15  | steel    | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1061X15 | steel    | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1062X15 | steel    | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1063X15 | steel    | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1065X15 | steel    | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1066X15 | steel    | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.1067X15 | steel    | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8  | 15 |
| K0247.106X20  | steel    | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1061X20 | steel    | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1062X20 | steel    | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1063X20 | steel    | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1065X20 | steel    | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1066X20 | steel    | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.1067X20 | steel    | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8  | 20 |
| K0247.106X25  | steel    | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1061X25 | steel    | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1062X25 | steel    | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1063X25 | steel    | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1065X25 | steel    | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1066X25 | steel    | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.1067X25 | steel    | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8  | 25 |
| K0247.106X30  | steel    | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8  | 30 |
| K0247.1061X30 | steel    | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8  | 30 |
| K0247.1062X30 | steel    | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8  | 30 |
| K0247.1063X30 | steel    | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8  | 30 |
| K0247.1065X30 | steel    | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8  | 30 |
| K0247.1066X30 | steel    | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8  | 30 |

# Knurled knobs with external thread

## Overview of items

| Order No.      | Material        | Colour<br>Cap         | D   | D1 | D2 | D3 | H  | H1  | L  |
|----------------|-----------------|-----------------------|-----|----|----|----|----|-----|----|
| K0247.1067X30  | steel           | colza yellow RAL 1021 | M6  | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.208X20   | steel           | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2081X20  | steel           | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2082X20  | steel           | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2083X20  | steel           | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2085X20  | steel           | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2086X20  | steel           | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.2087X20  | steel           | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.208X25   | steel           | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2081X25  | steel           | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2082X25  | steel           | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2083X25  | steel           | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2085X25  | steel           | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2086X25  | steel           | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.2087X25  | steel           | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.208X30   | steel           | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2081X30  | steel           | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2082X30  | steel           | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2083X30  | steel           | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2085X30  | steel           | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2086X30  | steel           | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.2087X30  | steel           | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.208X40   | steel           | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2081X40  | steel           | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2082X40  | steel           | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2083X40  | steel           | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2085X40  | steel           | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2086X40  | steel           | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.2087X40  | steel           | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.310X20   | steel           | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3101X20  | steel           | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3102X20  | steel           | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3103X20  | steel           | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3105X20  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3106X20  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.3107X20  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.310X30   | steel           | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3101X30  | steel           | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3102X30  | steel           | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3103X30  | steel           | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3105X30  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3106X30  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.3107X30  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.310X40   | steel           | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3101X40  | steel           | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3102X40  | steel           | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3103X40  | steel           | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3105X40  | steel           | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3106X40  | steel           | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.3107X40  | steel           | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.0105X10  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01051X10 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01052X10 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01053X10 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01055X10 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01056X10 | stainless steel | traffic red RAL 3020  | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.01057X10 | stainless steel | colza yellow RAL 1021 | M5  | 21 | 14 | 19 | 22 | 8   | 10 |
| K0247.0105X12  | stainless steel | black grey RAL 7021   | M5  | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.01051X12 | stainless steel | orange RAL 2004       | M5  | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.01052X12 | stainless steel | signal green RAL6032  | M5  | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.01053X12 | stainless steel | blue RAL5017          | M5  | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.01055X12 | stainless steel | light grey RAL 7035   | M5  | 21 | 14 | 19 | 22 | 8   | 12 |

# Knurled knobs with external thread

## Overview of items

| Order No.      | Material        | Colour<br>Cap         | D  | D1 | D2 | D3 | H  | H1  | L  |
|----------------|-----------------|-----------------------|----|----|----|----|----|-----|----|
| K0247.01056X12 | stainless steel | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.01057X12 | stainless steel | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8   | 12 |
| K0247.0105X15  | stainless steel | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01051X15 | stainless steel | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01052X15 | stainless steel | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01053X15 | stainless steel | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01055X15 | stainless steel | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01056X15 | stainless steel | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01057X15 | stainless steel | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.0105X20  | stainless steel | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01051X20 | stainless steel | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01052X20 | stainless steel | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01053X20 | stainless steel | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01055X20 | stainless steel | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01056X20 | stainless steel | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01057X20 | stainless steel | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.0105X25  | stainless steel | black grey RAL 7021   | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01051X25 | stainless steel | orange RAL 2004       | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01052X25 | stainless steel | signal green RAL6032  | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01053X25 | stainless steel | blue RAL5017          | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01055X25 | stainless steel | light grey RAL 7035   | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01056X25 | stainless steel | traffic red RAL 3020  | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01057X25 | stainless steel | colza yellow RAL 1021 | M5 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.0106X15  | stainless steel | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01061X15 | stainless steel | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01062X15 | stainless steel | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01063X15 | stainless steel | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01065X15 | stainless steel | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01066X15 | stainless steel | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.01067X15 | stainless steel | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8   | 15 |
| K0247.0106X20  | stainless steel | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01061X20 | stainless steel | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01062X20 | stainless steel | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01063X20 | stainless steel | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01065X20 | stainless steel | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01066X20 | stainless steel | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.01067X20 | stainless steel | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8   | 20 |
| K0247.0106X25  | stainless steel | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01061X25 | stainless steel | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01062X25 | stainless steel | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01063X25 | stainless steel | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01065X25 | stainless steel | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01066X25 | stainless steel | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.01067X25 | stainless steel | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8   | 25 |
| K0247.0106X30  | stainless steel | black grey RAL 7021   | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01061X30 | stainless steel | orange RAL 2004       | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01062X30 | stainless steel | signal green RAL6032  | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01063X30 | stainless steel | blue RAL5017          | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01065X30 | stainless steel | light grey RAL 7035   | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01066X30 | stainless steel | traffic red RAL 3020  | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.01067X30 | stainless steel | colza yellow RAL 1021 | M6 | 21 | 14 | 19 | 22 | 8   | 30 |
| K0247.0208X20  | stainless steel | black grey RAL 7021   | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02081X20 | stainless steel | orange RAL 2004       | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02082X20 | stainless steel | signal green RAL6032  | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02083X20 | stainless steel | blue RAL5017          | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02085X20 | stainless steel | light grey RAL 7035   | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02086X20 | stainless steel | traffic red RAL 3020  | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.02087X20 | stainless steel | colza yellow RAL 1021 | M8 | 26 | 18 | 23 | 26 | 9,5 | 20 |
| K0247.0208X25  | stainless steel | black grey RAL 7021   | M8 | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.02081X25 | stainless steel | orange RAL 2004       | M8 | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.02082X25 | stainless steel | signal green RAL6032  | M8 | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.02083X25 | stainless steel | blue RAL5017          | M8 | 26 | 18 | 23 | 26 | 9,5 | 25 |

## Knurled knobs with external thread

### Overview of items

| Order No.      | Material        | Colour<br>Cap         | D   | D1 | D2 | D3 | H  | H1  | L  |
|----------------|-----------------|-----------------------|-----|----|----|----|----|-----|----|
| K0247.02085X25 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.02086X25 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.02087X25 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 25 |
| K0247.0208X30  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02081X30 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02082X30 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02083X30 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02085X30 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02086X30 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.02087X30 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 30 |
| K0247.0208X40  | stainless steel | black grey RAL 7021   | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02081X40 | stainless steel | orange RAL 2004       | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02082X40 | stainless steel | signal green RAL6032  | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02083X40 | stainless steel | blue RAL5017          | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02085X40 | stainless steel | light grey RAL 7035   | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02086X40 | stainless steel | traffic red RAL 3020  | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.02087X40 | stainless steel | colza yellow RAL 1021 | M8  | 26 | 18 | 23 | 26 | 9,5 | 40 |
| K0247.0310X20  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03101X20 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03102X20 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03103X20 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03105X20 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03106X20 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.03107X20 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 20 |
| K0247.0310X30  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03101X30 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03102X30 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03103X30 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03105X30 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03106X30 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.03107X30 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 30 |
| K0247.0310X40  | stainless steel | black grey RAL 7021   | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03101X40 | stainless steel | orange RAL 2004       | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03102X40 | stainless steel | signal green RAL6032  | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03103X40 | stainless steel | blue RAL5017          | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03105X40 | stainless steel | light grey RAL 7035   | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03106X40 | stainless steel | traffic red RAL 3020  | M10 | 34 | 22 | 31 | 36 | 13  | 40 |
| K0247.03107X40 | stainless steel | colza yellow RAL 1021 | M10 | 34 | 22 | 31 | 36 | 13  | 40 |