


LOCTITE bonding agents (accessories)

Item description/product images

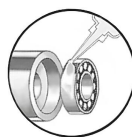

Bonds bushes and bearings

Description

Note:

To fasten bushes, bearings and sleeves in the slide, press and shrink fit. Full surface contact prevents play, corrosion and fretting corrosion.

Special LOCTITE adhesive product, K0655.638....

Large gap-filling capacity as well as quickly finger-tight. Temperature resistance from -55 °C to +150 °C.

Universal LOCTITE adhesive product, K0655.648....

Good gap-filling capacity, quickly finger-tight and excellent temperature resistance. Temperature resistance from -55 °C to +175 °C.

Note:

Safety data sheets (see downloads) can be found officially and in various languages on the internet under the search term: 'Henkel Documents'.

LOCTITE bonding agents (accessories)

Drawings



Overview of items

Order No.	Version 1	Container	Shearing strength N/mm²	Break-away torque Nm	Temperature resistance
K0655.6380010	retaining compound	10 ml bottle	20-35	35-60	-55 °C - +150 °C
K0655.6480010	retaining compound	10 ml bottle	16-30	30-55	-55 °C - +175 °C