

Quarter-turn locks

Item description/product images



Description

Material:

Housing, actuator and nut, die-cast zinc or PA6 GFR 30 plastic.
Flat seal rubber.
Tongue steel.

Version:

Housing, actuator and nut trivalent passivated or black.
Tongue electro zinc-plated.

Note:

Quarter-turn lock with spring-loaded tongue. Right or left deployment. The lock can be installed pre-assembled. The fastening nut is an earthing nut with teeth one side.

Vibration-proof (except plastic version), a catch prevents independent opening.
Water and dust tight according to IP65.

Please order the desired tongue type separately. Every tongue can be combined with every housing.

Accessory:


Key K0535

Drawing reference:

Actuation:

- a) square 7 mm
- b) square 8 mm
- c) slot
- d) double lug 3 mm
- e) double lug 5 mm

Drawings

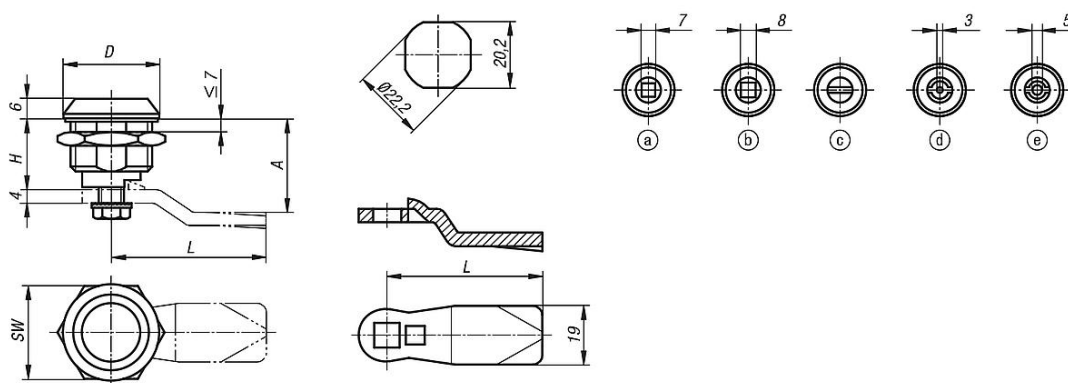

Overview of items

Quarter-turn locks

| Order No. | Main material | D | Actuation | SW | H |
|-------------|---------------|----|-------------|----|------|
| K0522.17181 | zinc | 30 | square 7 mm | 27 | 18,5 |
| K0522.18181 | zinc | 30 | square 8 mm | 27 | 18,5 |

Quarter-turn locks

Overview of items

| Order No. | Main material | D | Actuation | SW | H |
|-------------|---------------|----|-----------------|----|------|
| K0522.20181 | zinc | 30 | slot | 27 | 18,5 |
| K0522.43181 | zinc | 30 | double lug 3 mm | 27 | 18,5 |
| K0522.45181 | zinc | 30 | double lug 5 mm | 27 | 18,5 |
| K0522.20185 | plastic | 28 | slot | 27 | 18,5 |
| K0522.43185 | plastic | 28 | double lug 3 mm | 27 | 18,5 |
| K0522.45185 | plastic | 28 | double lug 5 mm | 27 | 18,5 |

Tongue for quarter-turn lock

| Order No. | A | L |
|---------------|------|----|
| K0523.135X165 | 16,5 | 35 |
| K0523.135X185 | 18,5 | 35 |
| K0523.135X205 | 20,5 | 35 |
| K0523.135X225 | 22,5 | 35 |
| K0523.135X245 | 24,5 | 35 |
| K0523.145X045 | 4,5 | 45 |
| K0523.145X065 | 6,5 | 45 |
| K0523.145X085 | 8,5 | 45 |
| K0523.145X105 | 10,5 | 45 |
| K0523.145X125 | 12,5 | 45 |
| K0523.145X145 | 14,5 | 45 |
| K0523.145X165 | 16,5 | 45 |
| K0523.145X185 | 18,5 | 45 |
| K0523.145X205 | 20,5 | 45 |
| K0523.145X215 | 21,5 | 45 |
| K0523.145X225 | 22,5 | 45 |
| K0523.145X245 | 24,5 | 45 |
| K0523.145X265 | 26,5 | 45 |
| K0523.145X285 | 28,5 | 45 |
| K0523.145X305 | 30,5 | 45 |
| K0523.145X325 | 32,5 | 45 |
| K0523.145X345 | 34,5 | 45 |
| K0523.145X365 | 36,5 | 45 |
| K0523.145X385 | 38,5 | 45 |
| K0523.145X405 | 40,5 | 45 |
| K0523.145X425 | 42,5 | 45 |