

# Precision indexing plungers, steel with plastic spherical knob, cylindrical indexing pin and locking slot

Item description/product images



## Description

### Material:

Steel.  
Grip ball thermoplastic.

### Version:


Hardened and ground.  
Grip ball black grey.

### Note:

The indexing plungers with bushes are a perfect combination for rapid positioning and fixing. The precise design of both the indexing plungers and the bush guarantees high repeating accuracy when assembling two elements.

Technical Information see assembly and installation instructions.

## Drawings

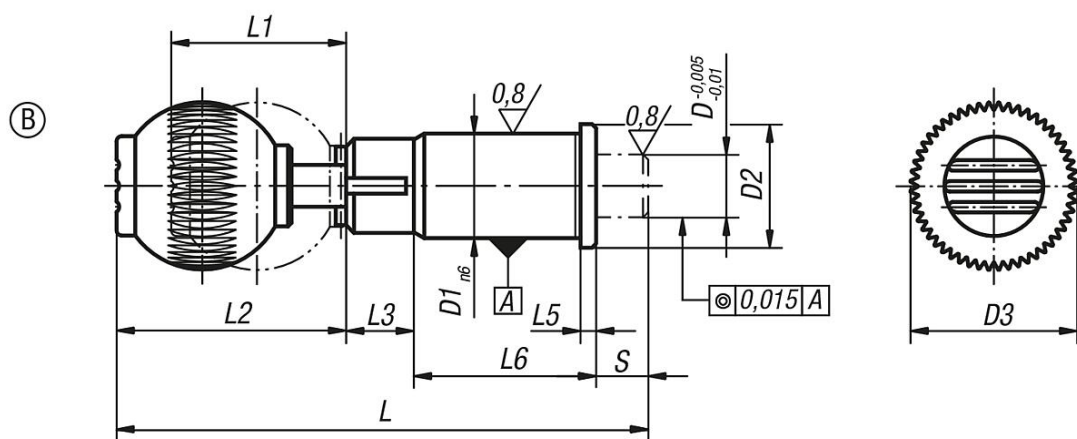

## Overview of items

### Precision indexing plungers with cylindrical pin

Order No.	Form	D	D1	D2	D3	L	L1	L2	L3	L5	L6	Travel S	Spring force initial pressure F1 approx. N	Spring force final pressure F2 approx. N	female thread grip ball
K0361.110	B	10	16	19	25	79	25	36,5	13	2,5	31	10	15	30	M6
K0361.112	B	12	20	23	32	91	33	44,5	13	3	35	10	15	35	M8
K0361.116	B	16	25	28	40	106,5	41,5	53	13	3	42	10	20	50	M10
K0361.120	B	20	30	33	40	114,5	41,5	53	13	3	50	10	36	63	M10
K0361.125	B	25	38	42	50	134	51	62,5	13	3	60	10	20	73	M10

**Precision indexing plungers, steel with plastic spherical knob,  
cylindrical indexing pin and locking slot**

Overview of items

---