


## Hexagon head bolts DIN 933/ISO 4017, stainless steel

## Item description/product images

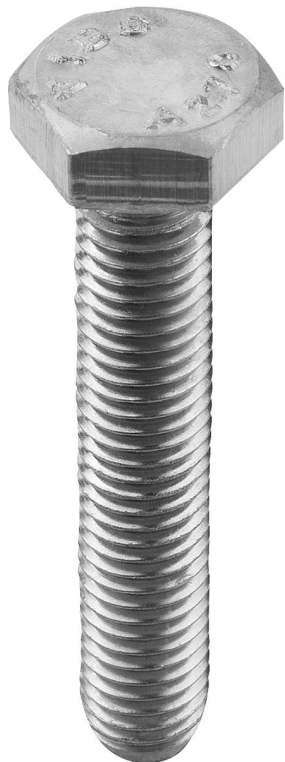

## Description

## Material:


Stainless steel A2 or stainless steel A4.

## Version:

Stainless steel A2-70, bright.

Stainless steel A4-70, bright.

## Drawings

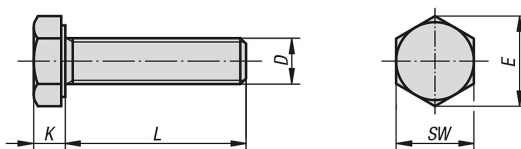

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	K	SW	E	DIN	ISO
K0871.104X10	stainless steel A2	70	bright	M4	10	2,8	7	7,66	DIN 933	-
K0871.104X12	stainless steel A2	70	bright	M4	12	2,8	7	7,66	DIN 933	-
K0871.104X16	stainless steel A2	70	bright	M4	16	2,8	7	7,66	DIN 933	-
K0871.104X18	stainless steel A2	70	bright	M4	18	2,8	7	7,66	DIN 933	-
K0871.104X20	stainless steel A2	70	bright	M4	20	2,8	7	7,66	DIN 933	-
K0871.104X25	stainless steel A2	70	bright	M4	25	2,8	7	7,66	DIN 933	-
K0871.105X10	stainless steel A2	70	bright	M5	10	3,5	8	8,79	DIN 933	-
K0871.105X12	stainless steel A2	70	bright	M5	12	3,5	8	8,79	DIN 933	-
K0871.105X16	stainless steel A2	70	bright	M5	16	3,5	8	8,79	DIN 933	-
K0871.105X18	stainless steel A2	70	bright	M5	18	3,5	8	8,79	DIN 933	-
K0871.105X20	stainless steel A2	70	bright	M5	20	3,5	8	8,79	DIN 933	-
K0871.105X25	stainless steel A2	70	bright	M5	25	3,5	8	8,79	DIN 933	-
K0871.105X30	stainless steel A2	70	bright	M5	30	3,5	8	8,79	DIN 933	-
K0871.105X35	stainless steel A2	70	bright	M5	35	3,5	8	8,79	DIN 933	-
K0871.105X40	stainless steel A2	70	bright	M5	40	3,5	8	8,79	DIN 933	-
K0871.106X10	stainless steel A2	70	bright	M6	10	4	10	11,05	DIN 933	-

## Hexagon head bolts DIN 933/ISO 4017, stainless steel

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	K	SW	E	DIN	ISO
K0871.106X12	stainless steel A2	70	bright	M6	12	4	10	11,05	DIN 933	-
K0871.106X16	stainless steel A2	70	bright	M6	16	4	10	11,05	DIN 933	-
K0871.106X18	stainless steel A2	70	bright	M6	18	4	10	11,05	DIN 933	-
K0871.106X20	stainless steel A2	70	bright	M6	20	4	10	11,05	DIN 933	-
K0871.106X25	stainless steel A2	70	bright	M6	25	4	10	11,05	DIN 933	-
K0871.106X30	stainless steel A2	70	bright	M6	30	4	10	11,05	DIN 933	-
K0871.106X35	stainless steel A2	70	bright	M6	35	4	10	11,05	DIN 933	-
K0871.106X40	stainless steel A2	70	bright	M6	40	4	10	11,05	DIN 933	-
K0871.106X45	stainless steel A2	70	bright	M6	45	4	10	11,05	DIN 933	-
K0871.106X50	stainless steel A2	70	bright	M6	50	4	10	11,05	DIN 933	-
K0871.106X55	stainless steel A2	70	bright	M6	55	4	10	11,05	DIN 933	-
K0871.106X60	stainless steel A2	70	bright	M6	60	4	10	11,05	DIN 933	-
K0871.108X16	stainless steel A2	70	bright	M8	16	5,3	13	14,38	DIN 933	-
K0871.108X18	stainless steel A2	70	bright	M8	18	5,3	13	14,38	DIN 933	-
K0871.108X20	stainless steel A2	70	bright	M8	20	5,3	13	14,38	DIN 933	-
K0871.108X25	stainless steel A2	70	bright	M8	25	5,3	13	14,38	DIN 933	-
K0871.108X30	stainless steel A2	70	bright	M8	30	5,3	13	14,38	DIN 933	-
K0871.108X35	stainless steel A2	70	bright	M8	35	5,3	13	14,38	DIN 933	-
K0871.108X40	stainless steel A2	70	bright	M8	40	5,3	13	14,38	DIN 933	-
K0871.108X45	stainless steel A2	70	bright	M8	45	5,3	13	14,38	DIN 933	-
K0871.108X50	stainless steel A2	70	bright	M8	50	5,3	13	14,38	DIN 933	-
K0871.108X60	stainless steel A2	70	bright	M8	60	5,3	13	14,38	DIN 933	-
K0871.108X70	stainless steel A2	70	bright	M8	70	5,3	13	14,38	DIN 933	-
K0871.108X80	stainless steel A2	70	bright	M8	80	5,3	13	14,38	DIN 933	-
K0871.108X90	stainless steel A2	70	bright	M8	90	5,3	13	14,38	DIN 933	-
K0871.108X100	stainless steel A2	70	bright	M8	100	5,3	13	14,38	DIN 933	-
K0871.110X16	stainless steel A2	70	bright	M10	16	6,4	17	18,9	DIN 933	-
K0871.110X18	stainless steel A2	70	bright	M10	18	6,4	17	18,9	DIN 933	-
K0871.110X20	stainless steel A2	70	bright	M10	20	6,4	17	18,9	DIN 933	-
K0871.110X25	stainless steel A2	70	bright	M10	25	6,4	17	18,9	DIN 933	-
K0871.110X30	stainless steel A2	70	bright	M10	30	6,4	17	18,9	DIN 933	-
K0871.110X35	stainless steel A2	70	bright	M10	35	6,4	17	18,9	DIN 933	-
K0871.110X40	stainless steel A2	70	bright	M10	40	6,4	17	18,9	DIN 933	-
K0871.110X45	stainless steel A2	70	bright	M10	45	6,4	17	18,9	DIN 933	-
K0871.110X50	stainless steel A2	70	bright	M10	50	6,4	17	18,9	DIN 933	-
K0871.110X60	stainless steel A2	70	bright	M10	60	6,4	17	18,9	DIN 933	-
K0871.110X70	stainless steel A2	70	bright	M10	70	6,4	17	18,9	DIN 933	-
K0871.110X80	stainless steel A2	70	bright	M10	80	6,4	17	18,9	DIN 933	-
K0871.110X90	stainless steel A2	70	bright	M10	90	6,4	17	18,9	DIN 933	-
K0871.110X100	stainless steel A2	70	bright	M10	100	6,4	17	18,9	DIN 933	-
K0871.112X20	stainless steel A2	70	bright	M12	20	7,5	19	21,1	DIN 933	-
K0871.112X25	stainless steel A2	70	bright	M12	25	7,5	19	21,1	DIN 933	-
K0871.112X30	stainless steel A2	70	bright	M12	30	7,5	19	21,1	DIN 933	-
K0871.112X35	stainless steel A2	70	bright	M12	35	7,5	19	21,1	DIN 933	-
K0871.112X40	stainless steel A2	70	bright	M12	40	7,5	19	21,1	DIN 933	-
K0871.112X45	stainless steel A2	70	bright	M12	45	7,5	19	21,1	DIN 933	-
K0871.112X50	stainless steel A2	70	bright	M12	50	7,5	19	21,1	DIN 933	-
K0871.112X60	stainless steel A2	70	bright	M12	60	7,5	19	21,1	DIN 933	-
K0871.112X70	stainless steel A2	70	bright	M12	70	7,5	19	21,1	DIN 933	-
K0871.112X80	stainless steel A2	70	bright	M12	80	7,5	19	21,1	DIN 933	-
K0871.112X90	stainless steel A2	70	bright	M12	90	7,5	19	21,1	DIN 933	-
K0871.112X100	stainless steel A2	70	bright	M12	100	7,5	19	21,1	DIN 933	-
K0871.112X110	stainless steel A2	70	bright	M12	110	7,5	19	21,1	DIN 933	-
K0871.112X120	stainless steel A2	70	bright	M12	120	7,5	19	21,1	DIN 933	-
K0871.116X30	stainless steel A2	70	bright	M16	30	10	24	26,75	DIN 933	-
K0871.116X35	stainless steel A2	70	bright	M16	35	10	24	26,75	DIN 933	-
K0871.116X40	stainless steel A2	70	bright	M16	40	10	24	26,75	DIN 933	-
K0871.116X45	stainless steel A2	70	bright	M16	45	10	24	26,75	DIN 933	-
K0871.116X50	stainless steel A2	70	bright	M16	50	10	24	26,75	DIN 933	-
K0871.116X60	stainless steel A2	70	bright	M16	60	10	24	26,75	DIN 933	-
K0871.116X70	stainless steel A2	70	bright	M16	70	10	24	26,75	DIN 933	-
K0871.116X80	stainless steel A2	70	bright	M16	80	10	24	26,75	DIN 933	-

## Hexagon head bolts DIN 933/ISO 4017, stainless steel

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	K	SW	E	DIN	ISO
K0871.116X90	stainless steel A2	70	bright	M16	90	10	24	26,75	DIN 933	-
K0871.116X100	stainless steel A2	70	bright	M16	100	10	24	26,75	DIN 933	-
K0871.116X110	stainless steel A2	70	bright	M16	110	10	24	26,75	DIN 933	-
K0871.116X120	stainless steel A2	70	bright	M16	120	10	24	26,75	DIN 933	-
K0871.120X40	stainless steel A2	70	bright	M20	40	12,5	30	33,53	DIN 933	-
K0871.120X45	stainless steel A2	70	bright	M20	45	12,5	30	33,53	DIN 933	-
K0871.120X50	stainless steel A2	70	bright	M20	50	12,5	30	33,53	DIN 933	-
K0871.120X60	stainless steel A2	70	bright	M20	60	12,5	30	33,53	DIN 933	-
K0871.120X70	stainless steel A2	70	bright	M20	70	12,5	30	33,53	DIN 933	-
K0871.120X80	stainless steel A2	70	bright	M20	80	12,5	30	33,53	DIN 933	-
K0871.120X90	stainless steel A2	70	bright	M20	90	12,5	30	33,53	DIN 933	-
K0871.120X100	stainless steel A2	70	bright	M20	100	12,5	30	33,53	DIN 933	-
K0871.120X110	stainless steel A2	70	bright	M20	110	12,5	30	33,53	DIN 933	-
K0871.120X120	stainless steel A2	70	bright	M20	120	12,5	30	33,53	DIN 933	-
K0871.603X06	stainless steel A4	70	bright	M3	6	2	5,5	6,01	DIN 933	ISO 4017
K0871.603X08	stainless steel A4	70	bright	M3	8	2	5,5	6,01	DIN 933	ISO 4017
K0871.603X10	stainless steel A4	70	bright	M3	10	2	5,5	6,01	DIN 933	ISO 4017
K0871.604X08	stainless steel A4	70	bright	M4	8	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X10	stainless steel A4	70	bright	M4	10	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X12	stainless steel A4	70	bright	M4	12	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X16	stainless steel A4	70	bright	M4	16	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X18	stainless steel A4	70	bright	M4	18	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X20	stainless steel A4	70	bright	M4	20	2,8	7	7,66	DIN 933	ISO 4017
K0871.604X25	stainless steel A4	70	bright	M4	25	2,8	7	7,66	DIN 933	ISO 4017
K0871.605X10	stainless steel A4	70	bright	M5	10	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X12	stainless steel A4	70	bright	M5	12	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X16	stainless steel A4	70	bright	M5	16	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X18	stainless steel A4	70	bright	M5	18	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X20	stainless steel A4	70	bright	M5	20	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X25	stainless steel A4	70	bright	M5	25	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X30	stainless steel A4	70	bright	M5	30	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X35	stainless steel A4	70	bright	M5	35	3,5	8	8,79	DIN 933	ISO 4017
K0871.605X40	stainless steel A4	70	bright	M5	40	3,5	8	8,79	DIN 933	ISO 4017
K0871.606X10	stainless steel A4	70	bright	M6	10	4	10	11,05	DIN 933	ISO 4017
K0871.606X12	stainless steel A4	70	bright	M6	12	4	10	11,05	DIN 933	ISO 4017
K0871.606X16	stainless steel A4	70	bright	M6	16	4	10	11,05	DIN 933	ISO 4017
K0871.606X20	stainless steel A4	70	bright	M6	20	4	10	11,05	DIN 933	ISO 4017
K0871.606X25	stainless steel A4	70	bright	M6	25	4	10	11,05	DIN 933	ISO 4017
K0871.606X30	stainless steel A4	70	bright	M6	30	4	10	11,05	DIN 933	ISO 4017
K0871.606X35	stainless steel A4	70	bright	M6	35	4	10	11,05	DIN 933	ISO 4017
K0871.606X40	stainless steel A4	70	bright	M6	40	4	10	11,05	DIN 933	ISO 4017
K0871.606X45	stainless steel A4	70	bright	M6	45	4	10	11,05	DIN 933	ISO 4017
K0871.606X50	stainless steel A4	70	bright	M6	50	4	10	11,05	DIN 933	ISO 4017
K0871.606X55	stainless steel A4	70	bright	M6	55	4	10	11,05	DIN 933	ISO 4017
K0871.606X60	stainless steel A4	70	bright	M6	60	4	10	11,05	DIN 933	ISO 4017
K0871.608X16	stainless steel A4	70	bright	M8	16	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X18	stainless steel A4	70	bright	M8	18	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X20	stainless steel A4	70	bright	M8	20	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X25	stainless steel A4	70	bright	M8	25	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X30	stainless steel A4	70	bright	M8	30	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X35	stainless steel A4	70	bright	M8	35	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X40	stainless steel A4	70	bright	M8	40	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X45	stainless steel A4	70	bright	M8	45	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X50	stainless steel A4	70	bright	M8	50	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X60	stainless steel A4	70	bright	M8	60	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X70	stainless steel A4	70	bright	M8	70	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X80	stainless steel A4	70	bright	M8	80	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X90	stainless steel A4	70	bright	M8	90	5,3	13	14,38	DIN 933	ISO 4017
K0871.608X100	stainless steel A4	70	bright	M8	100	5,3	13	14,38	DIN 933	ISO 4017
K0871.610X16	stainless steel A4	70	bright	M10	16	6,4	17	18,9	DIN 933	-
K0871.610X20	stainless steel A4	70	bright	M10	20	6,4	17	18,9	DIN 933	-
K0871.610X25	stainless steel A4	70	bright	M10	25	6,4	17	18,9	DIN 933	-

## Hexagon head bolts DIN 933/ISO 4017, stainless steel

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	K	SW	E	DIN	ISO
K0871.610X30	stainless steel A4	70	bright	M10	30	6,4	17	18,9	DIN 933	-
K0871.610X35	stainless steel A4	70	bright	M10	35	6,4	17	18,9	DIN 933	-
K0871.610X40	stainless steel A4	70	bright	M10	40	6,4	17	18,9	DIN 933	-
K0871.610X45	stainless steel A4	70	bright	M10	45	6,4	17	18,9	DIN 933	-
K0871.610X50	stainless steel A4	70	bright	M10	50	6,4	17	18,9	DIN 933	-
K0871.610X60	stainless steel A4	70	bright	M10	60	6,4	17	18,9	DIN 933	-
K0871.610X70	stainless steel A4	70	bright	M10	70	6,4	17	18,9	DIN 933	-
K0871.610X80	stainless steel A4	70	bright	M10	80	6,4	17	18,9	DIN 933	-
K0871.610X90	stainless steel A4	70	bright	M10	90	6,4	17	18,9	DIN 933	-
K0871.610X100	stainless steel A4	70	bright	M10	100	6,4	17	18,9	DIN 933	-
K0871.612X20	stainless steel A4	70	bright	M12	20	7,5	19	21,1	DIN 933	-
K0871.612X25	stainless steel A4	70	bright	M12	25	7,5	19	21,1	DIN 933	-
K0871.612X30	stainless steel A4	70	bright	M12	30	7,5	19	21,1	DIN 933	-
K0871.612X35	stainless steel A4	70	bright	M12	35	7,5	19	21,1	DIN 933	-
K0871.612X40	stainless steel A4	70	bright	M12	40	7,5	19	21,1	DIN 933	-
K0871.612X45	stainless steel A4	70	bright	M12	45	7,5	19	21,1	DIN 933	-
K0871.612X50	stainless steel A4	70	bright	M12	50	7,5	19	21,1	DIN 933	-
K0871.612X60	stainless steel A4	70	bright	M12	60	7,5	19	21,1	DIN 933	-
K0871.612X70	stainless steel A4	70	bright	M12	70	7,5	19	21,1	DIN 933	-
K0871.612X80	stainless steel A4	70	bright	M12	80	7,5	19	21,1	DIN 933	-
K0871.612X90	stainless steel A4	70	bright	M12	90	7,5	19	21,1	DIN 933	-
K0871.612X100	stainless steel A4	70	bright	M12	100	7,5	19	21,1	DIN 933	-
K0871.612X110	stainless steel A4	70	bright	M12	110	7,5	19	21,1	DIN 933	-
K0871.612X120	stainless steel A4	70	bright	M12	120	7,5	19	21,1	DIN 933	-
K0871.616X30	stainless steel A4	70	bright	M16	30	10	24	26,75	DIN 933	ISO 4017
K0871.616X35	stainless steel A4	70	bright	M16	35	10	24	26,75	DIN 933	ISO 4017
K0871.616X40	stainless steel A4	70	bright	M16	40	10	24	26,75	DIN 933	ISO 4017
K0871.616X45	stainless steel A4	70	bright	M16	45	10	24	26,75	DIN 933	ISO 4017
K0871.616X50	stainless steel A4	70	bright	M16	50	10	24	26,75	DIN 933	ISO 4017
K0871.616X60	stainless steel A4	70	bright	M16	60	10	24	26,75	DIN 933	ISO 4017
K0871.616X70	stainless steel A4	70	bright	M16	70	10	24	26,75	DIN 933	ISO 4017
K0871.616X80	stainless steel A4	70	bright	M16	80	10	24	26,75	DIN 933	ISO 4017
K0871.616X90	stainless steel A4	70	bright	M16	90	10	24	26,75	DIN 933	ISO 4017
K0871.616X100	stainless steel A4	70	bright	M16	100	10	24	26,75	DIN 933	ISO 4017
K0871.616X110	stainless steel A4	70	bright	M16	110	10	24	26,75	DIN 933	ISO 4017
K0871.616X120	stainless steel A4	70	bright	M16	120	10	24	26,75	DIN 933	ISO 4017
K0871.620X40	stainless steel A4	70	bright	M20	40	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X45	stainless steel A4	70	bright	M20	45	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X50	stainless steel A4	70	bright	M20	50	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X60	stainless steel A4	70	bright	M20	60	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X70	stainless steel A4	70	bright	M20	70	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X80	stainless steel A4	70	bright	M20	80	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X90	stainless steel A4	70	bright	M20	90	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X100	stainless steel A4	70	bright	M20	100	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X110	stainless steel A4	70	bright	M20	110	12,5	30	33,53	DIN 933	ISO 4017
K0871.620X120	stainless steel A4	70	bright	M20	120	12,5	30	33,53	DIN 933	ISO 4017