

Magnets raw, Form B with hole, NdFeB, disc form

Item description/product images



Description

Material:
NdFeB (neodymium).

Version:
Electro zinc-plated.


Note:
Unshielded system.

Temperature range:
max. 80°C.

Assembly:
The magnets can be mounted by press-fit, screwing-in or gluing.

Drawing reference:
1) magnetic face

Drawings

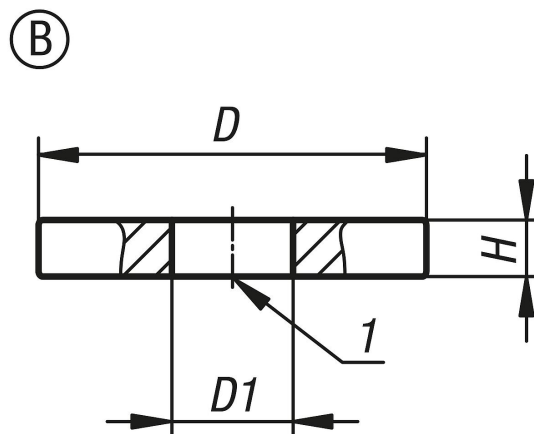

Overview of items

Order No.	Form	D	D1	H	Tightening torque max. Nm	Magnetic force N
K1405.32	B	32 ±0,1	10,5 ±0,1	2 ±0,1	3	42
K1405.38	B	38 ±0,1	12 ±0,1	4 ±0,1	3	110
K1405.48	B	48 ±0,2	15 ±0,1	5 ±0,1	3	165
K1405.56	B	56 ±0,2	15 ±0,1	6 ±0,1	3	230