

Tension levers with internal thread, 0 degrees

Item description/product images



Description

Material:

Steel parts grade 5.8.
Ball knob black plastic.

Version:

Black oxidised.


Note:

Tension levers can be used for simple clamping or control operations.
Where applicable, there must be enough space available so that the grip can be rotated 360°.

On request:

Other female threads, reamed holes and special versions.
Dimension "A" available in other lengths at extra charge.

Drawings

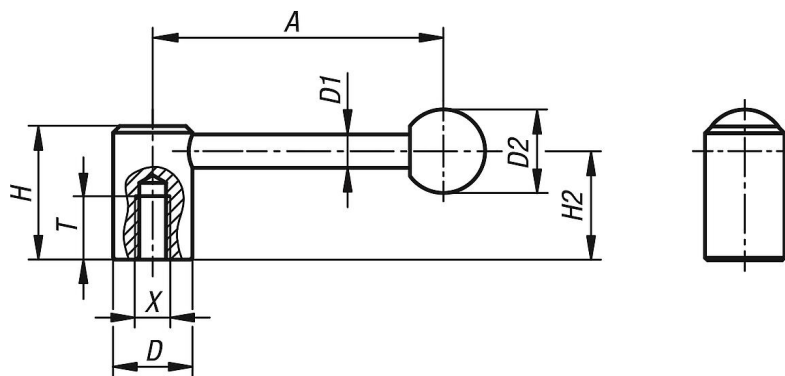

Overview of items

Order No.	Kind of fastening	X	T	A=Handle length	D	D1	D2	H	H2
K0176.2082	internal thread	M8	18	88,1	24	10	25	40	32,5
K0176.2102	internal thread	M10	18	88,1	24	10	25	40	32,5
K0176.21012	internal thread	M10	20	104	28	12	32	46	36,5
K0176.2122	internal thread	M12	20	104	28	12	32	46	36,5
K0176.2162	internal thread	M16	23	126,5	33	13	32	52	41
K0176.2202	internal thread	M20	26	128,5	41	13	32	61	49