

Latches, fastening holes hidden

Item description/product images



Description

Material:

Die-cast zinc.

Version:

Black powder-coated, high-gloss chromed or matt chromed.

Note:

Latches for the easy and secure locking of doors and hatches. The toggle system makes them vibration proof.

The latches can be screwed on or riveted. We recommend using M3 countersunk screws to fasten the components.


The die-cast housing conceals all functional parts and so secures against dismantling when closed.

2 keys are supplied with the version that has a cylinder lock. The key can be removed in both positions (open and closed). The locks have a single key system, i.e. all locks can be opened with the same key.

Max. load capacity is 1,200 N.

Supplied with catch plate.

Drawings

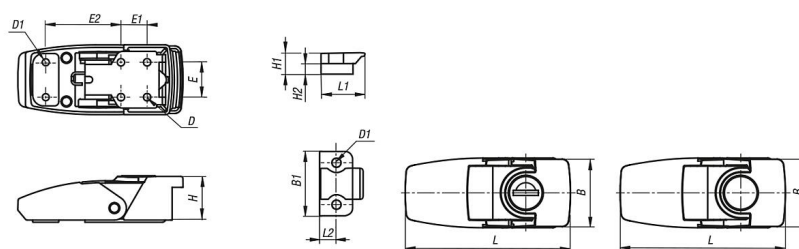

Overview of items

Latches, fastening holes hidden

Order No.	Version 1	Main colour	Surface finish body	L	B	H	B1	D	D1	E	E1	E2	H1	H2	L1	L2
K2359.10064	not lockable	black	powder-coated	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.20064	not lockable	-	high-gloss chromed	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.30064	not lockable	-	matt chromed	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.10076	not lockable	black	powder-coated	76	32	21	24	3,2	3,2	16	12	34,5	8	4	16	6
K2359.20076	not lockable	-	high-gloss chromed	76	32	21	24	3,2	3,2	16	12	34,7	8	4	16	6
K2359.30076	not lockable	-	matt chromed	76	32	21	24	3,2	3,2	16	12	34,9	8	4	16	6
K2359.11064	lockable	black	powder-coated	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.21064	lockable	-	high-gloss chromed	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.31064	lockable	-	matt chromed	64,8	26,5	18	19,7	3,2	3,2	12	12	30	6,5	3,5	15,5	6
K2359.11076	lockable	black	powder-coated	76	32	21	24	3,2	3,2	16	12	34,6	8	4	16	6
K2359.21076	lockable	-	high-gloss chromed	76	32	21	24	3,2	3,2	16	12	34,8	8	4	16	6

Latches, fastening holes hidden

Overview of items

Order No.	Version 1	Main colour	Surface finish body	L	B	H	B1	D	D1	E	E1	E2	H1	H2	L1	L2
K2359.31076	lockable	-	matt chromed	76	32	21	24	3,2	3,2	16	12	34,1	8	4	16	6