

## Quarter-turn locks, stainless steel long version

### Item description/product images



### Description

**Material:**

Housing, stainless steel 1.4305.

Actuation and fastening nut, stainless steel 1.4404.

**Version:**

Bright.

**Note:**

The quarter turn lock can be installed pre-assembled. For right or left use. Water and dust protected acc. to IP65 from DIN EN 60529.

Please order required tongue version separately. Every tongue can be combined with every housing.

\*Dimension A results from the combination of the quarter turn lock and the tongue and is specified with the matching tongues.

**Accessory:**

Key K0535.

Tongue for stainless steel quarter-turn lock K1340.

**Drawing reference:**

Actuation:


- a) square 7 mm
- b) square 8 mm
- c) double lug 3 mm
- d) double lug 5 mm
- e) T-grip
- f) triangle 7 mm

1) O-ring

2) flat seal

# Quarter-turn locks, stainless steel long version

## Drawings

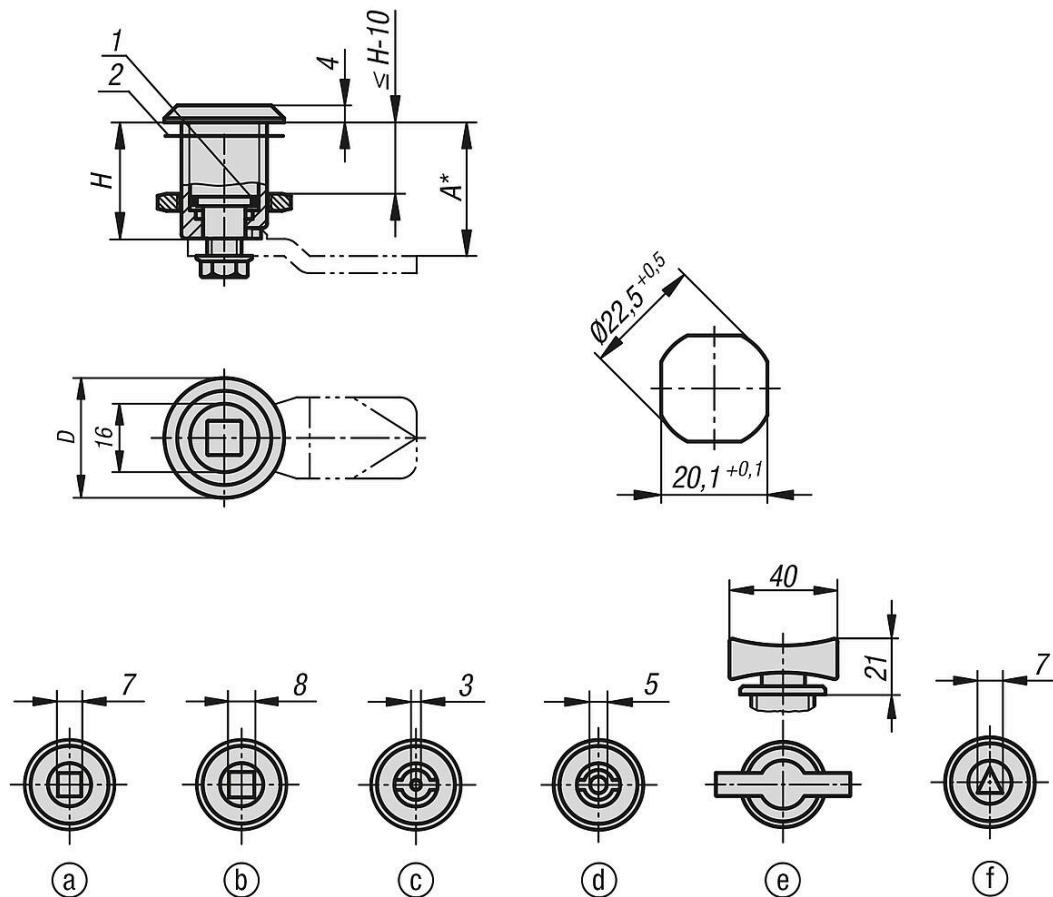

## Overview of items

### Quarter-turn locks, stainless steel, long version

| Order No.  | Actuation       | D  | H  | S<br>max. |
|------------|-----------------|----|----|-----------|
| K1352.1730 | square 7 mm     | 28 | 30 | 20        |
| K1352.1860 | square 8 mm     | 28 | 60 | 50        |
| K1352.4330 | double lug 3 mm | 28 | 30 | 20        |
| K1352.4336 | double lug 3 mm | 28 | 36 | 26        |
| K1352.4340 | double lug 3 mm | 28 | 40 | 30        |
| K1352.4350 | double lug 3 mm | 28 | 50 | 40        |
| K1352.4360 | double lug 3 mm | 28 | 60 | 50        |
| K1352.4530 | double lug 5 mm | 28 | 30 | 20        |
| K1352.4536 | double lug 5 mm | 28 | 36 | 26        |
| K1352.4540 | double lug 5 mm | 28 | 40 | 30        |
| K1352.4550 | double lug 5 mm | 28 | 50 | 40        |
| K1352.1736 | square 7 mm     | 28 | 36 | 26        |
| K1352.4560 | double lug 5 mm | 28 | 60 | 50        |
| K1352.0030 | wing grip       | 28 | 30 | 20        |
| K1352.0036 | wing grip       | 28 | 36 | 26        |
| K1352.0040 | wing grip       | 28 | 40 | 30        |
| K1352.0050 | wing grip       | 28 | 50 | 40        |
| K1352.0060 | wing grip       | 28 | 60 | 50        |
| K1352.1740 | square 7 mm     | 28 | 40 | 30        |
| K1352.1750 | square 7 mm     | 28 | 50 | 40        |
| K1352.1760 | square 7 mm     | 28 | 60 | 50        |
| K1352.1830 | square 8 mm     | 28 | 30 | 20        |

## Quarter-turn locks, stainless steel long version

### Overview of items

| Order No.  | Actuation     | D  | H  | S<br>max. |
|------------|---------------|----|----|-----------|
| K1352.1836 | square 8 mm   | 28 | 36 | 26        |
| K1352.1840 | square 8 mm   | 28 | 40 | 30        |
| K1352.1850 | square 8 mm   | 28 | 50 | 40        |
| K1352.8730 | Triangle 7 mm | 28 | 30 | 20        |
| K1352.8736 | Triangle 7 mm | 28 | 36 | 26        |
| K1352.8740 | Triangle 7 mm | 28 | 40 | 30        |
| K1352.8750 | Triangle 7 mm | 28 | 50 | 40        |
| K1352.8760 | Triangle 7 mm | 28 | 60 | 50        |