
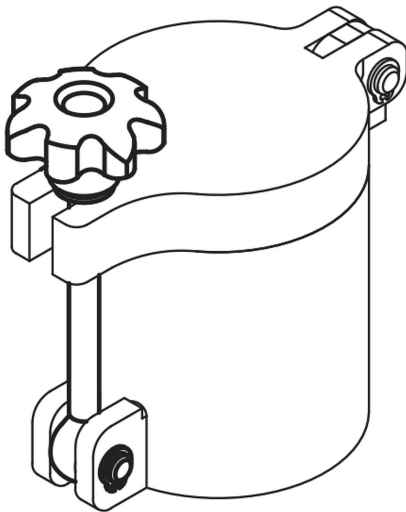


## Swing screws

### Item description/product images

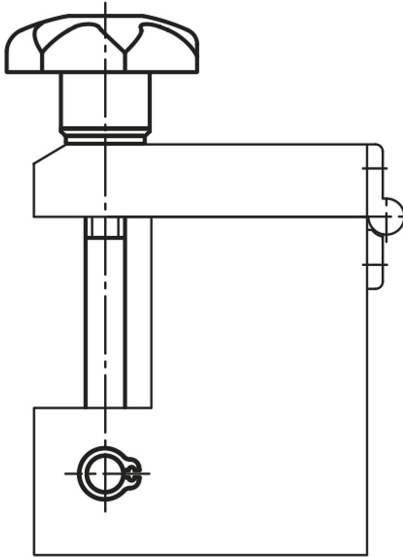

### Description

#### Material:

Star grip thermoplastic.  
 Bush steel.  
 Washer steel 140 HV.  
 Eye bolt steel grade 8.8.  
 Hinge pin steel 1.1181.

#### Version:


Star grip black.  
 Bush trivalent blue passivated  
 Washer bright.  
 Eye bolt black oxidised.  
 Hinge pins tempered, ground and bright.

#### Note:

The swing screws are supplied unassembled.  
 Suitable circlips are enclosed.

Swing screws

Drawings

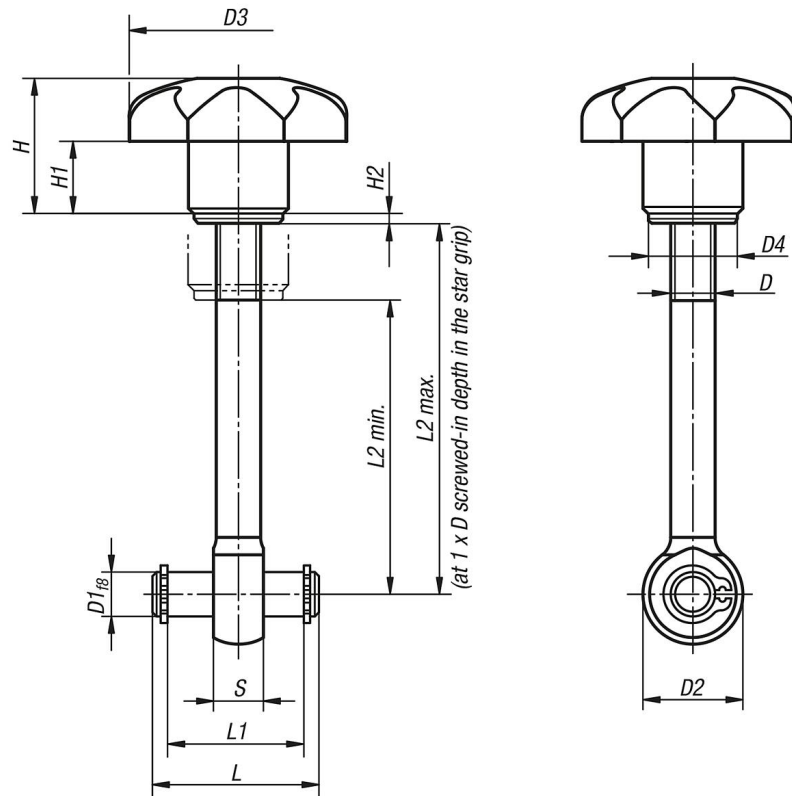

Overview of items

Swing screws

Order No.	D	D1	D2	D3	D4	H	H1	H2	L	L1	L2 min.	L2 max.	S
K0053.06050	M6	6	14	32	12	20	10	1,6	22	17	32	44	7
K0053.06075	M6	6	14	32	12	20	10	1,6	22	17	57	69	7
K0053.08050	M8	8	18	40	16	24	13	1,6	30	25	28	42	9
K0053.08075	M8	8	18	40	16	24	13	1,6	30	25	53	67	9
K0053.10075	M10	10	20	50	20	31	17	2	37	32	49	65	12
K0053.10100	M10	10	20	50	20	31	17	2	37	32	74	90	12