

Knurled knobs

Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	colza yellow RAL 1021	

Description

Material:

Black thermoplastic.
Bush and screw grade 5.8 steel.


Version:

Steel trivalent blue-passivated.

Drawing reference:

Form D: tapped bush without cap
Form K: tapped bush with cap
Form E: reamed bush without cap
Form H: reamed bush with cap
Form L: external thread

Drawings

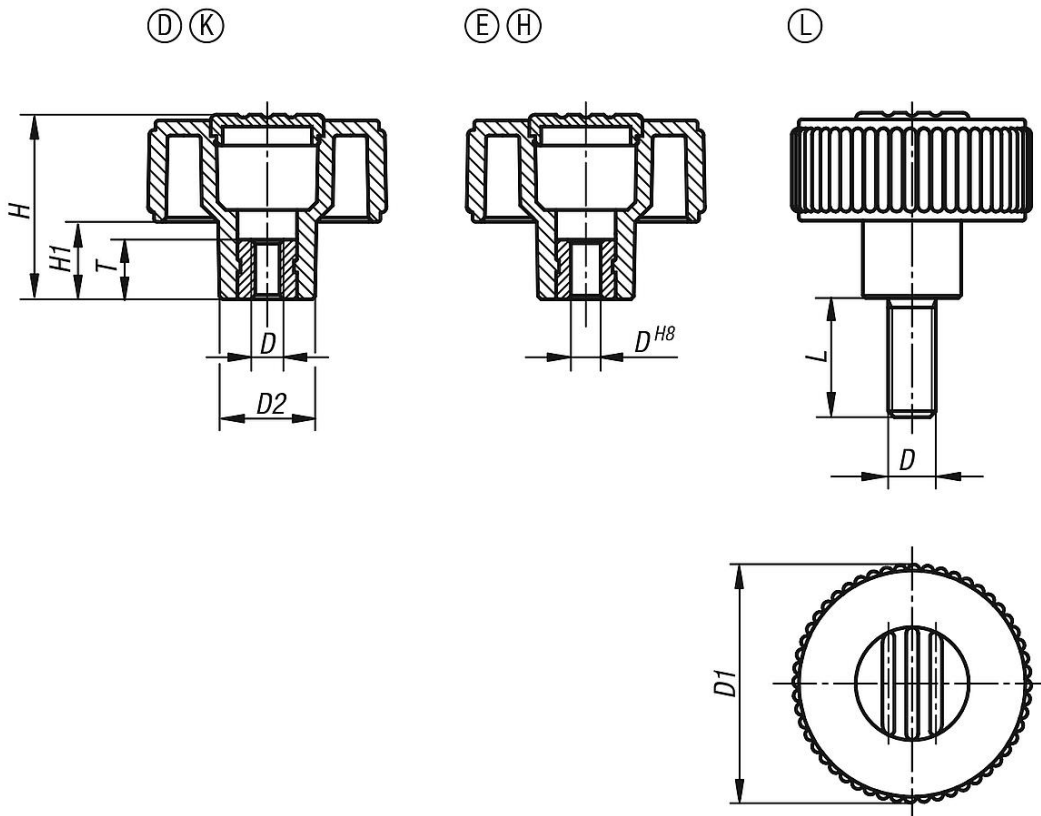

Overview of items

Knurled knobs Form D, with tapped bush, without cap

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T	L
K0260.1105	D	-	1	M5	40	16,5	30	13	10	-
K0260.1106	D	-	1	M6	40	16,5	30	13	10	-
K0260.1108	D	-	1	M8	40	16,5	30	13	14	-
K0260.1208	D	-	2	M8	50	18	35	15	14	-
K0260.1210	D	-	2	M10	50	18	35	15	14	-
K0260.1310	D	-	3	M10	63	22	40	17	14	-
K0260.1312	D	-	3	M12	63	22	40	17	18	-
K0260.2105	K	black grey RAL 7021	1	M5	40	16,5	31	13	10	-
K0260.21051	K	orange RAL 2004	1	M5	40	16,5	31	13	10	-
K0260.21052	K	signal green RAL6032	1	M5	40	16,5	31	13	10	-
K0260.21053	K	blue RAL5017	1	M5	40	16,5	31	13	10	-
K0260.21055	K	light grey RAL 7035	1	M5	40	16,5	31	13	10	-
K0260.21056	K	traffic red RAL 3020	1	M5	40	16,5	31	13	10	-
K0260.21057	K	colza yellow RAL 1021	1	M5	40	16,5	31	13	10	-
K0260.2106	K	black grey RAL 7021	1	M6	40	16,5	31	13	10	-
K0260.21061	K	orange RAL 2004	1	M6	40	16,5	31	13	10	-
K0260.21062	K	signal green RAL6032	1	M6	40	16,5	31	13	10	-
K0260.21063	K	blue RAL5017	1	M6	40	16,5	31	13	10	-
K0260.21065	K	light grey RAL 7035	1	M6	40	16,5	31	13	10	-
K0260.21066	K	traffic red RAL 3020	1	M6	40	16,5	31	13	10	-
K0260.21067	K	colza yellow RAL 1021	1	M6	40	16,5	31	13	10	-
K0260.2108	K	black grey RAL 7021	1	M8	40	16,5	31	13	14	-
K0260.21081	K	orange RAL 2004	1	M8	40	16,5	31	13	14	-
K0260.21082	K	signal green RAL6032	1	M8	40	16,5	31	13	14	-
K0260.21083	K	blue RAL5017	1	M8	40	16,5	31	13	14	-
K0260.21085	K	light grey RAL 7035	1	M8	40	16,5	31	13	14	-
K0260.21086	K	traffic red RAL 3020	1	M8	40	16,5	31	13	14	-
K0260.21087	K	colza yellow RAL 1021	1	M8	40	16,5	31	13	14	-
K0260.2208	K	black grey RAL 7021	2	M8	50	18	36	15	14	-
K0260.22081	K	orange RAL 2004	2	M8	50	18	36	15	14	-
K0260.22082	K	signal green RAL6032	2	M8	50	18	36	15	14	-
K0260.22083	K	blue RAL5017	2	M8	50	18	36	15	14	-
K0260.22085	K	light grey RAL 7035	2	M8	50	18	36	15	14	-
K0260.22086	K	traffic red RAL 3020	2	M8	50	18	36	15	14	-
K0260.22087	K	colza yellow RAL 1021	2	M8	50	18	36	15	14	-
K0260.2210	K	black grey RAL 7021	2	M10	50	18	36	15	14	-
K0260.22101	K	orange RAL 2004	2	M10	50	18	36	15	14	-
K0260.22102	K	signal green RAL6032	2	M10	50	18	36	15	14	-
K0260.22103	K	blue RAL5017	2	M10	50	18	36	15	14	-
K0260.22105	K	light grey RAL 7035	2	M10	50	18	36	15	14	-
K0260.22106	K	traffic red RAL 3020	2	M10	50	18	36	15	14	-
K0260.22107	K	colza yellow RAL 1021	2	M10	50	18	36	15	14	-
K0260.2310	K	black grey RAL 7021	3	M10	63	22	41	17	14	-
K0260.23101	K	orange RAL 2004	3	M10	63	22	41	17	14	-
K0260.23102	K	signal green RAL6032	3	M10	63	22	41	17	14	-
K0260.23103	K	blue RAL5017	3	M10	63	22	41	17	14	-
K0260.23105	K	light grey RAL 7035	3	M10	63	22	41	17	14	-
K0260.23106	K	traffic red RAL 3020	3	M10	63	22	41	17	14	-
K0260.23107	K	colza yellow RAL 1021	3	M10	63	22	41	17	14	-
K0260.2312	K	black grey RAL 7021	3	M12	63	22	41	17	18	-
K0260.23121	K	orange RAL 2004	3	M12	63	22	41	17	18	-
K0260.23122	K	signal green RAL6032	3	M12	63	22	41	17	18	-
K0260.23123	K	blue RAL5017	3	M12	63	22	41	17	18	-
K0260.23125	K	light grey RAL 7035	3	M12	63	22	41	17	18	-
K0260.23126	K	traffic red RAL 3020	3	M12	63	22	41	17	18	-
K0260.23127	K	colza yellow RAL 1021	3	M12	63	22	41	17	18	-
K0260.3106	E	-	1	6	40	16,5	30	13	10	-
K0260.3208	E	-	2	8	50	18	35	15	14	-
K0260.3310	E	-	3	10	63	22	40	17	14	-
K0260.4106	H	black grey RAL 7021	1	6	40	16,5	31	13	10	-
K0260.41061	H	orange RAL 2004	1	6	40	16,5	31	13	10	-
K0260.41062	H	signal green RAL6032	1	6	40	16,5	31	13	10	-

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T	L
K0260.41063	H	blue RAL5017	1	6	40	16,5	31	13	10	-
K0260.41065	H	light grey RAL 7035	1	6	40	16,5	31	13	10	-
K0260.41066	H	traffic red RAL 3020	1	6	40	16,5	31	13	10	-
K0260.41067	H	colza yellow RAL 1021	1	6	40	16,5	31	13	10	-
K0260.4208	H	black grey RAL 7021	2	8	50	18	36	15	14	-
K0260.42081	H	orange RAL 2004	2	8	50	18	36	15	14	-
K0260.42082	H	signal green RAL6032	2	8	50	18	36	15	14	-
K0260.42083	H	blue RAL5017	2	8	50	18	36	15	14	-
K0260.42085	H	light grey RAL 7035	2	8	50	18	36	15	14	-
K0260.42086	H	traffic red RAL 3020	2	8	50	18	36	15	14	-
K0260.42087	H	colza yellow RAL 1021	2	8	50	18	36	15	14	-
K0260.4310	H	black grey RAL 7021	3	10	63	22	41	17	14	-
K0260.43101	H	orange RAL 2004	3	10	63	22	41	17	14	-
K0260.43102	H	signal green RAL6032	3	10	63	22	41	17	14	-
K0260.43103	H	blue RAL5017	3	10	63	22	41	17	14	-
K0260.43105	H	light grey RAL 7035	3	10	63	22	41	17	14	-
K0260.43106	H	traffic red RAL 3020	3	10	63	22	41	17	14	-
K0260.43107	H	colza yellow RAL 1021	3	10	63	22	41	17	14	-
K0260.5105X10	L	black grey RAL 7021	1	M5	40	16,5	31	13	-	10
K0260.51051X10	L	orange RAL 2004	1	M5	40	16,5	31	13	-	10
K0260.51052X10	L	signal green RAL6032	1	M5	40	16,5	31	13	-	10
K0260.51053X10	L	blue RAL5017	1	M5	40	16,5	31	13	-	10
K0260.51055X10	L	light grey RAL 7035	1	M5	40	16,5	31	13	-	10
K0260.51056X10	L	traffic red RAL 3020	1	M5	40	16,5	31	13	-	10
K0260.51057X10	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	-	10
K0260.5105X20	L	black grey RAL 7021	1	M5	40	16,5	31	13	-	20
K0260.51051X20	L	orange RAL 2004	1	M5	40	16,5	31	13	-	20
K0260.51052X20	L	signal green RAL6032	1	M5	40	16,5	31	13	-	20
K0260.51053X20	L	blue RAL5017	1	M5	40	16,5	31	13	-	20
K0260.51055X20	L	light grey RAL 7035	1	M5	40	16,5	31	13	-	20
K0260.51056X20	L	traffic red RAL 3020	1	M5	40	16,5	31	13	-	20
K0260.51057X20	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	-	20
K0260.5105X40	L	black grey RAL 7021	1	M5	40	16,5	31	13	-	40
K0260.51051X40	L	orange RAL 2004	1	M5	40	16,5	31	13	-	40
K0260.51052X40	L	signal green RAL6032	1	M5	40	16,5	31	13	-	40
K0260.51053X40	L	blue RAL5017	1	M5	40	16,5	31	13	-	40
K0260.51055X40	L	light grey RAL 7035	1	M5	40	16,5	31	13	-	40
K0260.51056X40	L	traffic red RAL 3020	1	M5	40	16,5	31	13	-	40
K0260.51057X40	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	-	40
K0260.5106X10	L	black grey RAL 7021	1	M6	40	16,5	31	13	-	10
K0260.51061X10	L	orange RAL 2004	1	M6	40	16,5	31	13	-	10
K0260.51062X10	L	signal green RAL6032	1	M6	40	16,5	31	13	-	10
K0260.51063X10	L	blue RAL5017	1	M6	40	16,5	31	13	-	10
K0260.51065X10	L	light grey RAL 7035	1	M6	40	16,5	31	13	-	10
K0260.51066X10	L	traffic red RAL 3020	1	M6	40	16,5	31	13	-	10
K0260.51067X10	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	-	10
K0260.5106X20	L	black grey RAL 7021	1	M6	40	16,5	31	13	-	20
K0260.51061X20	L	orange RAL 2004	1	M6	40	16,5	31	13	-	20
K0260.51062X20	L	signal green RAL6032	1	M6	40	16,5	31	13	-	20
K0260.51063X20	L	blue RAL5017	1	M6	40	16,5	31	13	-	20
K0260.51065X20	L	light grey RAL 7035	1	M6	40	16,5	31	13	-	20
K0260.51066X20	L	traffic red RAL 3020	1	M6	40	16,5	31	13	-	20
K0260.51067X20	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	-	20
K0260.5106X40	L	black grey RAL 7021	1	M6	40	16,5	31	13	-	40
K0260.51061X40	L	orange RAL 2004	1	M6	40	16,5	31	13	-	40
K0260.51062X40	L	signal green RAL6032	1	M6	40	16,5	31	13	-	40
K0260.51063X40	L	blue RAL5017	1	M6	40	16,5	31	13	-	40
K0260.51065X40	L	light grey RAL 7035	1	M6	40	16,5	31	13	-	40
K0260.51066X40	L	traffic red RAL 3020	1	M6	40	16,5	31	13	-	40
K0260.51067X40	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	-	40
K0260.5108X15	L	black grey RAL 7021	1	M8	40	16,5	31	13	-	15
K0260.51081X15	L	orange RAL 2004	1	M8	40	16,5	31	13	-	15

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T	L
K0260.51082X15	L	signal green RAL6032	1	M8	40	16,5	31	13	-	15
K0260.51083X15	L	blue RAL5017	1	M8	40	16,5	31	13	-	15
K0260.51085X15	L	light grey RAL 7035	1	M8	40	16,5	31	13	-	15
K0260.51086X15	L	traffic red RAL 3020	1	M8	40	16,5	31	13	-	15
K0260.51087X15	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	-	15
K0260.5108X30	L	black grey RAL 7021	1	M8	40	16,5	31	13	-	30
K0260.51081X30	L	orange RAL 2004	1	M8	40	16,5	31	13	-	30
K0260.51082X30	L	signal green RAL6032	1	M8	40	16,5	31	13	-	30
K0260.51083X30	L	blue RAL5017	1	M8	40	16,5	31	13	-	30
K0260.51085X30	L	light grey RAL 7035	1	M8	40	16,5	31	13	-	30
K0260.51086X30	L	traffic red RAL 3020	1	M8	40	16,5	31	13	-	30
K0260.51087X30	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	-	30
K0260.5108X60	L	black grey RAL 7021	1	M8	40	16,5	31	13	-	60
K0260.51081X60	L	orange RAL 2004	1	M8	40	16,5	31	13	-	60
K0260.51082X60	L	signal green RAL6032	1	M8	40	16,5	31	13	-	60
K0260.51083X60	L	blue RAL5017	1	M8	40	16,5	31	13	-	60
K0260.51085X60	L	light grey RAL 7035	1	M8	40	16,5	31	13	-	60
K0260.51086X60	L	traffic red RAL 3020	1	M8	40	16,5	31	13	-	60
K0260.51087X60	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	-	60
K0260.5208X15	L	black grey RAL 7021	2	M8	50	18	36	15	-	15
K0260.52081X15	L	orange RAL 2004	2	M8	50	18	36	15	-	15
K0260.52082X15	L	signal green RAL6032	2	M8	50	18	36	15	-	15
K0260.52083X15	L	blue RAL5017	2	M8	50	18	36	15	-	15
K0260.52085X15	L	light grey RAL 7035	2	M8	50	18	36	15	-	15
K0260.52086X15	L	traffic red RAL 3020	2	M8	50	18	36	15	-	15
K0260.52087X15	L	colza yellow RAL 1021	2	M8	50	18	36	15	-	15
K0260.5208X30	L	black grey RAL 7021	2	M8	50	18	36	15	-	30
K0260.52081X30	L	orange RAL 2004	2	M8	50	18	36	15	-	30
K0260.52082X30	L	signal green RAL6032	2	M8	50	18	36	15	-	30
K0260.52083X30	L	blue RAL5017	2	M8	50	18	36	15	-	30
K0260.52085X30	L	light grey RAL 7035	2	M8	50	18	36	15	-	30
K0260.52086X30	L	traffic red RAL 3020	2	M8	50	18	36	15	-	30
K0260.52087X30	L	colza yellow RAL 1021	2	M8	50	18	36	15	-	30
K0260.5208X60	L	black grey RAL 7021	2	M8	50	18	36	15	-	60
K0260.52081X60	L	orange RAL 2004	2	M8	50	18	36	15	-	60
K0260.52082X60	L	signal green RAL6032	2	M8	50	18	36	15	-	60
K0260.52083X60	L	blue RAL5017	2	M8	50	18	36	15	-	60
K0260.52085X60	L	light grey RAL 7035	2	M8	50	18	36	15	-	60
K0260.52086X60	L	traffic red RAL 3020	2	M8	50	18	36	15	-	60
K0260.52087X60	L	colza yellow RAL 1021	2	M8	50	18	36	15	-	60
K0260.5210X20	L	black grey RAL 7021	2	M10	50	18	36	15	-	20
K0260.52101X20	L	orange RAL 2004	2	M10	50	18	36	15	-	20
K0260.52102X20	L	signal green RAL6032	2	M10	50	18	36	15	-	20
K0260.52103X20	L	blue RAL5017	2	M10	50	18	36	15	-	20
K0260.52105X20	L	light grey RAL 7035	2	M10	50	18	36	15	-	20
K0260.52106X20	L	traffic red RAL 3020	2	M10	50	18	36	15	-	20
K0260.52107X20	L	colza yellow RAL 1021	2	M10	50	18	36	15	-	20
K0260.5210X30	L	black grey RAL 7021	2	M10	50	18	36	15	-	30
K0260.52101X30	L	orange RAL 2004	2	M10	50	18	36	15	-	30
K0260.52102X30	L	signal green RAL6032	2	M10	50	18	36	15	-	30
K0260.52103X30	L	blue RAL5017	2	M10	50	18	36	15	-	30
K0260.52105X30	L	light grey RAL 7035	2	M10	50	18	36	15	-	30
K0260.52106X30	L	traffic red RAL 3020	2	M10	50	18	36	15	-	30
K0260.52107X30	L	colza yellow RAL 1021	2	M10	50	18	36	15	-	30
K0260.5210X60	L	black grey RAL 7021	2	M10	50	18	36	15	-	60
K0260.52101X60	L	orange RAL 2004	2	M10	50	18	36	15	-	60
K0260.52102X60	L	signal green RAL6032	2	M10	50	18	36	15	-	60
K0260.52103X60	L	blue RAL5017	2	M10	50	18	36	15	-	60
K0260.52105X60	L	light grey RAL 7035	2	M10	50	18	36	15	-	60
K0260.52106X60	L	traffic red RAL 3020	2	M10	50	18	36	15	-	60
K0260.52107X60	L	colza yellow RAL 1021	2	M10	50	18	36	15	-	60
K0260.5310X20	L	black grey RAL 7021	3	M10	63	22	41	17	-	20

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	T	L
K0260.53101X20	L	orange RAL 2004	3	M10	63	22	41	17	-	20
K0260.53102X20	L	signal green RAL6032	3	M10	63	22	41	17	-	20
K0260.53103X20	L	blue RAL5017	3	M10	63	22	41	17	-	20
K0260.53105X20	L	light grey RAL 7035	3	M10	63	22	41	17	-	20
K0260.53106X20	L	traffic red RAL 3020	3	M10	63	22	41	17	-	20
K0260.53107X20	L	colza yellow RAL 1021	3	M10	63	22	41	17	-	20
K0260.5310X30	L	black grey RAL 7021	3	M10	63	22	41	17	-	30
K0260.53101X30	L	orange RAL 2004	3	M10	63	22	41	17	-	30
K0260.53102X30	L	signal green RAL6032	3	M10	63	22	41	17	-	30
K0260.53103X30	L	blue RAL5017	3	M10	63	22	41	17	-	30
K0260.53105X30	L	light grey RAL 7035	3	M10	63	22	41	17	-	30
K0260.53106X30	L	traffic red RAL 3020	3	M10	63	22	41	17	-	30
K0260.53107X30	L	colza yellow RAL 1021	3	M10	63	22	41	17	-	30
K0260.5310X60	L	black grey RAL 7021	3	M10	63	22	41	17	-	60
K0260.53101X60	L	orange RAL 2004	3	M10	63	22	41	17	-	60
K0260.53102X60	L	signal green RAL6032	3	M10	63	22	41	17	-	60
K0260.53103X60	L	blue RAL5017	3	M10	63	22	41	17	-	60
K0260.53105X60	L	light grey RAL 7035	3	M10	63	22	41	17	-	60
K0260.53106X60	L	traffic red RAL 3020	3	M10	63	22	41	17	-	60
K0260.53107X60	L	colza yellow RAL 1021	3	M10	63	22	41	17	-	60
K0260.5312X30	L	black grey RAL 7021	3	M12	63	22	41	17	-	30
K0260.53121X30	L	orange RAL 2004	3	M12	63	22	41	17	-	30
K0260.53122X30	L	signal green RAL6032	3	M12	63	22	41	17	-	30
K0260.53123X30	L	blue RAL5017	3	M12	63	22	41	17	-	30
K0260.53125X30	L	light grey RAL 7035	3	M12	63	22	41	17	-	30
K0260.53126X30	L	traffic red RAL 3020	3	M12	63	22	41	17	-	30
K0260.53127X30	L	colza yellow RAL 1021	3	M12	63	22	41	17	-	30
K0260.5312X60	L	black grey RAL 7021	3	M12	63	22	41	17	-	60
K0260.53121X60	L	orange RAL 2004	3	M12	63	22	41	17	-	60
K0260.53122X60	L	signal green RAL6032	3	M12	63	22	41	17	-	60
K0260.53123X60	L	blue RAL5017	3	M12	63	22	41	17	-	60
K0260.53125X60	L	light grey RAL 7035	3	M12	63	22	41	17	-	60
K0260.53126X60	L	traffic red RAL 3020	3	M12	63	22	41	17	-	60
K0260.53127X60	L	colza yellow RAL 1021	3	M12	63	22	41	17	-	60