

## Clamping levers, plastic with internal thread, threaded insert stainless steel

Item description/product images



### Description

**Material:**

Handle fibreglass reinforced plastic with die-cast zinc toothed ring.  
Steel parts stainless steel 1.4305.

**Version:**

Steel parts bright.

**Note:**

Δ Add the desired grip colour here.

**On request:**

Other threads and special versions.

Dimension "H1" available in other lengths at extra charge.

# Clamping levers, plastic with internal thread, threaded insert stainless steel

Item description/product images


---




**Clamping levers, plastic with internal thread, threaded insert stainless steel**

Item description/product images

lift to  
disengage

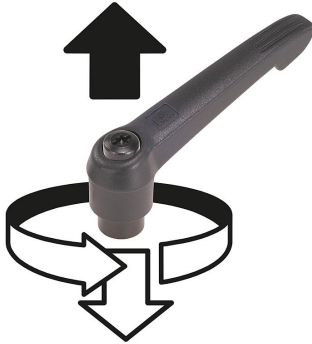

**Drawings**

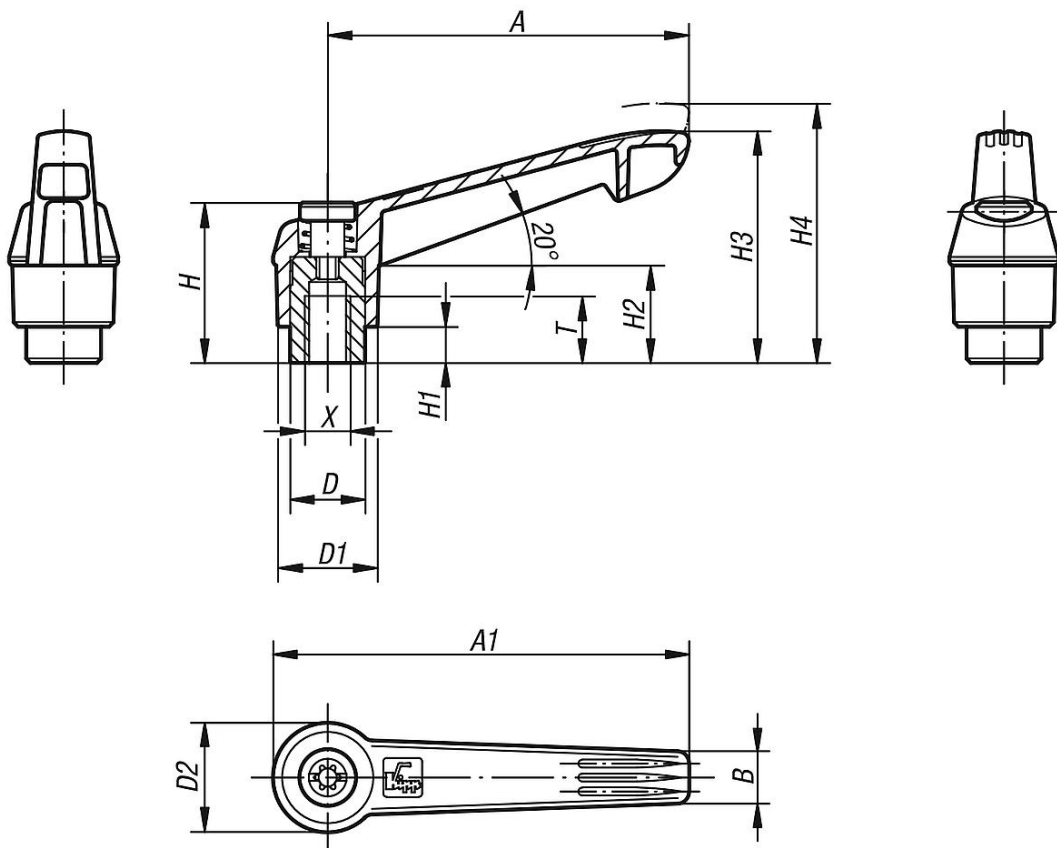

**Overview of items**

**Clamping levers with plastic handle, internal thread, metal parts stainless steel**

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
K0270.1041	black grey RAL 7021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16

# Clamping levers, plastic with internal thread, threaded insert stainless steel

## Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
K0270.1042	orange RAL 2004	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10416	colza yellow RAL 1021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10484	traffic red RAL 3020	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10486	signal green RAL 6032	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10487	traffic blue RAL 5017	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10488	light grey RAL 7035	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.1051	black grey RAL 7021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.1052	orange RAL 2004	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10516	colza yellow RAL 1021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10584	traffic red RAL 3020	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10586	signal green RAL 6032	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10587	traffic blue RAL 5017	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10588	light grey RAL 7035	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.1061	black grey RAL 7021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.1062	orange RAL 2004	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10616	colza yellow RAL 1021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10684	traffic red RAL 3020	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10686	signal green RAL 6032	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10687	traffic blue RAL 5017	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.10688	light grey RAL 7035	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
K0270.2061	black grey RAL 7021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.2062	orange RAL 2004	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20616	colza yellow RAL 1021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20684	traffic red RAL 3020	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20686	signal green RAL 6032	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20687	traffic blue RAL 5017	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20688	light grey RAL 7035	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.2081	black grey RAL 7021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.2082	orange RAL 2004	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20816	colza yellow RAL 1021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20884	traffic red RAL 3020	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20886	signal green RAL 6032	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20887	traffic blue RAL 5017	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.20888	light grey RAL 7035	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
K0270.3081	black grey RAL 7021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.3082	orange RAL 2004	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.30816	colza yellow RAL 1021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.30884	traffic red RAL 3020	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.30886	signal green RAL 6032	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.30887	traffic blue RAL 5017	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.30888	light grey RAL 7035	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.3101	black grey RAL 7021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.3102	orange RAL 2004	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.31016	colza yellow RAL 1021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.31084	traffic red RAL 3020	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.31086	signal green RAL 6032	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.31087	traffic blue RAL 5017	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.31088	light grey RAL 7035	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
K0270.4101	black grey RAL 7021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.4102	orange RAL 2004	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41016	colza yellow RAL 1021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41084	traffic red RAL 3020	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41086	signal green RAL 6032	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41087	traffic blue RAL 5017	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41088	light grey RAL 7035	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.4121	black grey RAL 7021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.4122	orange RAL 2004	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41216	colza yellow RAL 1021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41284	traffic red RAL 3020	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41286	signal green RAL 6032	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41287	traffic blue RAL 5017	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
K0270.41288	light grey RAL 7035	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24

# Clamping levers, plastic with internal thread, threaded insert stainless steel

## Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
<b>K0270.5121</b>	black grey RAL 7021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.5122</b>	orange RAL 2004	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51216</b>	colza yellow RAL 1021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51284</b>	traffic red RAL 3020	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51286</b>	signal green RAL 6032	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51287</b>	traffic blue RAL 5017	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51288</b>	light grey RAL 7035	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.5161</b>	black grey RAL 7021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.5162</b>	orange RAL 2004	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51616</b>	colza yellow RAL 1021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51684</b>	traffic red RAL 3020	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51686</b>	signal green RAL 6032	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51687</b>	traffic blue RAL 5017	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
<b>K0270.51688</b>	light grey RAL 7035	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26