

# Ball-end thrust screws with head stainless steel Form A, with full ball

## Item description/product images



## Description


### Version:

Bright.

### Note:

Form A with full ball is used when a clean, polished pressure surface is required.

## Drawings

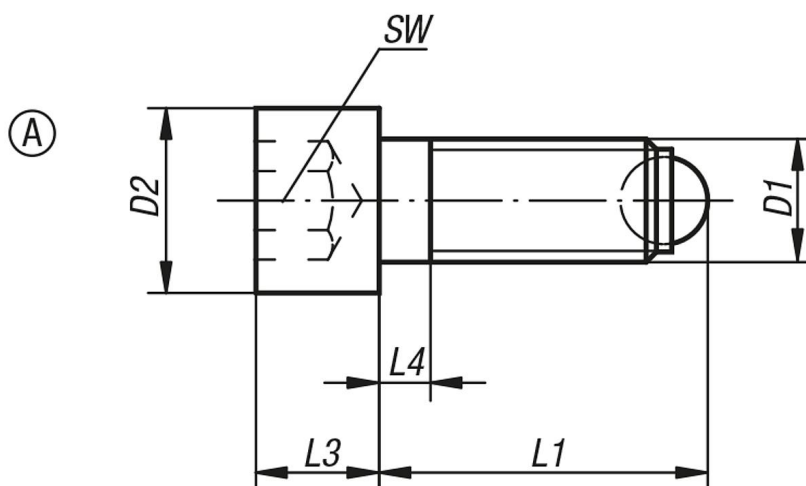

## Overview of items

Order No.	Form	D1	D2	L1	L3	L4	Ball-Ø	SW
K0381.10410	A	M4	7	10,2	4	2,1	2,5	3
K0381.10416	A	M4	7	16,2	4	2,1	2,5	3
K0381.10420	A	M4	7	20,2	4	2,1	2,5	3
K0381.10512	A	M5	8,5	12,4	5	2,4	3	4
K0381.10516	A	M5	8,5	16,4	5	2,4	3	4

## Ball-end thrust screws with head stainless steel Form A, with full ball

### Overview of items

Order No.	Form	D1	D2	L1	L3	L4	Ball-Ø	SW
K0381.10520	A	M5	8,5	20,4	5	2,4	3	4
K0381.10620	A	M6	10	20,8	6	3	4	5
K0381.10630	A	M6	10	30,8	6	3	4	5
K0381.10640	A	M6	10	40,8	6	16	4	5
K0381.10820	A	M8	13	21,2	8	3,5	5,5	6
K0381.10835	A	M8	13	36,2	8	3,5	5,5	6
K0381.10850	A	M8	13	51,2	8	22	5,5	6
K0381.11025	A	M10	16	26,7	10	4,5	7	8
K0381.11040	A	M10	16	41,7	10	4,5	7	8
K0381.11060	A	M10	16	61,7	10	28	7	8
K0381.11230	A	M12	18	32	12	5	8,5	10
K0381.11250	A	M12	18	52	12	5	8,5	10
K0381.11280	A	M12	18	82	12	44	8,5	10
K0381.11640	A	M16	24	43,3	16	6	12	14
K0381.11660	A	M16	24	63,3	16	6	12	14
K0381.11680	A	M16	24	83,3	16	36	12	14