

Star grips similar to DIN 6336

Item description/product images



Description

Material:

Thermoset PF 31, black.

Bush and screw steel, trivalent blue passivated.

Version:

High-gloss polished.

Note:

The version K0152.22004 has a brass bush.

On request:



Other colours.

Drawing reference:

Form K: tapped bush

Form L: external thread

Drawings

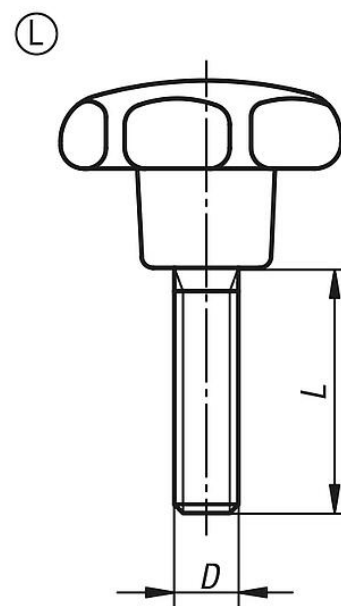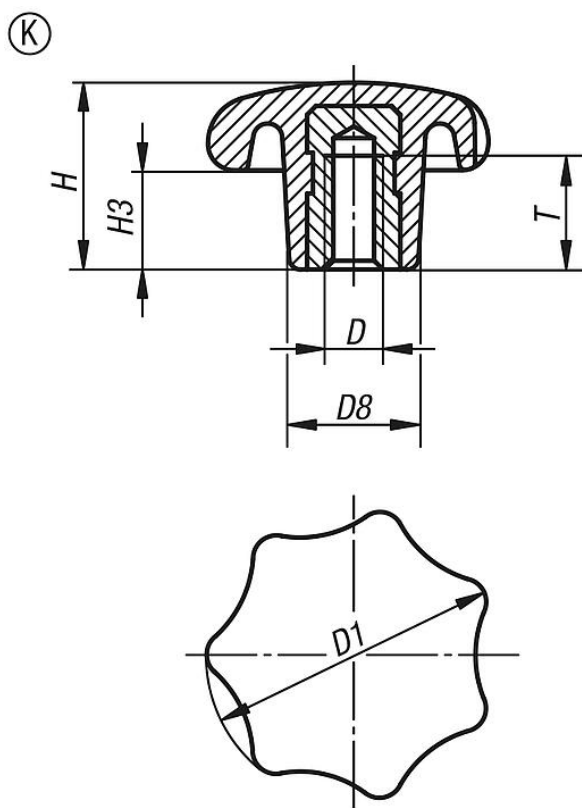

Overview of items

Order No.	Form	D	D1	D8	H	H3	L	T
K0152.22004	K	M4	20	10	13	7	-	8
K0152.22505	K	M5	25	12	16	8	-	10,5
K0152.23206	K	M6	32	14	20	10	-	16
K0152.24008	K	M8	40	18	25	12	-	18
K0152.25010	K	M10	50	21	32	16	-	25
K0152.26312	K	M12	63	26	40	19	-	27

Star grips similar to DIN 6336

Overview of items

Order No.	Form	D	D1	D8	H	H3	L	T
K0152.28016	K	M16	80	36	48	25	-	33
K0152.42505X15	L	M5	25	12	16	8	15	-
K0152.42505X20	L	M5	25	12	16	8	20	-
K0152.42505X25	L	M5	25	12	16	8	25	-
K0152.43206X15	L	M6	32	14	20	10	15	-
K0152.43206X20	L	M6	32	14	20	10	20	-
K0152.43206X25	L	M6	32	14	20	10	25	-
K0152.43206X30	L	M6	32	14	20	10	30	-
K0152.44008X20	L	M8	40	18	25	12	20	-
K0152.44008X25	L	M8	40	18	25	12	25	-
K0152.44008X30	L	M8	40	18	25	12	30	-
K0152.44008X35	L	M8	40	18	25	12	35	-
K0152.44008X40	L	M8	40	18	25	12	40	-
K0152.45010X25	L	M10	50	22	32	16	25	-
K0152.45010X30	L	M10	50	22	32	16	30	-
K0152.45010X35	L	M10	50	22	32	16	35	-
K0152.45010X40	L	M10	50	22	32	16	40	-
K0152.45010X50	L	M10	50	22	32	16	50	-
K0152.46312X30	L	M12	63	26	40	19	30	-
K0152.46312X35	L	M12	63	26	40	19	35	-
K0152.46312X40	L	M12	63	26	40	19	40	-
K0152.46312X50	L	M12	63	26	40	19	50	-
K0152.46312X60	L	M12	63	26	40	19	60	-
K0152.48016X30	L	M16	80	35	50	25	30	-
K0152.48016X40	L	M16	80	35	50	25	40	-
K0152.48016X50	L	M16	80	35	50	25	50	-
K0152.48016X60	L	M16	80	35	50	25	60	-